

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable



1404708

<https://www.phoenixcontact.com/us/products/1404708>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, 3-position, PVC, black RAL 9005, Plug straight M8, coding: A, on Socket straight M8, cable length: 5 m

## Your advantages

- Easy and safe: 100 % electrically tested plug-in components

## Commercial data

Item number	1404708
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF01
Product key	AF1BBA
GTIN	4046356724906
Weight per piece (including packing)	139.8 g
Weight per piece (excluding packing)	139.8 g
Customs tariff number	85444290
Country of origin	PL

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable



1404708

<https://www.phoenixcontact.com/us/products/1404708>

## Technical data

### Product properties

Product type	Sensor/actuator cable
Application	Standard
Number of positions	3
No. of cable outlets	1
Shielded	no
Coding	A

### Material specifications

Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material for screw connection	Zinc die-cast, nickel-plated

### Electrical properties

Insulation resistance	$\geq 100 \text{ M}\Omega$
Nominal voltage $U_N$	60 V
Nominal current $I_N$	4 A

### Mechanical properties

#### Mechanical data

Insertion/withdrawal cycles	$\geq 100$
-----------------------------	------------

### Signaling

Status display	no
Status display present	no

### Connection data

#### Conductor connection

Tightening torque	0.2 Nm (M8 connectors)
-------------------	------------------------

### Connector

#### Connection 1

Type	Plug straight M8
Number of positions	3
Coding type	A

#### Connection 2

Type	Socket straight M8
Number of positions	3

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable

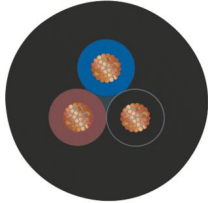
1404708

<https://www.phoenixcontact.com/us/products/1404708>

## Cable/line

Cable length	5 m
--------------	-----

### PVC black [PVC]

Dimensional drawing	
Cable weight	29 kg/km
Number of positions	3
Shielded	no
Cable type	PVC black [PVC]
Conductor structure signal line	32x 0.10 mm
AWG signal line	24
Conductor cross-section	3x 0.25 mm <sup>2</sup> (Signal line)
Wire diameter incl. insulation	1.25 mm ±0.02 mm
External cable diameter	4.40 mm ±0.15 mm
Outer sheath, material	PVC
External sheath, color	black RAL 9005
Conductor material	Bare Cu litz wires
Material wire insulation	PVC
Single wire, color	brown, blue, black
Thickness, insulation	≥ 0.23 mm (Core insulation)
Thickness, outer sheath	≥ 0.76 mm
Overall twist	3 wires, twisted
Max. conductor resistance	max. 78 Ω/km (at 20 °C)
Insulation resistance	≥ 100 MΩ*km (at 20 °C)
Nominal voltage, cable	≥ 300 V
Test voltage	≤ 3000 V
Flame resistance	As per UL-Style 2464
Ambient temperature (operation)	-25 °C ... 80 °C (cable, fixed installation) -5 °C ... 80 °C (Cable, flexible installation)

## Environmental and real-life conditions

### Ambient conditions

Degree of protection	IP65 IP67 IP68
Ambient temperature (operation) (male connector/female)	-25 °C ... 90 °C (Plug / socket)

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable



1404708

<https://www.phoenixcontact.com/us/products/1404708>

connector)

## Standards and regulations

Standard designation	M8 connector
Standards/specifications	IEC 61076-2-104

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable



1404708

<https://www.phoenixcontact.com/us/products/1404708>

## Drawings

Dimensional drawing



M8 x 1 male plug, straight version

Dimensional drawing



Socket M8 x 1, straight

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable

1404708

<https://www.phoenixcontact.com/us/products/1404708>

Schematic diagram



Pin assignment M8 plug, 3-pos., view male side

Schematic diagram



Pin assignment M8 socket, 3-pos., view female side

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable



1404708

<https://www.phoenixcontact.com/us/products/1404708>

Circuit diagram



Contact assignment of M8 plugs/sockets

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable



1404708

<https://www.phoenixcontact.com/us/products/1404708>

## Classifications

### ECLASS

ECLASS-13.0	27060311
ECLASS-15.0	27060311

# SAC-3P-M 8MS/5,0-PVC/M 8FS B-L - Sensor/actuator cable



1404708

<https://www.phoenixcontact.com/us/products/1404708>

## Environmental product compliance

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)