



UNO POWER

Compact power supplies
2017/2018

UNO POWER

Compact power supplies

Thanks to their high power density, UNO POWER power supplies offer the ideal solution for loads up to 240 W, particularly in compact control boxes. The wide range of products from 5 to 48 V DC covers all common voltage levels.




Your advantages

- ✓ Maximum energy efficiency thanks to high efficiency of up to 94 % and extremely low idling losses to under 0.3 W
- ✓ Especially compact due to high power density
- ✓ Outdoor installation possible with a wide temperature range of -25 °C to +70 °C

UNO POWER 1~					UNO POWER 2~
85 ... 264 V AC	85 ... 264 V AC	85 ... 264 V AC	85 ... 264 V AC	85 ... 264 V AC	264 ... 575 V AC
22.5 x 90 x 84 mm*	35 x 90 x 84 mm*	55 x 90 x 84 mm*	37 x 130 x 125 mm*	45 x 130 x 125 mm*	55 x 90 x 84 mm*
24 DC / 30 W	24 DC / 60 W	24 DC / 100 W	24 DC / 150 W	24 DC / 240 W	24 DC / 90 W / C2LPS**
2902991	2902992	2902993	2904376	2904372	2904371
		24 DC / 90 W / C2LPS**	* W x H x D ** NEC Class 2 output, certified in accordance with UL 1310/Limited Power Source (LPS) in accordance with UL 60950-1		
		2902994			
	48 DC / 60 W	48 DC / 100 W			
	2902995	2902996			
15 DC / 30 W	15 DC / 55 W	15 DC / 100 W			
2903000	2903001	2903002			
12 DC / 30 W	12 DC / 55 W	12 DC / 100 W			
2902998	2902999	2902997			
5 DC / 25 W	5 DC / 40 W				
2904374	2904375				

More information at
phoenixcontact.net

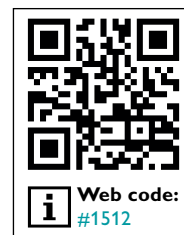

Further information on UNO POWER:
Just scan the QR code or enter the web code into the search field on our website.