

# SAC-4P-100,0-186/0,75 - Cable reel



1457461

<https://www.phoenixcontact.com/us/products/1457461>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

By the meter, Cable reel, PUR, black-gray RAL 7021, 4-wire, color single wire: brown, white, blue, black, cable length: 100 m



## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 1457461                        |
| Packing unit                         | 1 pc                           |
| Minimum order quantity               | 1 pc                           |
| Note                                 | Made to order (non-returnable) |
| Sales key                            | BF11                           |
| Product key                          | BF1LBA                         |
| Catalog page                         | Page 168 (C-4-2013)            |
| GTIN                                 | 4046356617789                  |
| Weight per piece (including packing) | 5,660 g                        |
| Weight per piece (excluding packing) | 5,350 g                        |
| Customs tariff number                | 85444290                       |
| Country of origin                    | PL                             |

# SAC-4P-100,0-186/0,75 - Cable reel

1457461

<https://www.phoenixcontact.com/us/products/1457461>

## Technical data

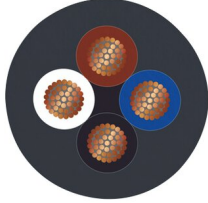
### Product properties

|                     |                    |
|---------------------|--------------------|
| Product type        | Cable by the meter |
| Number of positions | 4                  |
| Application         | Connector          |
| Shielded            | no                 |

### Cable/line

|              |       |
|--------------|-------|
| Cable length | 100 m |
|--------------|-------|

PUR POWER 0.75 mm<sup>2</sup> black [186]

|  |   |
|--|---|
| Dimensional drawing                        |  |
| Cable weight                               | 57 kg/km  |
| UL AWM Style                               | 20549 / 1061 (80°C/300 V)   |
| Number of positions                        | 4   |
| Shielded                                   | no  |
| Cable type                                 | PUR POWER 0.75 mm <sup>2</sup> black [186]  |
| Conductor structure signal line            | 42x 0.15 mm   |
| AWG signal line                            | 18  |
| Conductor cross section                    | 4x 0.75 mm <sup>2</sup> (power line)  |
| Wire diameter incl. insulation             | 1.75 mm ±0.05 mm  |
| External cable diameter                    | 5.9 mm ±0.15 mm   |
| Outer sheath, material                     | PUR   |
| External sheath, color                     | black-gray RAL 7021   |
| Conductor material                         | Bare Cu litz wires  |
| Material wire insulation                   | PVC   |
| Single wire, color                         | brown, white, blue, black   |
| Thickness, insulation                      | ≥ 0.23 mm (Core insulation)<br>≥ 0.76 mm (Outer cable sheath)                       |
| Overall twist                              | 4 wires, twisted  |
| Max. conductor resistance                  | max. 26 Ω/km (at 20 °C)   |
| Insulation resistance                      | ≥ 1 MΩ*km (at 20 °C)  |
| Nominal voltage, cable                     | ≤ 300 V   |
| Test voltage                               | ≥ 3000 V  |
| Minimum bending radius, fixed installation | 5 x D   |

# SAC-4P-100,0-186/0,75 - Cable reel



1457461

<https://www.phoenixcontact.com/us/products/1457461>

|   |   |
|---|---|
| Minimum bending radius, flexible installation | 10 x D  |
| Smallest bending radius, fixed installation   | 30 mm   |
| Smallest bending radius, movable installation | 59 mm   |
| Max. bending cycles                           | 2000000   |
| Flame resistance                              | according to UL 758/1581 (horizontal)<br>in accordance with UL 758/1581 FT2                       |
| Resistance to oil                             | According to DIN EN 60811-2-1, 168 h at 100°C   |
| Other resistance                              | hydrolysis and microbe resistant<br>Low adhesion<br>abrasion-resistant<br>Resistant to salt water |
| Ambient temperature (operation)               | -25 °C ... 80 °C (cable, fixed installation)<br>-5 °C ... 80 °C (Cable, flexible installation)    |

# SAC-4P-100,0-186/0,75 - Cable reel



1457461

<https://www.phoenixcontact.com/us/products/1457461>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1457461>



**EAC-RoHS**

Approval ID: RU D-DE.HB35.B.00371

# SAC-4P-100,0-186/0,75 - Cable reel



1457461

<https://www.phoenixcontact.com/us/products/1457461>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27061801 |
| ECLASS-12.0 | 27061801 |
| ECLASS-13.0 | 27061801 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC003249 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 26121600 |
|-------------|----------|

# SAC-4P-100,0-186/0,75 - Cable reel



1457461

<https://www.phoenixcontact.com/us/products/1457461>

## Environmental product compliance

|            |   |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

# SAC-4P-100,0-186/0,75 - Cable reel



1457461

<https://www.phoenixcontact.com/us/products/1457461>

## Accessories

### WIREFOX SAC - Stripping tool

1212623

<https://www.phoenixcontact.com/us/products/1212623>



Stripping pliers, for halogen-free sensor/actuator cables (SAC cables), with PUR and PVC insulation, from Ø of 4.4 to 7 mm, any stripping length

---

Phoenix Contact 2023 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)