

PTFIX 2,5-RZ - Mounting adapter



1632417

<https://www.phoenixcontact.com/gb/products/1632417>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Securing pin adapter, for direct mounting of 2.5 mm², 4 mm², and 10 mm² FIX blocks, color: gray



Commercial data

Item number	1632417
Packing unit	20 pc
Minimum order quantity	20 pc
Sales key	BEAZ11
Product key	BEAZ11
GTIN	4067923151192
Weight per piece (including packing)	0.69 g
Weight per piece (excluding packing)	0.69 g
Country of origin	PL

PTFIX 2,5-RZ - Mounting adapter

1632417


<https://www.phoenixcontact.com/gb/products/1632417>

Technical data

Product properties

Product type	Mounting material
--------------	-------------------

Dimensions

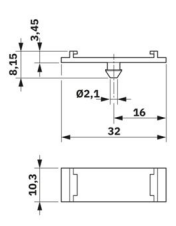Dimensional drawing	
Width	10.3 mm
Height	32 mm
Depth	8.2 mm
Hole diameter	3.5 mm
Plate thickness	0.6 mm ... 1.6 mm

Material specifications

Color	gray (RAL 7042)
Flammability rating according to UL 94	V0
Static insulating material application in cold	-60 °C
Relative insulation material temperature index (Elec., UL 746 B)	130 °C
Fire protection for rail vehicles (DIN EN 45545-2) R22	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R23	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R24	HL 1 - HL 3
Fire protection for rail vehicles (DIN EN 45545-2) R26	HL 1 - HL 3
Surface flammability NFPA 130 (ASTM E 162)	passed
Specific optical density of smoke NFPA 130 (ASTM E 662)	passed
Smoke gas toxicity NFPA 130 (SMP 800C)	passed

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-60 °C ... 110 °C (Operating temperature range incl. self-heating; for max. short-term operating temperature, see RTI Elec.)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C
Permissible humidity (operation)	20 % ... 90 %
Permissible humidity (storage/transport)	30 % ... 70 %


PTFIX 2,5-RZ - Mounting adapter

1632417

<https://www.phoenixcontact.com/gb/products/1632417>

Drawings

Dimensional drawing

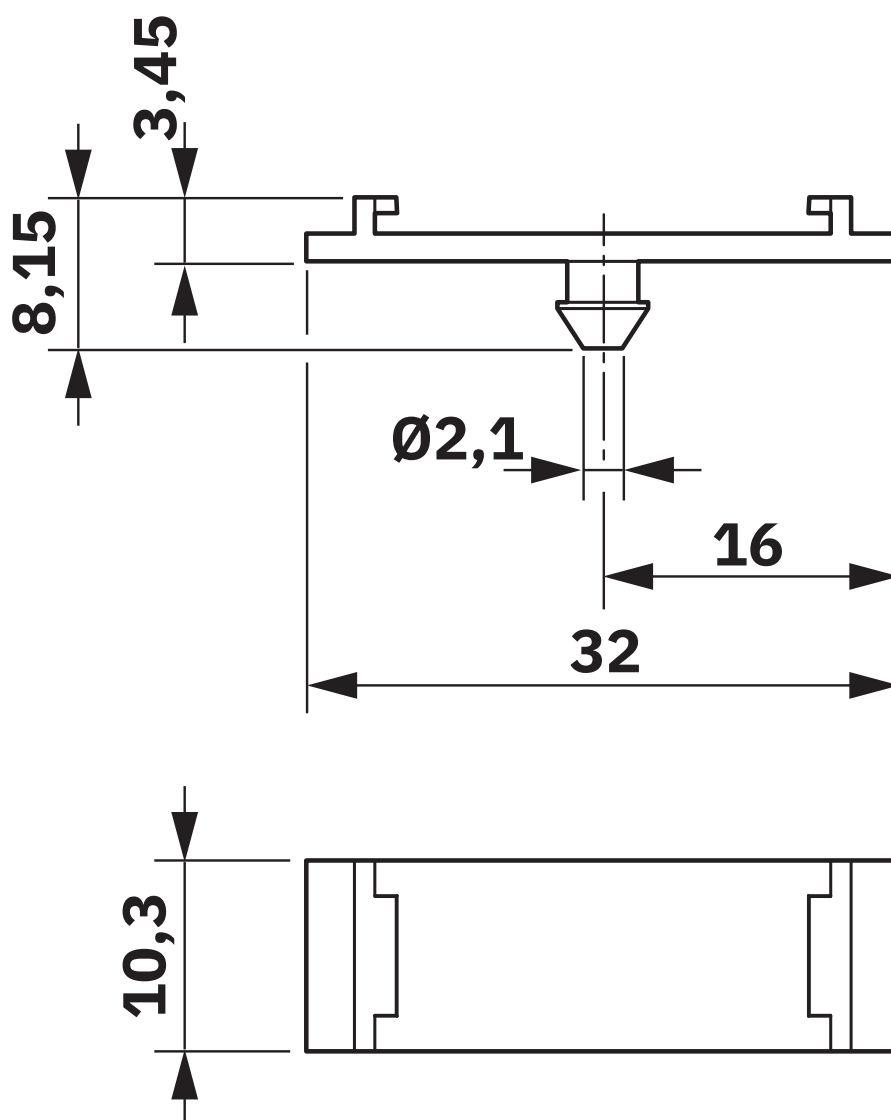

PTFIX 2,5-RZ - Mounting adapter



1632417

<https://www.phoenixcontact.com/gb/products/1632417>

Classifications

ECLASS

ECLASS-13.0	27370419
ECLASS-15.0	27370419

ETIM

ETIM 10.0	EC001024
-----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

PTFIX 2,5-RZ - Mounting adapter



1632417

<https://www.phoenixcontact.com/gb/products/1632417>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

EF3.1 Climate Change

CO2e kg	0.004 kg CO2e
---------	---------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk