

# SAC-3P-MS/0,4-PUR/CI1LS SCO VL - Sensor/actuator cable



1400736

<https://www.phoenixcontact.com/us/products/1400736>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, Plug straight M12 SPEEDCON, coding: A, on Valve connector CI (9.4 mm), with 1 LED, Wiring: Z diode

## Commercial data

Item number	1400736
Packing unit	50 pc
Minimum order quantity	50 pc
Product key	AF1DOA
GTIN	4046356513357
Weight per piece (including packing)	41.83 g
Weight per piece (excluding packing)	37.6 g
Country of origin	PL

# SAC-3P-MS/0,4-PUR/CI1LS SCO VL - Sensor/actuator cable



1400736

<https://www.phoenixcontact.com/us/products/1400736>

## Technical data

### Product properties

Product type	Sensor/actuator cable with valve connector
--------------	--

### Insulation characteristics

Overvoltage category	III
Degree of pollution	3

### Electrical properties

Nominal voltage $U_N$	24 V AC
	24 V DC
Nominal current $I_N$	4 A

### Connector

#### Connection 1

Type	Plug straight M12 SPEEDCON
Locking type	SPEEDCON
Coding type	A

#### Connection 2

Type	Valve connector CI (9.4 mm)
Protective circuit	Z diode

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP65
	IP67


# SAC-3P-MS/0,4-PUR/CI1LS SCO VL - Sensor/actuator cable

1400736

<https://www.phoenixcontact.com/us/products/1400736>

## Drawings

Schematic diagram

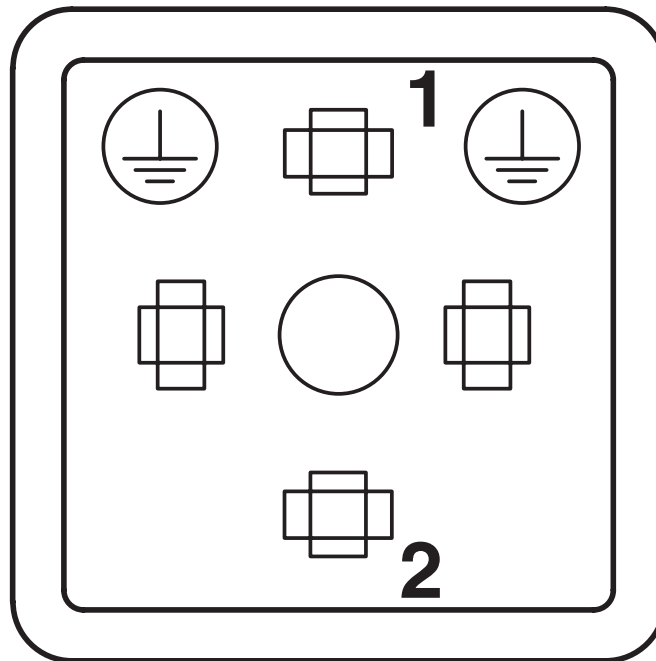

# SAC-3P-MS/0,4-PUR/CI1LS SCO VL - Sensor/actuator cable



1400736

<https://www.phoenixcontact.com/us/products/1400736>

## Classifications

### ECLASS

ECLASS-13.0	27060311
ECLASS-15.0	27060312

### UNSPSC

UNSPSC 21.0	31251501
-------------	----------

# SAC-3P-MS/0,4-PUR/CI1LS SCO VL - Sensor/actuator cable



1400736

<https://www.phoenixcontact.com/us/products/1400736>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	7(c)-I

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)