

# SAC-5P-M12MSB/ 6,0-500/M12FSB - Sensor/actuator cable



1402301

<https://www.phoenixcontact.com/us/products/1402301>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, 5-position, PVC, gray RAL 7001, Plug straight M12, coding: B, on Socket straight M12, coding: B, cable length: 6 m

## Commercial data

Item number	1402301
Packing unit	1 pc
Minimum order quantity	25 pc
Product key	AF1CDA
GTIN	4046356593823
Weight per piece (including packing)	326.3 g
Weight per piece (excluding packing)	311.7 g
Country of origin	PL

# SAC-5P-M12MSB/ 6,0-500/M12FSB - Sensor/actuator cable



1402301

<https://www.phoenixcontact.com/us/products/1402301>

## Technical data

### Product properties

Product type	Sensor/actuator cable
Number of positions	5
No. of cable outlets	1
Coding	B

### Material specifications

Seal material	NBR
Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material for screw connection	Zinc die-cast, nickel-plated

### Electrical properties

Insulation resistance	$\geq 100 \text{ M}\Omega$
Nominal voltage $U_N$	48 V AC
	60 V DC

### Mechanical properties

#### Mechanical data

Insertion/withdrawal cycles	$\geq 100$
-----------------------------	------------

### Signaling

Status display	no
Status display present	no

### Connector

#### Connection 1

Type	Plug straight M12
Number of positions	5
Coding type	B

#### Connection 2

Type	Socket straight M12
Number of positions	5
Coding type	B

### Cable/line

Cable length	6 m
--------------	-----


PVC gray [500]

# SAC-5P-M12MSB/ 6,0-500/M12FSB - Sensor/actuator cable



1402301

<https://www.phoenixcontact.com/us/products/1402301>

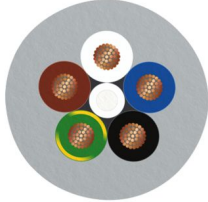Dimensional drawing	
Cable weight	51 kg/km
UL AWM Style	2464 / 1729 (80°C/300 V)
Number of positions	5
Shielded	no
Cable type	PVC gray [500]
Conductor structure signal line	19x 0.15 mm
AWG signal line	22
Conductor cross-section	5x 0.34 mm <sup>2</sup> (Signal line)
Wire diameter incl. insulation	1.26 mm ±0.05 mm
External cable diameter	5.00 mm ±0.15 mm
Outer sheath, material	PVC
External sheath, color	gray RAL 7001
Conductor material	Bare Cu litz wires
Material wire insulation	PVC
Single wire, color	brown, white, blue, black, green-yellow
Thickness, insulation	≥ 0.23 mm (Core insulation)
Thickness, outer sheath	≥ 0.76 mm
Overall twist	5 wires around filler to the core
Max. conductor resistance	max. 57 Ω/km (at 20 °C)
Insulation resistance	≥ 200 MΩ*km (at 20 °C)
Nominal voltage, cable	≤ 300 V
Test voltage	≥ 3000 V
Minimum bending radius, fixed installation	5 x D
Minimum bending radius, flexible installation	10 x D
Smallest bending radius, fixed installation	25 mm
Smallest bending radius, movable installation	50 mm
Flame resistance	As per UL-Style 2464
Ambient temperature (operation)	-40 °C ... 80 °C (cable, fixed installation) -25 °C ... 80 °C (Cable, flexible installation)

## Environmental and real-life conditions

### Ambient conditions

Ambient temperature (operation) (male connector/female connector)	-25 °C ... 90 °C (Plug / socket)
---	----------------------------------

# SAC-5P-M12MSB/ 6,0-500/M12FSB - Sensor/actuator cable

1402301

<https://www.phoenixcontact.com/us/products/1402301>

## Drawings

Dimensional drawing



Plug, M12 x 1, straight, shielded

Dimensional drawing



M12 x 1 socket, straight, shielded


# SAC-5P-M12MSB/ 6,0-500/M12FSB - Sensor/actuator cable



1402301

<https://www.phoenixcontact.com/us/products/1402301>

Schematic diagram

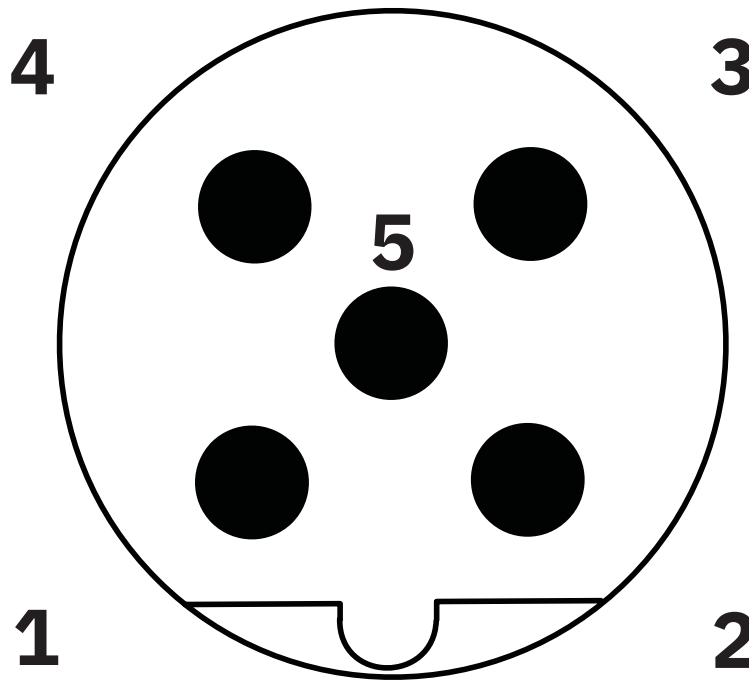


Pin assignment M12 male connector, 5-pos., B-coded, male side

1402301

<https://www.phoenixcontact.com/us/products/1402301>

Schematic diagram

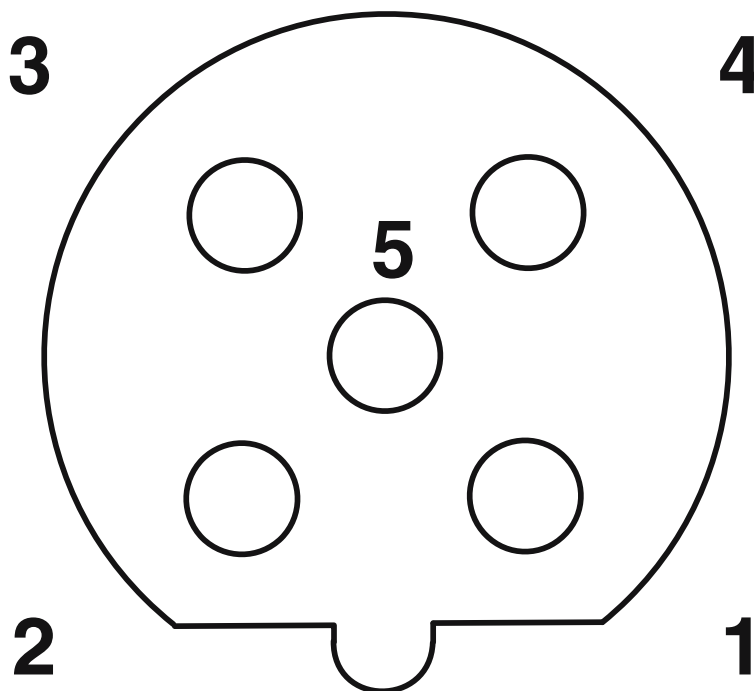

Pin assignment M12 socket, 5-pos., B-coded, female side

# SAC-5P-M12MSB/ 6,0-500/M12FSB - Sensor/actuator cable



1402301

<https://www.phoenixcontact.com/us/products/1402301>

## Classifications

### ECLASS

ECLASS-13.0	27060311
ECLASS-15.0	27060311

# SAC-5P-M12MSB/ 6,0-500/M12FSB - Sensor/actuator cable



1402301

<https://www.phoenixcontact.com/us/products/1402301>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)