

# HC-HPR-B24-BFH-EMR-BK - Housing



1411055

<https://www.phoenixcontact.com/us/products/1411055>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HEAVYCON B24 panel mounting base, HPR series, for screw locking, for increased environmental and EMC requirements

## Your advantages

- Vibration and shock: IEC 61373/EN 50155, category 1, class 1B

## Commercial data

Item number	1411055
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF60
Product key	AF7AAI
GTIN	4046356921688
Weight per piece (including packing)	198.6 g
Weight per piece (excluding packing)	190 g
Customs tariff number	85389099
Country of origin	CN

## Technical data

### Notes

General	For contact inserts HC-B24, BB46, BBB64, D64, DD108, M
---------	--------------------------------------------------------


### Product properties

Product type	Housing with screw locking
Housing type	Panel mounting base
Product family	HC-HPR-B
Series	HPR-B24
Application	Railway applications
Type	B24
Protective cover	no
Pg screw connection	none

### Connection data

Tightening torque	4 Nm (Locking screw)
-------------------	----------------------

### Dimensions

Dimensional drawing	
Width	58 mm
Height	20 mm
Length	192 mm
Drill hole distance, horizontal	130 mm
Drill hole distance, vertical	32 mm
Hole diameter	6.5 mm

### Installation dimensions

Width of the assembly cutout	35 mm
Length of the assembly cutout	108 mm

### Material specifications

Seal material	NBR
Housing material	Die-cast aluminum
Housing surface material	Powder-coated, black
Locking latch material	Stainless steel
Material of locking screw	Stainless steel

### Environmental and real-life conditions

#### Ambient conditions

# HC-HPR-B24-BFH-EMR-BK - Housing



1411055

<https://www.phoenixcontact.com/us/products/1411055>

Degree of protection	IP66
	IP68 (0.5 bar / 24 h)
	IP69 (ISO 20653:2013-02)
Impact strength	IK09
Ambient temperature (operation)	-40 °C ... 125 °C

## Mechanical properties

### Mechanical data

Locking type	Nut
--------------	-----


# HC-HPR-B24-BFH-EMR-BK - Housing

1411055


<https://www.phoenixcontact.com/us/products/1411055>

## Drawings

Dimensional drawing

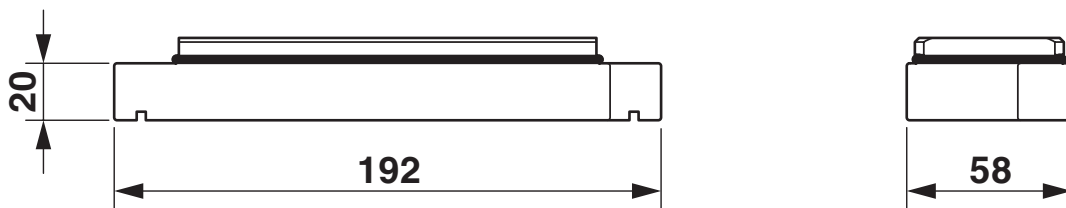

Dimensional drawing

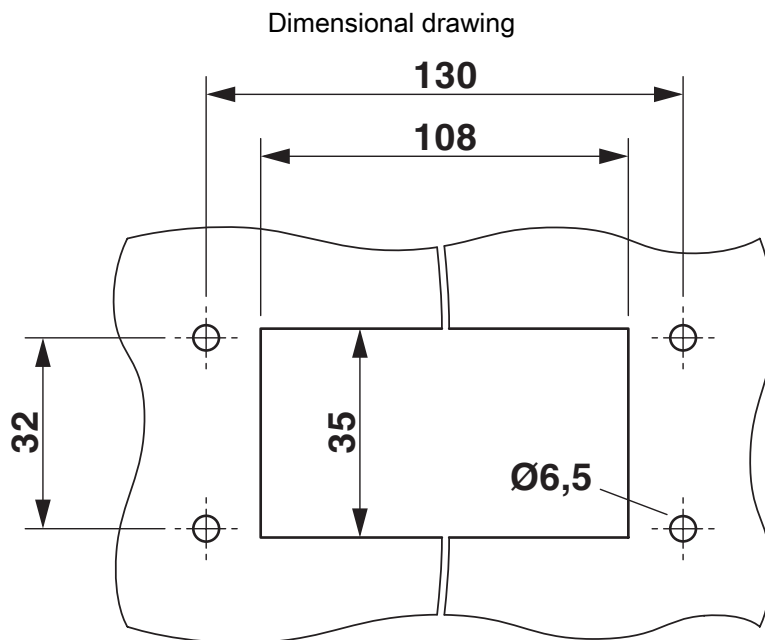

Mounting cutout

# HC-HPR-B24-BFH-EMR-BK - Housing



1411055

<https://www.phoenixcontact.com/us/products/1411055>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1411055>

**DNV**

Approval ID: TAE000037S



**EAC**

Approval ID: RU C-DE.AI30.B.01102

1411055

<https://www.phoenixcontact.com/us/products/1411055>

## Classifications

### ECLASS

ECLASS-13.0	27440202
ECLASS-15.0	27440202

### ETIM

ETIM 10.0	EC000437
-----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

1411055

<https://www.phoenixcontact.com/us/products/1411055>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
-----------------------------------------	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)