

# HC-B06-SG-CBK - Flat gasket

1411483

<https://www.phoenixcontact.com/us/products/1411483>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Replacement flat gasket, for HEAVYCON panel mounting base, HC-STA-...AL, type B6, conductive



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1411483       |
| Packing unit                         | 10 pc         |
| Minimum order quantity               | 10 pc         |
| Sales key                            | BF66          |
| Product key                          | AF7APZ        |
| GTIN                                 | 4046356932837 |
| Weight per piece (including packing) | 5.05 g        |
| Weight per piece (excluding packing) | 4.21 g        |
| Customs tariff number                | 40169300      |
| Country of origin                    | CN            |

# HC-B06-SG-CBK - Flat gasket

1411483


<https://www.phoenixcontact.com/us/products/1411483>

## Technical data

### Product properties

|              |                      |
|--------------|----------------------|
| Product type | Seal                 |
| Application  | for panel-mount base |

### Dimensions
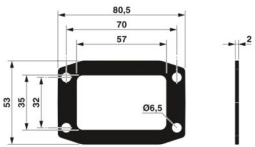
|                                 |                                                                                    |
|---------------------------------|------------------------------------------------------------------------------------|
| Dimensional drawing             |  |
| Width                           | 53 mm                                                                              |
| Height                          | 2 mm                                                                               |
| Length                          | 80.5 mm                                                                            |
| Drill hole distance, horizontal | 70 mm                                                                              |
| Drill hole distance, vertical   | 32 mm                                                                              |
| Hole diameter                   | 6.5 mm                                                                             |

### Material specifications

|               |                 |
|---------------|-----------------|
| Material      | NBR, conductive |
| Seal material | NBR             |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 125 °C |
|---------------------------------|-------------------|


# HC-B06-SG-CBK - Flat gasket

1411483

<https://www.phoenixcontact.com/us/products/1411483>



## Drawings

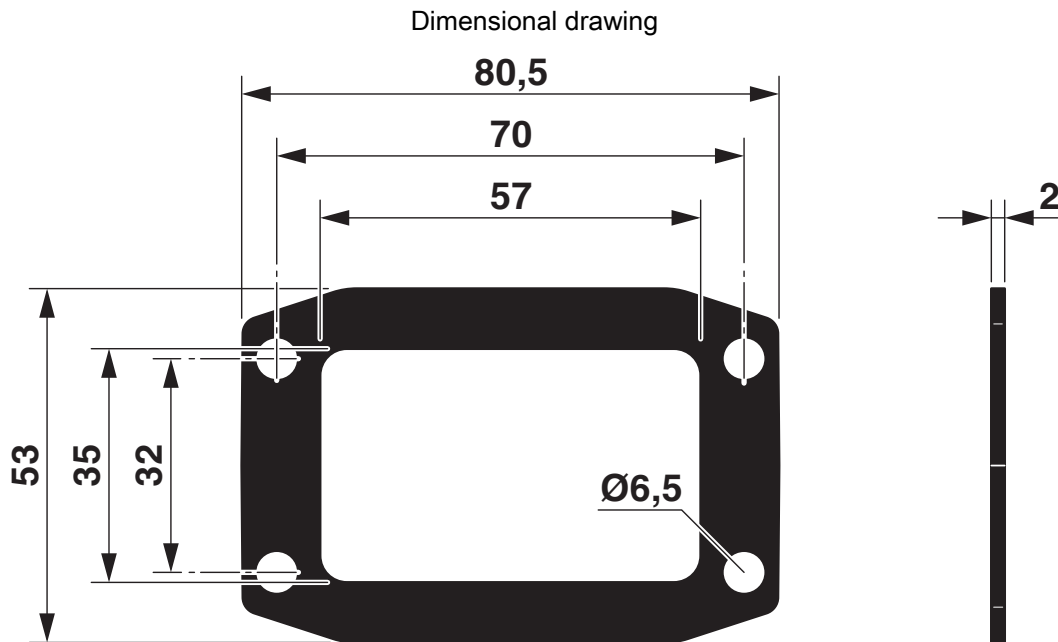

Dimensional drawing

# HC-B06-SG-CBK - Flat gasket



1411483

<https://www.phoenixcontact.com/us/products/1411483>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1411483>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-B06-SG-CBK - Flat gasket



1411483

<https://www.phoenixcontact.com/us/products/1411483>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 23071590 |
| ECLASS-15.0 | 27440292 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC002943 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31401600 |
|-------------|----------|

# HC-B06-SG-CBK - Flat gasket



1411483

<https://www.phoenixcontact.com/us/products/1411483>

## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)