

SAC-3P-500,0-PVC/0,34 - Cable drum



1414074

<https://www.phoenixcontact.com/us/products/1414074>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, 3-pos., PVC, gray, cable drum: 500 m

Commercial data

Item number	1414074
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF11
Product key	AF1LAA
GTIN	4055626014104
Weight per piece (including packing)	20.442 g
Weight per piece (excluding packing)	20.442 g
Customs tariff number	85444995
Country of origin	CN

SAC-3P-500,0-PVC/0,34 - Cable drum

1414074

<https://www.phoenixcontact.com/us/products/1414074>

Technical data

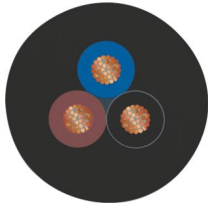
Product properties

Product type	Cable by the meter
--------------	--------------------

Cable/line

Cable length	500 m
--------------	-------

PVC black [PVC]

Dimensional drawing	
Cable weight	40 kg/km
UL AWM Style	2464 / 1729 (80°C/300 V)
Number of positions	3
Shielded	no
Cable type	PVC black [PVC]
Conductor structure signal line	19x 0.15 mm
AWG signal line	22
Conductor cross-section	3x 0.34 mm ² (Signal line)
Wire diameter incl. insulation	1.26 mm ±0.05 mm
External cable diameter	4.30 mm ±0.2 mm
Outer sheath, material	PVC
External sheath, color	black RAL 9005
Conductor material	Bare Cu litz wires
Material wire insulation	PVC
Single wire, color	brown, blue, black
Thickness, insulation	≥ 0.23 mm (Core insulation)
Thickness, outer sheath	≥ 0.76 mm
Overall twist	3 wires, twisted
Max. conductor resistance	max. 57 Ω/km (at 20 °C)
Insulation resistance	≥ 100 MΩ*km (at 20 °C)
Nominal voltage, cable	≤ 300 V
Test voltage	≥ 2500 V
Minimum bending radius, fixed installation	5 x D
Minimum bending radius, flexible installation	10 x D
Smallest bending radius, fixed installation	22 mm
Smallest bending radius, movable installation	43 mm

SAC-3P-500,0-PVC/0,34 - Cable drum



1414074

<https://www.phoenixcontact.com/us/products/1414074>

Flame resistance	As per UL-Style 2464
Ambient temperature (operation)	-25 °C ... 80 °C (cable, fixed installation)
	-10 °C ... 80 °C (Cable, flexible installation)

SAC-3P-500,0-PVC/0,34 - Cable drum



1414074

<https://www.phoenixcontact.com/us/products/1414074>

Classifications

ECLASS

ECLASS-13.0	27061801
ECLASS-15.0	27061801

SAC-3P-500,0-PVC/0,34 - Cable drum



1414074

<https://www.phoenixcontact.com/us/products/1414074>

Environmental product compliance

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com