

HC-STA-D15-HCLWS-PL-BK - Protective cover



1424375

<https://www.phoenixcontact.com/us/products/1424375>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Protective cover D15, with single locking latch, protective cover material: PA, height: 19 mm



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1424375 |
| Packing unit | 1 pc |
| Sales key | BF66 |
| Product key | AF7AZC |
| GTIN | 4055626371153 |
| Weight per piece (including packing) | 32.7 g |
| Weight per piece (excluding packing) | 30.8 g |
| Customs tariff number | 85389099 |
| Country of origin | CN |

HC-STA-D15-HCLWS-PL-BK - Protective cover



1424375


<https://www.phoenixcontact.com/us/products/1424375>

Technical data

Product properties

| | |
|--------------|------------------|
| Product type | Protective cover |
| Housing type | Protective cover |
| Type | D15 |

Dimensions
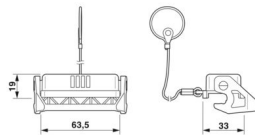
| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 33 mm |
| Height | 19 mm |
| Length | 63.5 mm |

Material specifications

| | |
|--|----|
| Material Protective cover | PA |
| Flammability rating according to UL 94 | V0 |
| Material, protective cover | PA |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP66 |
| Ambient temperature (operation) | -20 °C ... 100 °C |

Mounting

| | |
|---------------|--|
| Assembly note | Plastic protective cover for short-term protection |
|---------------|--|

HC-STA-D15-HCLWS-PL-BK - Protective cover




1424375

<https://www.phoenixcontact.com/us/products/1424375>

Drawings

Dimensional drawing

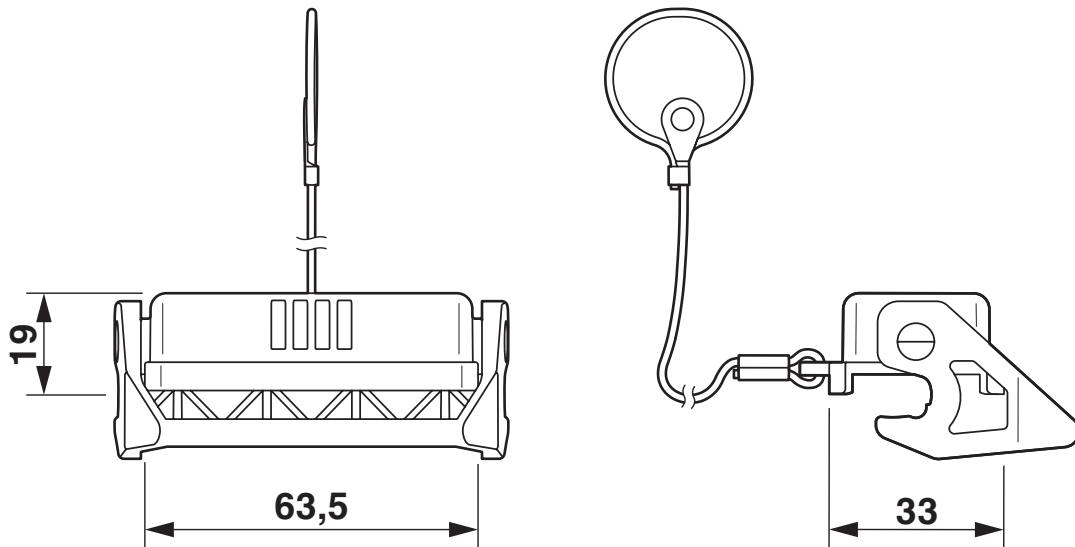

Dimensional drawing

HC-STA-D15-HCLWS-PL-BK - Protective cover



1424375

<https://www.phoenixcontact.com/us/products/1424375>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1424375>

DNV

Approval ID: TAE000037S

HC-STA-D15-HCLWS-PL-BK - Protective cover



1424375

<https://www.phoenixcontact.com/us/products/1424375>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440208 |
| ECLASS-15.0 | 27440208 |

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

HC-STA-D15-HCLWS-PL-BK - Protective cover



1424375

<https://www.phoenixcontact.com/us/products/1424375>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com