

SAC-3P-10,0-534/A-1L-V 230V - Sensor/actuator cable



1453740

<https://www.phoenixcontact.com/us/products/1453740>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Sensor/actuator cable, 3-position, PVC, black, free cable end, on Valve connector A, with 1 LED



Commercial data

Item number	1453740
Packing unit	1 pc
Minimum order quantity	50 pc
Product key	AF1DAA
GTIN	4046356554671
Weight per piece (including packing)	482 g
Weight per piece (excluding packing)	482 g
Country of origin	PL

1453740

<https://www.phoenixcontact.com/us/products/1453740>

Technical data

Product properties

Number of positions	3
---------------------	---

Electrical properties

Nominal voltage U_N	230 V AC
	230 V DC

Connector

Connection 1

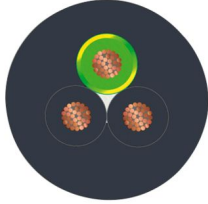
Type	free cable end
------	----------------

Connection 2

Type	Valve connector A
------	-------------------

Cable/line

PVC, 0.75 mm², black [534]

Dimensional drawing	
Cable weight	49.1 kg/km
Number of positions	3
Shielded	no
Cable type	PVC, 0.75 mm ² , black [534]
Conductor structure signal line	24x 0.20 mm
AWG signal line	18
Conductor cross-section	3x 0.75 mm ²
Wire diameter incl. insulation	1.7 mm ±0.1 mm
External cable diameter	5.30 mm ±0.2 mm
Outer sheath, material	PVC
External sheath, color	black
Conductor material	Bare Cu litz wires
Material wire insulation	PVC
Single wire, color	black 1, black 2, green/yellow
Overall twist	3 wires, twisted
Max. conductor resistance	26 Ω/km (at 20 °C)
Insulation resistance	min. 20 MΩ*km (at 20 °C)

SAC-3P-10,0-534/A-1L-V 230V - Sensor/actuator cable



1453740

<https://www.phoenixcontact.com/us/products/1453740>

Nominal voltage, cable	300 V
Test voltage	1200 V
Minimum bending radius, fixed installation	5 x D
Smallest bending radius, fixed installation	27 mm
Flame resistance	DIN VDE 0482
	DIN EN 50265-2-1
	in acc. to UL VW1
Resistance to oil	in accordance with DIN EN 60811-2-1
Ambient temperature (operation)	-40 °C ... 80 °C (cable, fixed installation)
	-5 °C ... 80 °C (Cable, flexible installation)

SAC-3P-10,0-534/A-1L-V 230V - Sensor/actuator cable



1453740

<https://www.phoenixcontact.com/us/products/1453740>

Classifications

ECLASS

ECLASS-13.0	27060312
ECLASS-15.0	27060312

1453740

<https://www.phoenixcontact.com/us/products/1453740>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com