

# VIP-2/SC/D26F UHIO - Termination board



2905715

<https://www.phoenixcontact.com/us/products/2905715>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



VARIOFACE module with screw connection and female D-Subminiature Amplimite 0.050 series connector.

## Your advantages

- Metal foot
- Screw connection

## Commercial data

Item number	2905715
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	C423
Product key	DK2B12
GTIN	4055626000640
Weight per piece (including packing)	118.1 g
Weight per piece (excluding packing)	99.99 g
Customs tariff number	85366990
Country of origin	US

2905715

<https://www.phoenixcontact.com/us/products/2905715>

## Technical data

### Product properties

Product type	Interface module
Product family	VARIOFACE Professional
Number of positions	26

### Electrical properties

Nominal voltage $U_N$	24 V AC/DC
Max. current carrying capacity per branch	500 mA

### Connection data

#### Field level

Connection in acc. with standard	IEC / EN
Connection method	Screw connection
Stripping length	8 mm
Screw thread	M 3
Conductor cross-section rigid	0.2 mm <sup>2</sup> ... 4 mm <sup>2</sup>
Conductor cross-section flexible	0.2 mm <sup>2</sup> ... 2.5 mm <sup>2</sup>
Conductor cross-section AWG	24 ... 12

#### Controller level

Connection method	D-SUB socket strip
Number of connections	1
Number of positions	26

### Signaling

Status display	no
Status display present	no

### Dimensions

#### Item dimensions

Width	49.7 mm
Height	65.5 mm
Depth	45.3 mm

### Material specifications

Color	gray (RAL 7042)
Flammability rating according to UL 94	V0
Housing insulation material	Polyamide PA non-reinforced

### Environmental and real-life conditions

#### Ambient conditions

# VIP-2/SC/D26F UHIO - Termination board



2905715

<https://www.phoenixcontact.com/us/products/2905715>

Ambient temperature (operation)	-20 °C ... 60 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

## Mounting

Mounting type	DIN rail mounting
Mounting position	any

## Notes

Notes on operation	For proper use, the specifications of the installation directive (see Downloads) must be observed. For applications or use with third-party products, the specifications, and the safety and warning instructions of the respective third-party manufacturer must also be met.
--------------------	--

# VIP-2/SC/D26F UHIO - Termination board




2905715

<https://www.phoenixcontact.com/us/products/2905715>

## Drawings

Circuit diagram

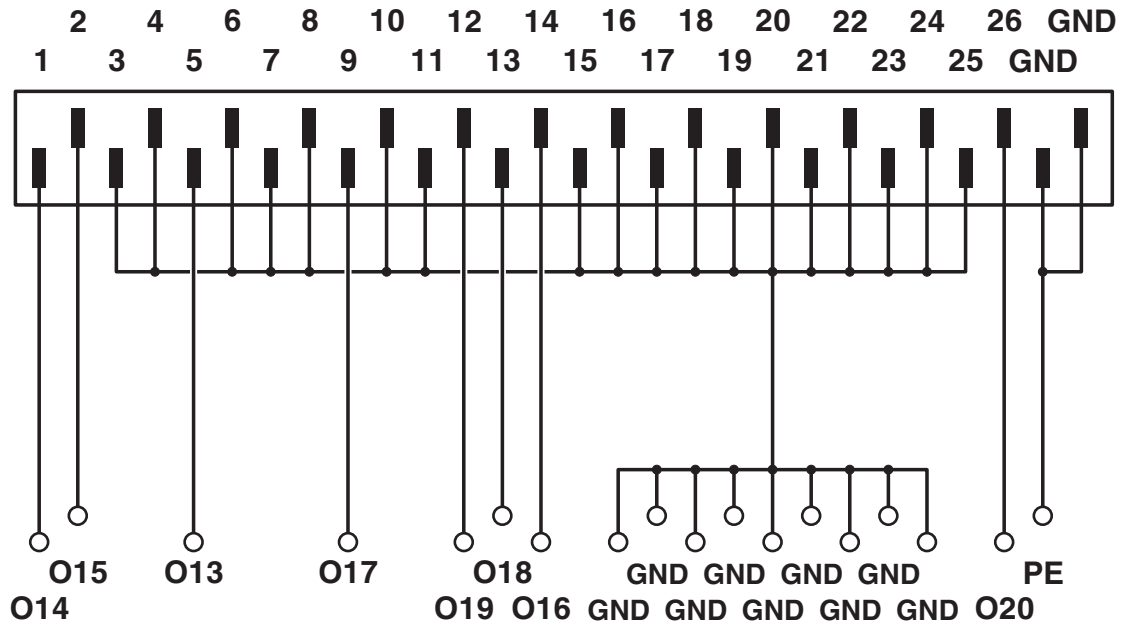

# VIP-2/SC/D26F UHIO - Termination board



2905715

<https://www.phoenixcontact.com/us/products/2905715>

## Classifications

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

2905715

<https://www.phoenixcontact.com/us/products/2905715>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)