

A/U CM - Cover profile

5021110

<https://www.phoenixcontact.com/us/products/5021110>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



U profile cover, for covering terminal strips, internal dimensions: 100 x 40 mm, 2 mm thick, produced according to length specifications, additionally required: 2 E/UK end brackets or E/U end clips and 2 VAH cover brackets, maximum supply length: 1.6 m

Your advantages

- Large-surface labeling with AP-ES insert strips
- Cover profiles provide protection against unauthorized actuation of terminal strips

Commercial data

Item number	5021110
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	BE07
Product key	BH8412
Weight per piece (including packing)	865 g
Weight per piece (excluding packing)	865 g
Customs tariff number	39162000
Country of origin	DE

A/U CM - Cover profile

5021110


<https://www.phoenixcontact.com/us/products/5021110>

Technical data

Product properties

Product type	Cover profile
--------------	---------------

Dimensions

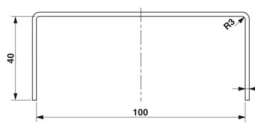Dimensional drawing	
Width	100 mm
Height	42 mm
Material strength	2.00 mm

Material specifications

Color	transparent
Material	Polycarbonate PC
Flammability rating according to UL 94	HB

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 115 °C
---------------------------------	-------------------


A/U CM - Cover profile

5021110

<https://www.phoenixcontact.com/us/products/5021110>

Drawings

Dimensional drawing

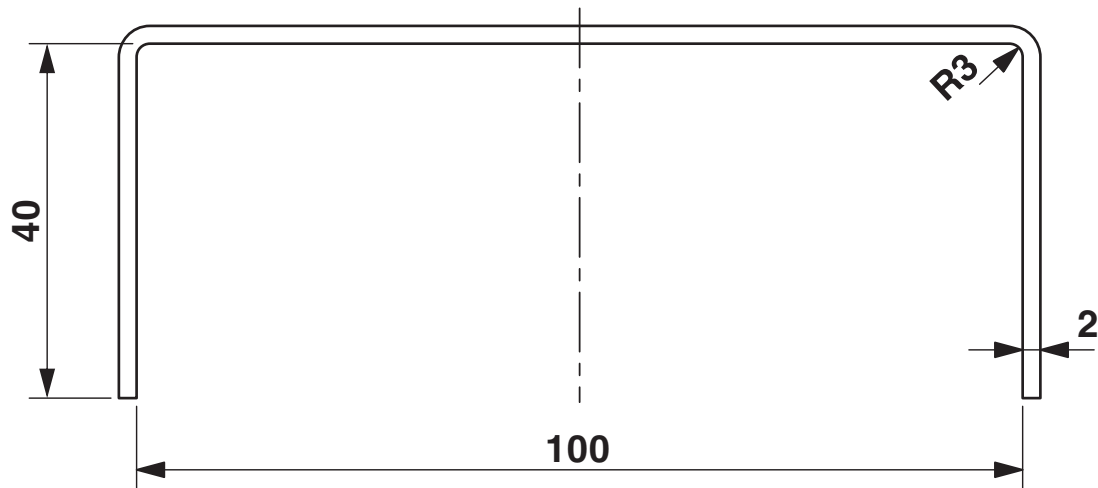

A/U CM - Cover profile



5021110

<https://www.phoenixcontact.com/us/products/5021110>

Classifications

ECLASS

ECLASS-15.0	27141190
ECLASS-13.0	27141190

ETIM

ETIM 10.0	EC002848
-----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

A/U CM - Cover profile



5021110

<https://www.phoenixcontact.com/us/products/5021110>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com