

Patch cable - NBC-R4AC1/0,3-94G/R4AC1-RD - 1421138


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Patch cable, degree of protection: IP20, cable length: 0.3 m, number of positions: 8, 10 Gbps, CAT6_A

RoHS

Key Commercial Data

Packing unit	1 pc
GTIN	 4 0 5 5 6 2 6 2 5 4 6 9 2
GTIN	4055626254692

Technical data

Dimensions

Length of cable	0.30 m
-----------------	--------

Ambient conditions

Ambient temperature (operation)	-25 °C ... 60 °C (RJ45 connector)
	-25 °C ... 75 °C (cable)

General data

Rated current at 40°C	0.5 A
Rated voltage	48 V
Number of positions	8
Rated voltage (III/3)	72 V (DC)

Standards and Regulations

Flame resistance	IEC 60332-1
------------------	-------------


Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings


Patch cable - NBC-R4AC1/0,3-94G/R4AC1-RD - 1421138

Schematic diagram

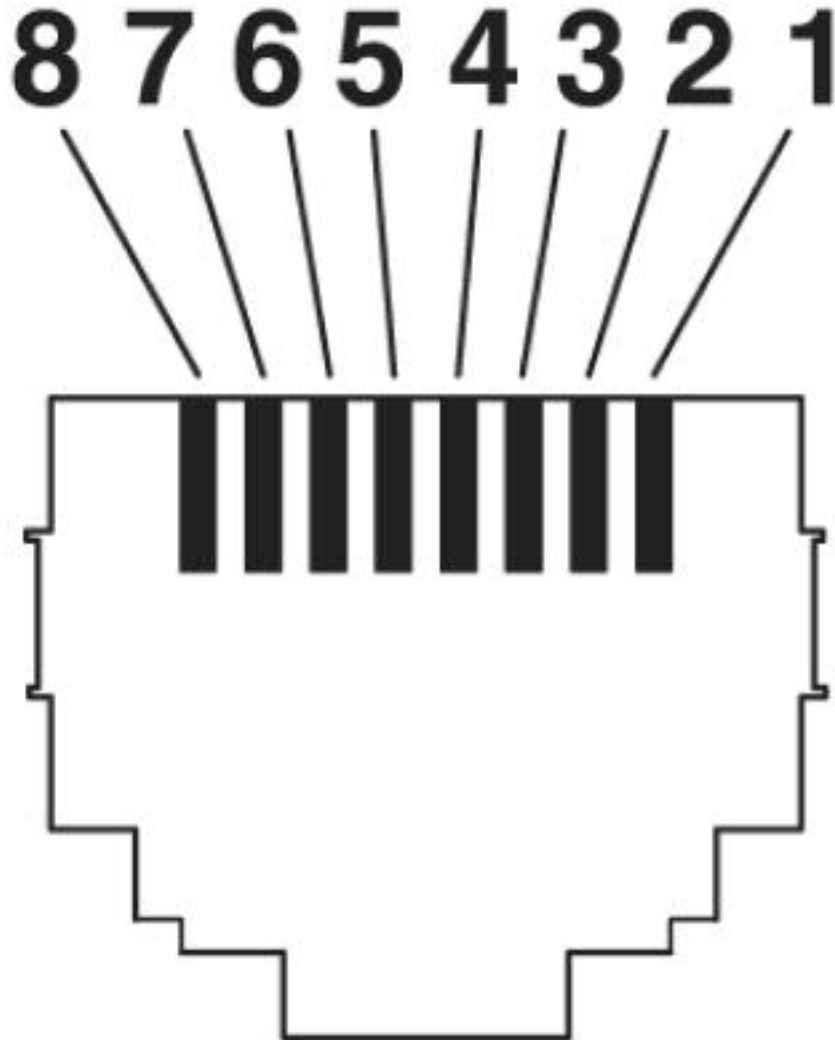

Connector pin assignment plug RJ45

Dimensional drawing

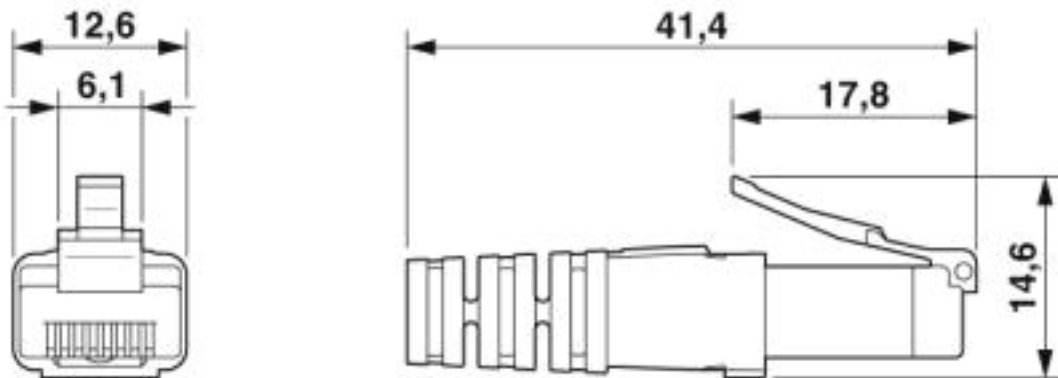

Patch cable - NBC-R4AC1/0,3-94G/R4AC1-RD - 1421138

Approvals


Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		B.00767
-----	---	---------

Phoenix Contact 2019 © - all rights reserved
<http://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachsmarktstr. 8
32825 Blomberg
Germany
Tel. +49 5235 300
Fax +49 5235 3 41200
<http://www.phoenixcontact.com>