


# ZB 4/YE CUS - Zack marker strip



0824959

<https://www.phoenixcontact.com/us/products/0824959>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

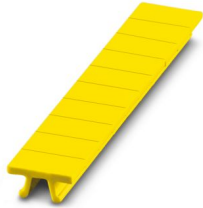

Zack marker strip, can be ordered: Strip, yellow (RAL 1018), labeled according to customer specifications, mounting type: snap into tall marker groove, for terminal block width: 4.2 mm, Number of individual labels: 10

## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 0824959                        |
| Packing unit                         | 1 pc                           |
| Minimum order quantity               | 1 pc                           |
| Note                                 | Made to order (non-returnable) |
| Product key                          | BG8112                         |
| GTIN                                 | 4046356357258                  |
| Weight per piece (including packing) | 1.12 g                         |
| Weight per piece (excluding packing) | 0.964 g                        |
| Country of origin                    | PL                             |

# ZB 4/YE CUS - Zack marker strip



0824959

<https://www.phoenixcontact.com/us/products/0824959>

## Technical data

### Product properties

|              |                 |
|--------------|-----------------|
| Product type | Terminal marker |
| Pitch        | 4.2 mm          |

### Marking

|                                     |      |
|-------------------------------------|------|
| Number of individual labels         | 10   |
| Number of individual labels per row | 10   |
| Number of marker strips             | 10   |
| Slot type                           | high |

### Dimensions

|        |          |
|--------|----------|
| Width  | 4.15 mm  |
| Height | 10.50 mm |
| Depth  | 4.20 mm  |
| Pitch  | 4.2 mm   |

### Material specifications

|  |                                |
|--|--------------------------------|
| Color                                  | yellow (RAL 1018)              |
| Material                               | PA                             |
| Flammability rating according to UL 94 | V2                             |
| Components                             | free from silicone and halogen |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 100 °C |
|---------------------------------|-------------------|

### Standards and regulations

|                 |                             |
|-----------------|-----------------------------|
| Wipe resistance | DIN EN 61010-1 (VDE 0411-1) |
|-----------------|-----------------------------|

### Mounting

|               |                              |
|---------------|------------------------------|
| Mounting type | snap into tall marker groove |
|---------------|------------------------------|

# ZB 4/YE CUS - Zack marker strip

0824959

<https://www.phoenixcontact.com/us/products/0824959>

## Drawings

Schematic diagram



- ① Horizontal
- ② Vertical

# ZB 4/YE CUS - Zack marker strip

0824959

<https://www.phoenixcontact.com/us/products/0824959>



## Classifications

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39131500 |
|-------------|----------|

# ZB 4/YE CUS - Zack marker strip



0824959

<https://www.phoenixcontact.com/us/products/0824959>

## Environmental product compliance

### EU RoHS

|   |                    |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)