

C PX A 405X305X202 - Empty enclosure



0899333

<https://www.phoenixcontact.com/us/products/0899333>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Empty enclosure, material: Glass-fiber-reinforced polyester with added graphite, black, 305 mm x 405 mm x 202 mm, type of locking: Door, scope of supply - ATD: Door hinge with 8 mm square lock, Door hinge with 8 mm square lock

The figure shows a similar product

Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 0899333 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | BH91 |
| Product key | BH9142 |
| GTIN | 4055626276021 |
| Weight per piece (including packing) | 99.99 g |
| Weight per piece (excluding packing) | 99.99 g |
| Customs tariff number | 85389099 |
| Country of origin | HU |

C PX A 405X305X202 - Empty enclosure

0899333

<https://www.phoenixcontact.com/us/products/0899333>

Technical data

Notes

| | |
|---------|-------------------------|
| General | Mounting panel required |
|---------|-------------------------|

Product properties

| | |
|-----------------|----------------------------------|
| Product type | Terminal box |
| Type | Ex empty enclosure with door |
| Scope of supply | Door hinge with 8 mm square lock |

Insulation characteristics

| | |
|------------------|----|
| Protection class | II |
|------------------|----|

Dimensions

| | |
|--|---|
| Dimensional drawing |  |
| Width | 305 mm |
| Height | 405 mm |
| Depth | 202 mm |
| Clearance width, maximum DIN rail length | 365 mm |
| max. assembly length | 345 mm |

Material specifications

| | |
|--|--|
| Color | black |
| Material | Glass-fiber-reinforced polyester with added graphite |
| Flammability rating according to UL 94 | V0 |
| Seal material | Silicon |
| Components | halogen-free |

Mechanical properties

General

| | |
|-----------------------|------------------|
| Type of locking (GRP) | Door Square lock |
|-----------------------|------------------|

Environmental and real-life conditions

Degree of protection (IP code)

| | |
|----------------------|------|
| Degree of protection | IP66 |
|----------------------|------|

Ambient conditions

| | |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -55 °C ... 127 °C |
|---------------------------------|-------------------|

C PX A 405X305X202 - Empty enclosure



0899333

<https://www.phoenixcontact.com/us/products/0899333>

Mounting

| | |
|--------------------------|---|
| Assembly note | External fixing clips |
| | External fixing clip not supplied as standard |
| Direct DIN rail mounting | no |
| Useable DIN rail type | NS 35 |

C PX A 405X305X202 - Empty enclosure




0899333


<https://www.phoenixcontact.com/us/products/0899333>

Drawings

Dimensional drawing

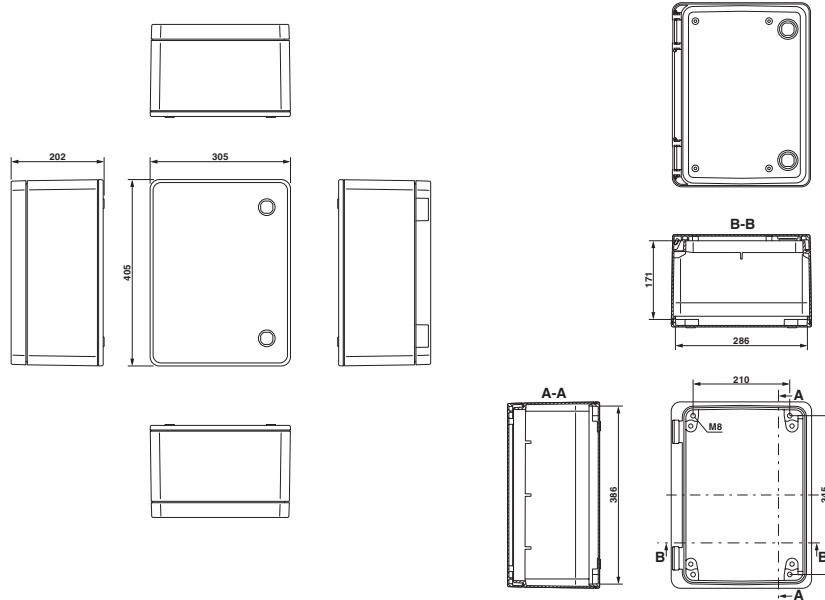

Schematic diagram

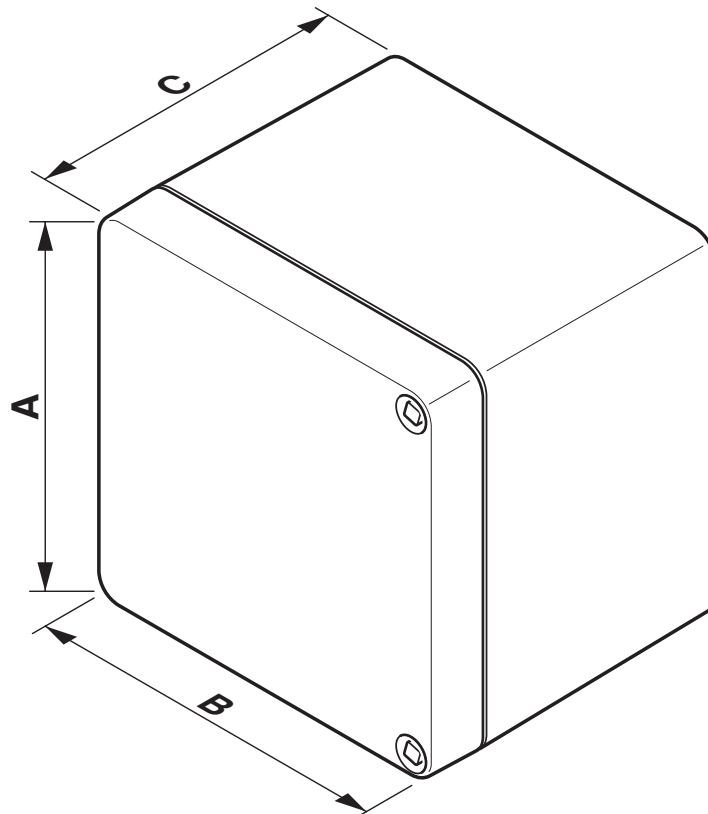

C PX A 405X305X202 - Empty enclosure



0899333

<https://www.phoenixcontact.com/us/products/0899333>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27180101 |
| ECLASS-15.0 | 27180101 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC000261 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

C PX A 405X305X202 - Empty enclosure



0899333

<https://www.phoenixcontact.com/us/products/0899333>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com