

# HC-B24/10-ADP-SS - Adapter plate



1034213

<https://www.phoenixcontact.com/us/products/1034213>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Adapter plate, design: B24 to B10



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1034213       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BF66          |
| Product key                          | AF7AZD        |
| GTIN                                 | 4055626539690 |
| Weight per piece (including packing) | 121 g         |
| Weight per piece (excluding packing) | 120 g         |
| Customs tariff number                | 39269097      |
| Country of origin                    | DE            |

# HC-B24/10-ADP-SS - Adapter plate

1034213

<https://www.phoenixcontact.com/us/products/1034213>



## Technical data

### Notes

|         |                              |
|---------|------------------------------|
| General | For wall cutouts of type B24 |
|---------|------------------------------|

### Product properties

|              |               |
|--------------|---------------|
| Product type | Adapter plate |
| Type         | B24           |
| Seal present | yes           |

### Dimensions

|                                 |        |
|---------------------------------|--------|
| Dimensional drawing             |        |
| Width                           | 53 mm  |
| Height                          | 5 mm   |
| Length                          | 151 mm |
| Drill hole distance, horizontal | 130 mm |
| Drill hole distance, vertical   | 32 mm  |
| Hole diameter                   | 5.5 mm |

### Material specifications

|               |                                 |
|---------------|---------------------------------|
| Material      | Stainless steel 1.4301/AISI 304 |
| Seal material | NBR/SBR                         |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection            | IP54              |
|                                 | IP65              |
| Ambient temperature (operation) | -40 °C ... 125 °C |

### Mounting

|               |                                          |
|---------------|------------------------------------------|
| Assembly note | Torque of the mounting screws 1 ... 2 Nm |
|---------------|------------------------------------------|

# HC-B24/10-ADP-SS - Adapter plate


1034213

<https://www.phoenixcontact.com/us/products/1034213>



## Drawings

Dimensional drawing

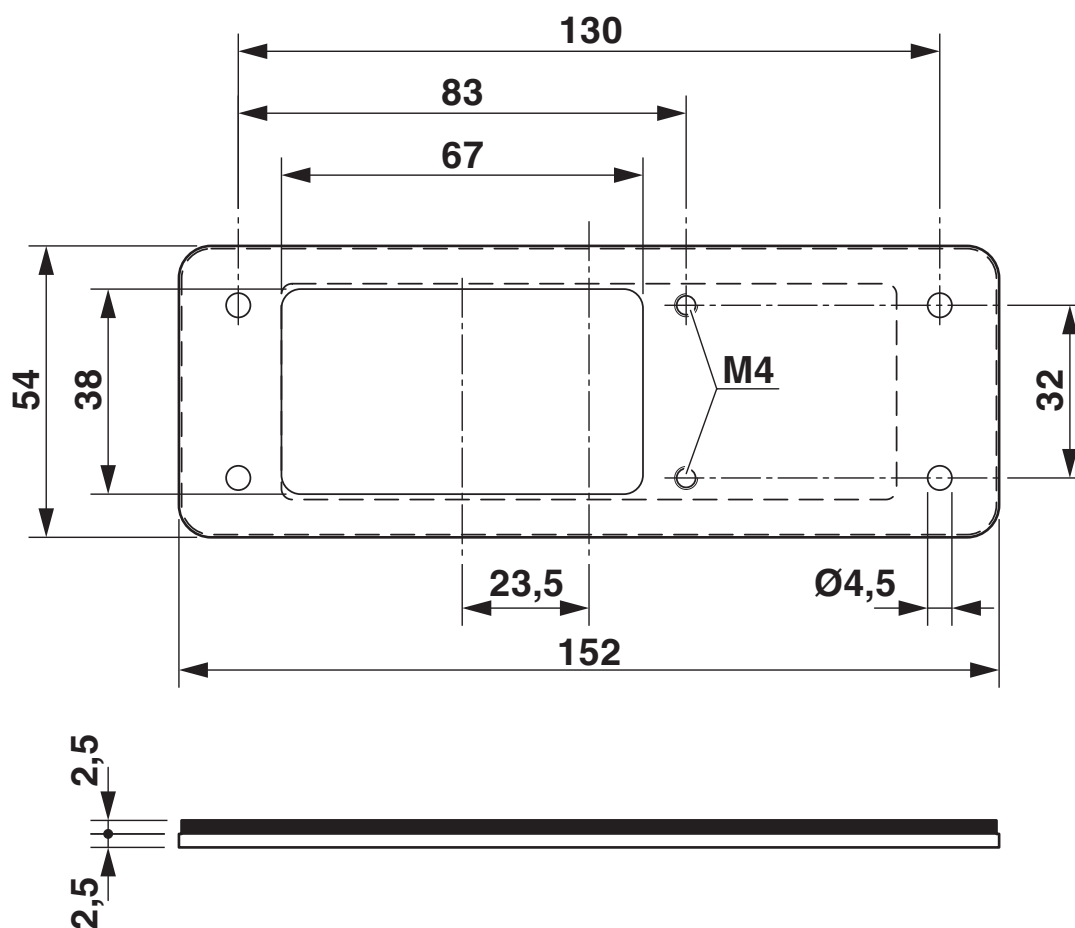

Dimensional drawing

# HC-B24/10-ADP-SS - Adapter plate



1034213

<https://www.phoenixcontact.com/us/products/1034213>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC002309 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-B24/10-ADP-SS - Adapter plate



1034213

<https://www.phoenixcontact.com/us/products/1034213>

## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |
| EF3.1 Climate Change                    |                                          |
| CO2e kg                                 | 2.338 kg CO2e                            |

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)