

CASE KNX L-BOXX MINI DE - Starter kit



1180883

<https://www.phoenixcontact.com/us/products/1180883>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Starter kit, KNX starter set in a practical Sortimo L-BOXX Mini system case. 56 double-level terminal blocks for KNX bus in building installation, cross section: 0.14 mm² to 1.5 mm², 4 end covers, 12 plug-in bridges, marking material, and accessories, color: black

Commercial data

Item number	1180883
Packing unit	1 pc
Minimum order quantity	1 pc
Product key	BE2251
GTIN	4063151216856
Weight per piece (including packing)	883.4 g
Weight per piece (excluding packing)	883.4 g
Country of origin	PL

CASE KNX L-BOXX MINI DE - Starter kit

1180883

<https://www.phoenixcontact.com/us/products/1180883>

Set consists of

PTTBS 1,5/S-KNX - Double-level terminal block

3214663

<https://www.phoenixcontact.com/us/products/3214663>



Double-level terminal block, for KNX bus in building installation, packed in pairs (25 pairs = 50 pcs.), nom. voltage: 500 V, nominal current: 16 A, connection method: Push-in connection, 1st and 2nd level, Rated cross section: 1.5 mm², cross section: 0.14 mm² - 1.5 mm², mounting type: NS 35/7,5, NS 35/15, color: white

D-PTTBS 1,5/S-KNX - End cover

3214664

<https://www.phoenixcontact.com/us/products/3214664>



End cover, depth: 40.5 mm, width: 2.2 mm, height: 78.6 mm, color: white

CASE KNX L-BOXX MINI DE - Starter kit



1180883

<https://www.phoenixcontact.com/us/products/1180883>

FBS 20-3,5 - Plug-in bridge

3213069

<https://www.phoenixcontact.com/us/products/3213069>



Plug-in bridge, pitch: 3.5 mm, number of positions: 20, nominal current: 17.5 A, color: red

FBS 5-3,5 - Plug-in bridge

3213043

<https://www.phoenixcontact.com/us/products/3213043>



Plug-in bridge, pitch: 3.5 mm, number of positions: 5, nominal current: 17.5 A, color: red

CASE KNX L-BOXX MINI DE - Starter kit




1180883

<https://www.phoenixcontact.com/us/products/1180883>

ZB 3,5,QR:FORT.ZAHLEN - Zack marker strip

0801405

<https://www.phoenixcontact.com/us/products/0801405>

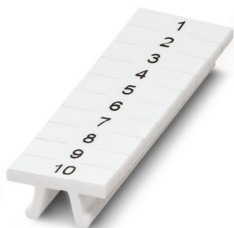

Zack marker strip, Strip, white (RAL 9010), labeled, Printed vertically: consecutive numbers 1 ... 10, 11 ... 20, etc. up to 91 ... 100, mounting type: latching, for terminal block width: 3.5 mm, Number of individual labels: 10, text field height: 10.5 mm, text field width: 3.5 mm

B-STIFT - Marker pen

1051993

<https://www.phoenixcontact.com/us/products/1051993>



Marker pen, for manual labeling of unprinted Zack strips, smear-proof and waterproof, line thickness 0.5 mm

CASE KNX L-BOXX MINI DE - Starter kit


1180883

<https://www.phoenixcontact.com/us/products/1180883>

PTFIX 1,5-KNX-NS35 - Function distribution block

1187192

<https://www.phoenixcontact.com/us/products/1187192>

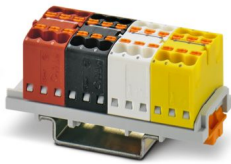

Function distribution block, for KNX bus in building installation, individual block is bridged internally, color in accordance with EIB cable coding, arrangement: inline, nom. voltage: 500 V, nominal current: 17.5 A, number of connections: 24, connection method: Push-in connection, cross section: 0.14 mm² - 2.5 mm², mounting type: NS 15, NS 35/7,5, NS 35/15

PTFIX 1,5-KNX-NS35AD - Function distribution block

1187193

<https://www.phoenixcontact.com/us/products/1187193>



Function distribution block, for KNX bus in building installation, individual block is bridged internally, color in accordance with EIB cable coding, arrangement: in pairs, nom. voltage: 500 V, nominal current: 17.5 A, number of connections: 24, connection method: Push-in connection, cross section: 0.14 mm² - 2.5 mm², mounting type: NS 35/7,5, NS 35/15

CASE KNX L-BOXX MINI DE - Starter kit



1180883

<https://www.phoenixcontact.com/us/products/1180883>

Technical data

Product properties

Product type	Feed-through terminal block
--------------	-----------------------------

Dimensions

Width	260 mm
Height	156 mm
Depth	63 mm

Material specifications

Color	black (RAL 9005)
-------	------------------

CASE KNX L-BOXX MINI DE - Starter kit



1180883

<https://www.phoenixcontact.com/us/products/1180883>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1180883>



EAC

Approval ID: KZ7500651131219505

CASE KNX L-BOXX MINI DE - Starter kit



1180883

<https://www.phoenixcontact.com/us/products/1180883>

Classifications

ECLASS

ECLASS-13.0	27141190
ECLASS-15.0	27141190

ETIM

ETIM 10.0	EC002848
-----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

CASE KNX L-BOXX MINI DE - Starter kit



1180883

<https://www.phoenixcontact.com/us/products/1180883>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Not applicable, No electrical and electronic equipment (EEE), cannot be used in EEE
---	---

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com