

CRIMPFOX 6T-F - Crimping pliers



1212038

<https://www.phoenixcontact.com/us/products/1212038>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Crimping pliers, for ferrules without insulating collar according to DIN 46228 Part 1 and ferrules with insulating collar according to DIN 46228 Part 4, 0.25 mm² ... 6 mm², front entry, trapezoidal crimp

Your advantages

- All ferrules can be optimally crimped with a minimum amount of effort even in the case of large conductor cross-sections
- Unlockable pressure lock
- Comprehensive range of crimping pliers
- Consistently high crimping quality
- Marked die stations for precise processing of corresponding cross sections

Commercial data

| | |
|--------------------------------------|--------------------------------|
| Item number | 1212038 |
| Packing unit | 1 pc |
| Note | Made to order (non-returnable) |
| Sales key | BH31 |
| Product key | BH3131 |
| GTIN | 4046356454032 |
| Weight per piece (including packing) | 548.1 g |
| Weight per piece (excluding packing) | 548.1 g |
| Customs tariff number | 82032000 |
| Country of origin | SE |

CRIMPFOX 6T-F - Crimping pliers



1212038

<https://www.phoenixcontact.com/us/products/1212038>

Technical data

Notes

Environmental Product Compliance

California Proposition 65

Further information on California's prop. 65 is available under "Downloads" in the manufacturer's declaration

Product properties

Product type

Crimping tool

Compression

Trapezoidal crimp

Crimping position 1

Min. cross section

0.25 mm²

Max. cross section

6 mm²

AWG min

24

AWG max

10

Connection data

Conductor connection

Cross section range, metric

0.25 mm² ... 6 mm²

Cross section range AWG

24 ... 10

Dimensions

Width

22.5 mm

Height

72 mm

Length

220 mm

Material specifications

Color

black

CRIMPFOX 6T-F - Crimping pliers


1212038

<https://www.phoenixcontact.com/us/products/1212038>



Drawings

Product drawing

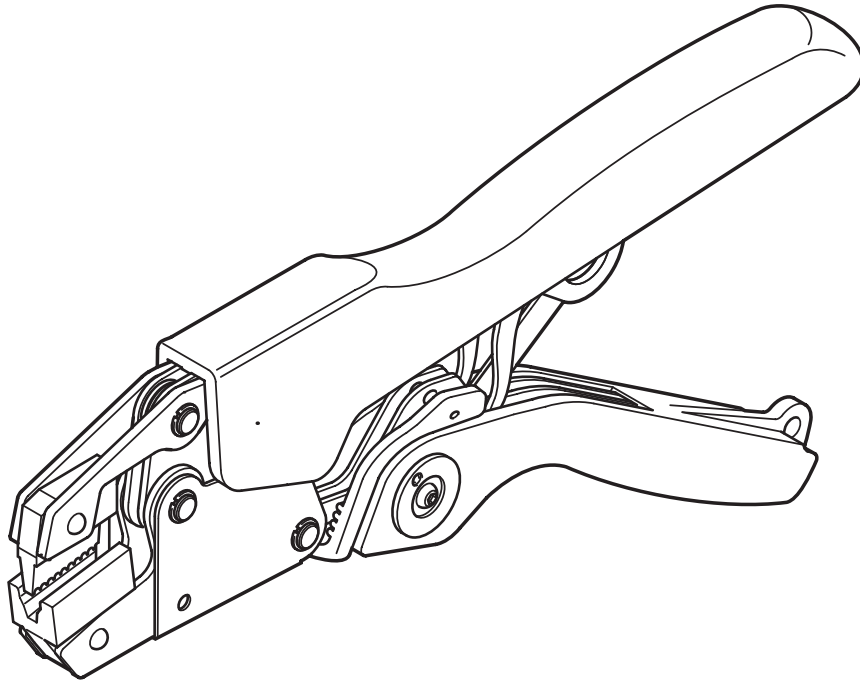

CRIMPFOX 6T-F - Crimping pliers



1212038

<https://www.phoenixcontact.com/us/products/1212038>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1212038>



EAC

Approval ID: RU x-DE.xx08.B.02974

CRIMPFOX 6T-F - Crimping pliers

1212038

<https://www.phoenixcontact.com/us/products/1212038>



Classifications

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 27111518 |
|-------------|----------|

CRIMPFOX 6T-F - Crimping pliers



1212038

<https://www.phoenixcontact.com/us/products/1212038>

Environmental product compliance

EU RoHS

| | |
|---|---|
| Fulfills EU RoHS substance requirements | Not applicable, No electrical and electronic equipment (EEE), cannot be used in EEE |
|---|---|

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com