

# CRIMPFOX 6 CUS - Crimping pliers



1212767

<https://www.phoenixcontact.com/us/products/1212767>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



**Crimping pliers**, laser marked according to customer specifications, for ferrules according to DIN 46228 Parts 1+4, 0.25 mm<sup>2</sup> ... 6.0 mm<sup>2</sup>, lateral entry, trapezoidal crimp

## Your advantages

- All ferrules can be optimally crimped with a minimum amount of effort even in the case of large conductor cross-sections
- Unlockable pressure lock
- Comprehensive range of crimping pliers
- Consistently high crimping quality
- Marked die stations for precise processing of corresponding cross sections

## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 1212767                        |
| Packing unit                         | 1 pc                           |
| Minimum order quantity               | 1 pc                           |
| Note                                 | Made to order (non-returnable) |
| Product key                          | BH313V                         |
| GTIN                                 | 4046356942942                  |
| Weight per piece (including packing) | 442.8 g                        |
| Weight per piece (excluding packing) | 441.2 g                        |
| Country of origin                    | SE                             |

# CRIMPFOX 6 CUS - Crimping pliers



1212767

<https://www.phoenixcontact.com/us/products/1212767>

## Technical data

### Notes

#### Environmental Product Compliance

California Proposition 65

Further information on California's prop. 65 is available under "Downloads" in the manufacturer's declaration

### Product properties

Product type

Crimping tool

Compression

Trapezoidal crimp

### Connection data

#### Conductor connection

Cross section range, metric

0.25 mm<sup>2</sup> ... 6 mm<sup>2</sup>

Cross section range AWG

24 ... 10

### Dimensions

Width

18 mm

Height

59 mm

Length

198 mm

### Material specifications

Color

black

# CRIMPFOX 6 CUS - Crimping pliers




1212767

<https://www.phoenixcontact.com/us/products/1212767>

## Drawings

Product drawing

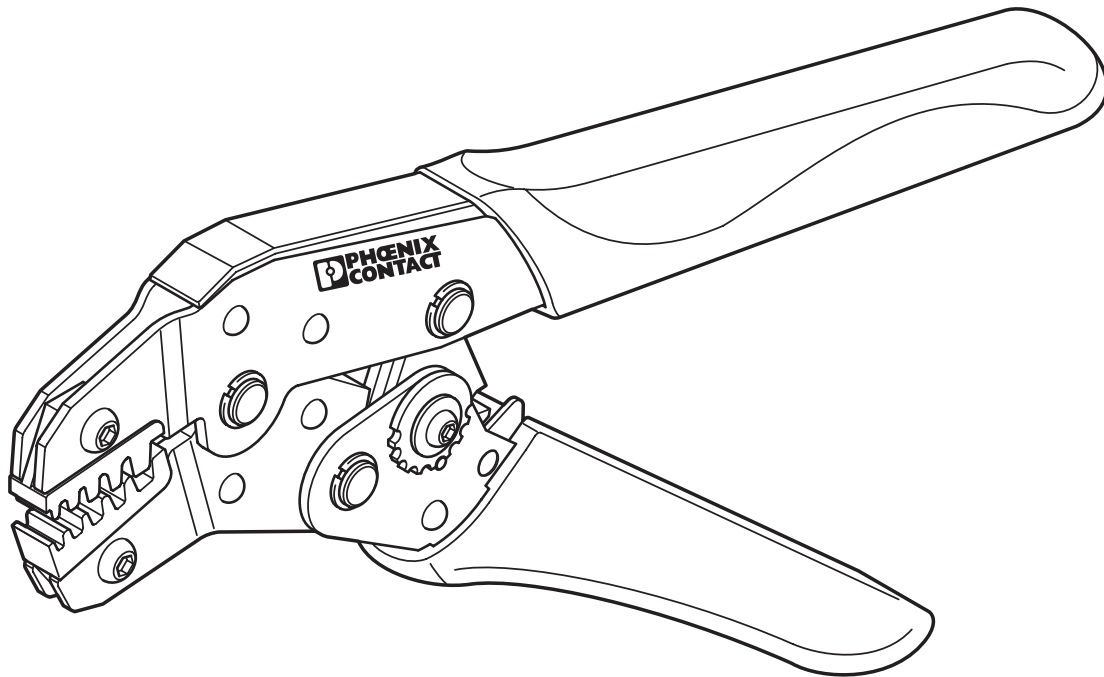

# CRIMPFOX 6 CUS - Crimping pliers



1212767

<https://www.phoenixcontact.com/us/products/1212767>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1212767>



**EAC**

Approval ID: RU x-DE.xx08.B.02974

# CRIMPFOX 6 CUS - Crimping pliers



1212767

<https://www.phoenixcontact.com/us/products/1212767>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 21043811 |
| ECLASS-15.0 | 21043811 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC000168 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 27111500 |
|-------------|----------|

# CRIMPFOX 6 CUS - Crimping pliers



1212767

<https://www.phoenixcontact.com/us/products/1212767>

## Environmental product compliance

### EU RoHS

|   |   |
|---|---|
| Fulfills EU RoHS substance requirements | Not applicable, No electrical and electronic equipment (EEE), cannot be used in EEE |
|---|---|

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)