

HC-STA-B10-HLFS-1STM20-EL/... - Housing



1372749

<https://www.phoenixcontact.com/us/products/1372749>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B10, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, 1x M20, height: 57 mm, cable gland: none

Commercial data

Item number	1372749
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	BF71
Product key	AF7APB
Weight per piece (including packing)	156.9 g
Weight per piece (excluding packing)	156.725 g
Customs tariff number	85389099
Country of origin	PL

HC-STA-B10-HLFS-1STM20-EL/... - Housing



1372749

<https://www.phoenixcontact.com/us/products/1372749>

Technical data

 
Notes

General	for contact inserts HC-B10, BB18, DD42, M, K8/24, HV03
---------	--

Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Application	Standard
Design	B10
Type of locking	for single locking latch
No. of cable outlets	1
Type of the screw connection	1x M20
Cable outlet	lateral

Dimensions

Dimensional drawing	
Width	44 mm
Height	57 mm
Length	73 mm

Material specifications

Color	black (RAL 9005)
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
	IP67
Enclosure rating (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Impact strength	IK08
Ambient temperature (operation)	-40 °C ... 125 °C

HC-STA-B10-HLFS-1STM20-EL/... - Housing


1372749

<https://www.phoenixcontact.com/us/products/1372749>



Drawings

Dimensional drawing

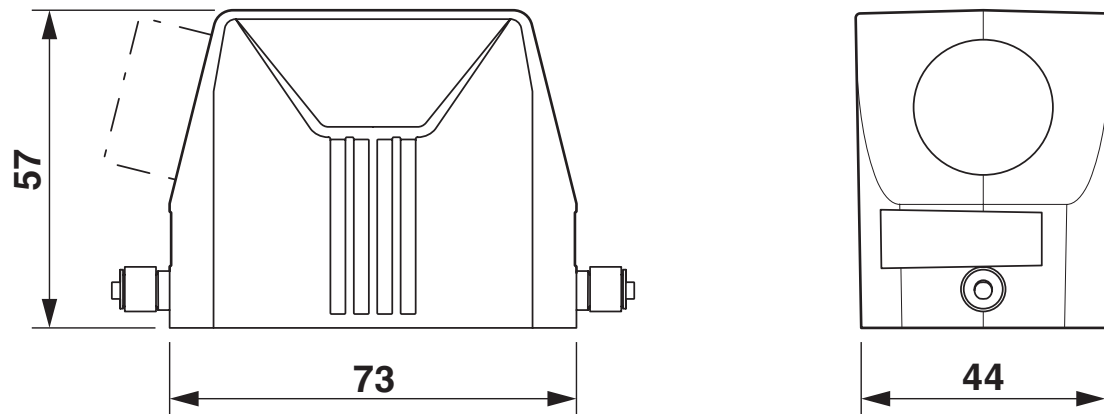

Dimensional drawing

Application drawing



YE – RAL 1021



WH – RAL 9016



RD – RAL 3020



VT – RAL 4004



GY – RAL 7045



GN – RAL 6005



PL – RAL 4006



BN – RAL 8017



BK – RAL 9005



OG – RAL 2004



BU – RAL 5005

HC-STA-B10-HLFS-1STM20-EL/... - Housing



1372749

<https://www.phoenixcontact.com/us/products/1372749>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1372749>



cUL Recognized
Approval ID: E255026



UL Recognized
Approval ID: E255026

1372749

<https://www.phoenixcontact.com/us/products/1372749>

Classifications

ECLASS

ECLASS-13.0	27440202
ECLASS-15.0	27440202

ETIM

ETIM 10.0	EC000437
-----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

1372749

<https://www.phoenixcontact.com/us/products/1372749>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com