

VS-08-BU-RJ45-5/BU - RJ45 jack insert



1402606

<https://www.phoenixcontact.com/us/products/1402606>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



RJ45 jack insert, degree of protection: IP20, number of positions: 8, material: Fiberglass, PBT, connection method: Female

Commercial data

Item number	1402606
Packing unit	5 pc
Minimum order quantity	1 pc
Product key	ABNMAY
GTIN	4046356624688
Weight per piece (including packing)	13.87 g
Weight per piece (excluding packing)	13.87 g
Country of origin	DE

1402606

<https://www.phoenixcontact.com/us/products/1402606>

Technical data

Product properties

Product type	Female insert
Number of positions	8
Number of slots	1
Shielded	yes

Insulation characteristics

Overvoltage category	II
Degree of pollution	2

Electrical properties

Rated voltage (III/3)	150 V
Rated current	1.5 A
Contact resistance	20 mΩ
Insulation resistance	500 MΩ
Transmission characteristics (category)	CAT5 (IEC 11801:2002)

Connection data

Connection technology

Connection method	Female
-------------------	--------

Material specifications

Flammability rating according to UL 94	V0
Housing material	Fiberglass, PBT
Contact material	Phosphor bronze
Contact surface material	Gold over nickel

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP20
----------------------	------

VS-08-BU-RJ45-5/BU - RJ45 jack insert




1402606

<https://www.phoenixcontact.com/us/products/1402606>

Drawings

Dimensional drawing

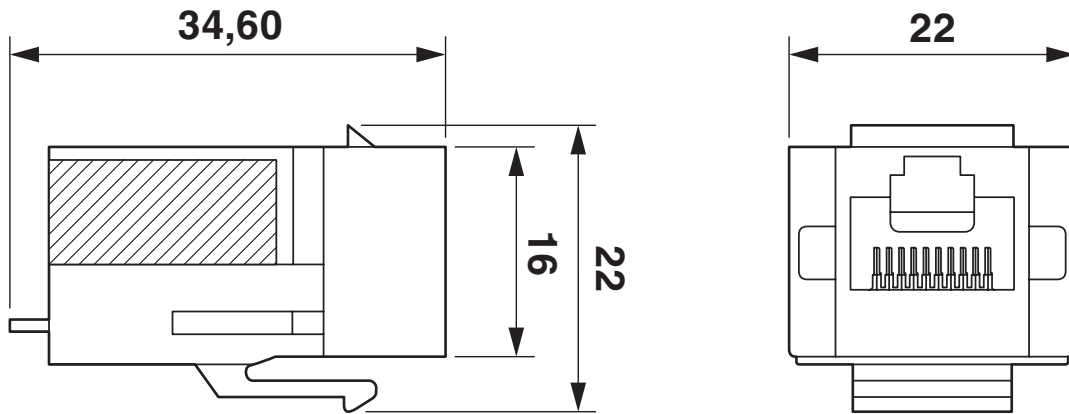

RJ45 socket insert, keystone


VS-08-BU-RJ45-5/BU - RJ45 jack insert

1402606

<https://www.phoenixcontact.com/us/products/1402606>



Schematic diagram

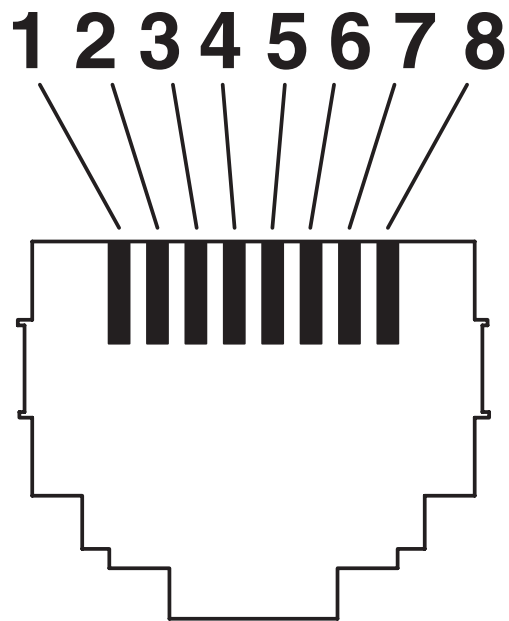


VS-08-BU-RJ45-5/BU - RJ45 jack insert



1402606

<https://www.phoenixcontact.com/us/products/1402606>

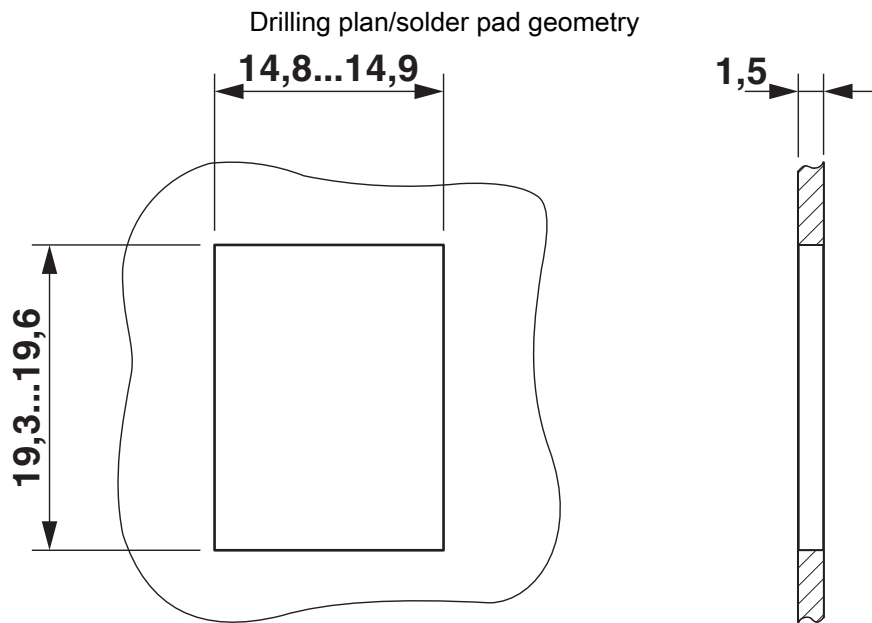

Panel cutout

1402606

<https://www.phoenixcontact.com/us/products/1402606>

Environmental product compliance

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com