

HC-ADV-B24-HHWH-1TGM32-PL - Housing



1404235

<https://www.phoenixcontact.com/us/products/1404235>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B24, with screw locking, material: PA, cable outlets: 1, straight, M32, height: 95 mm, cable gland: with, Standard

Your advantages

- Integrated screw connection
- Lower costs than metal version
- Low weight
- Lower risk of condensation

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1404235 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF58 |
| Product key | AF7APG |
| GTIN | 4046356682060 |
| Weight per piece (including packing) | 201.1 g |
| Weight per piece (excluding packing) | 187.9 g |
| Customs tariff number | 85389099 |
| Country of origin | DE |

HC-ADV-B24-HHWH-1TGM32-PL - Housing

1404235

<https://www.phoenixcontact.com/us/products/1404235>

Technical data


Product properties

| | |
|------------------------------|-----------------------------------|
| Product type | Housing with screw locking |
| Housing type | Sleeve housing |
| Application | Standard |
| Type | B24 |
| No. of cable outlets | 1 |
| Type of the screw connection | M32 |
| Fixing screws | M6 (screw head: 5 mm Allen screw) |
| Shielded | no |
| Cable outlet | straight |
| Pg screw connection | with |

Connection data

| | |
|------------------------------|--------------------------------------------------------------|
| External cable diameter | 11 mm ... 21 mm |
| Tightening torque | 3 Nm ... 5 Nm (for M6 mounting screws on the sleeve housing) |
| Tightening torque, union nut | 7.50 Nm |

Dimensions
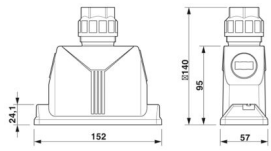
| | |
|------------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width | 57 mm |
| Height | 95 mm |
| Length | 152 mm |
| Wrench size, union nut | 30 mm |

Installation dimensions

| | |
|-------------------------------|--------|
| Width of the assembly cutout | 35 mm |
| Length of the assembly cutout | 112 mm |

Material specifications

| | |
|----------------------------------------|-----------------|
| Material Pressure screw | PA |
| Flammability rating according to UL 94 | V0 (Housing) |
| Seal material Profile gasket | NBR |
| Seal material Cable seal | NBR |
| Housing material | PA |
| Locking latch material | Stainless steel |
| Material of locking screw | Stainless steel |

Environmental and real-life conditions

HC-ADV-B24-HHWH-1TGM32-PL - Housing



1404235

<https://www.phoenixcontact.com/us/products/1404235>

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP66 |
| | IP67 |
| Impact strength | IK08 |
| Ambient temperature (operation) | -40 °C ... 100 °C |

Mechanical properties

Mechanical data

| | |
|------------------------------|-------|
| Type of the screw connection | M32 |
| Locking type | Screw |

Cable/line

| | |
|---------------------------------|-----------------|
| External cable diameter Cable 1 | 11 mm ... 21 mm |
|---------------------------------|-----------------|

Mounting

| | |
|---------------|----------------------------------------------|
| Assembly note | M6 locking screw, with 5 mm Allen screw head |
| Fixing screws | M6 (screw head: 5 mm Allen screw) |


HC-ADV-B24-HHWH-1TGM32-PL - Housing

1404235

<https://www.phoenixcontact.com/us/products/1404235>


Drawings

Dimensional drawing

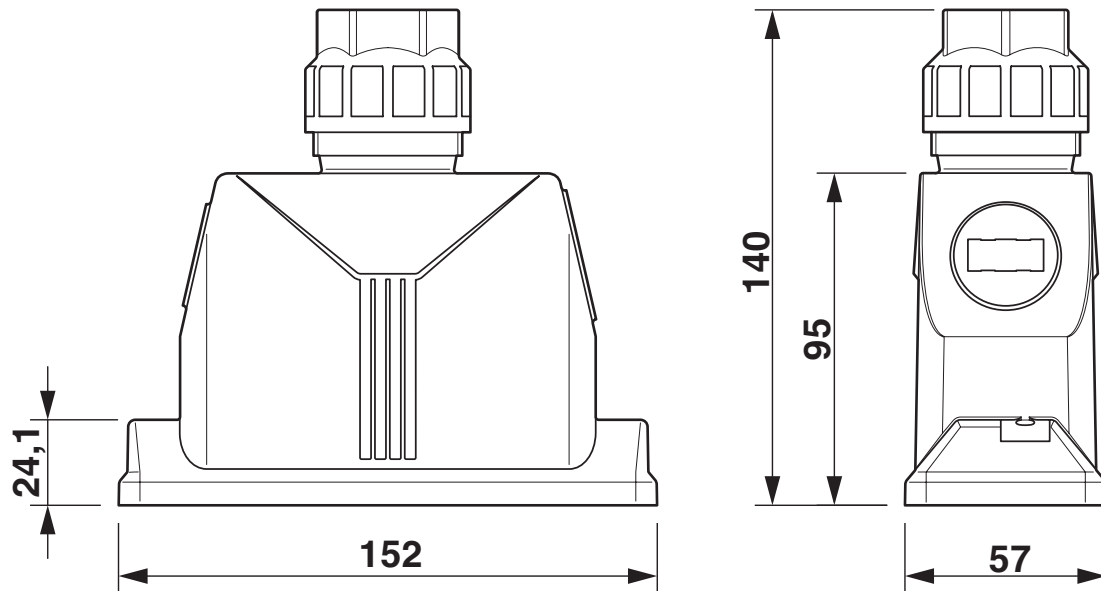

Dimensional drawing

Dimensional drawing

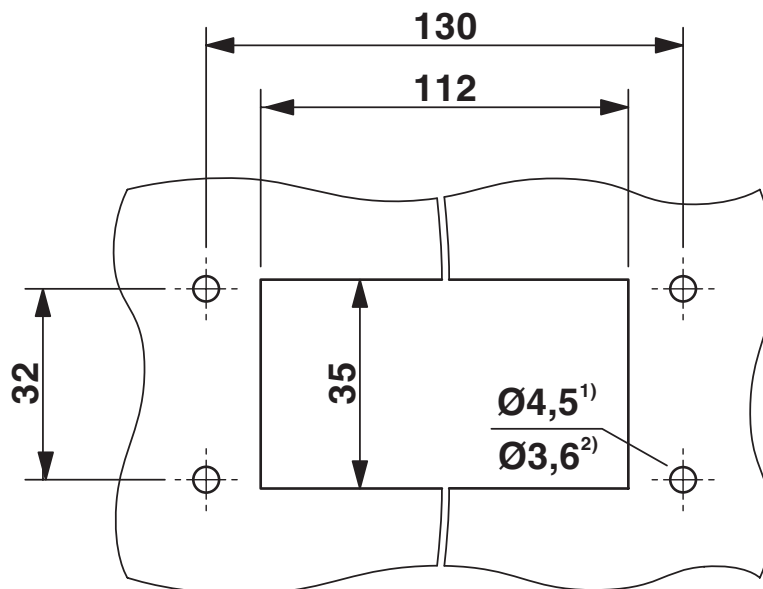

Mounting cutout

1) when M4 screws are used

2) when self-tapping Torx® screws are used (Torx® 20, M4)

HC-ADV-B24-HHWH-1TGM32-PL - Housing



1404235

<https://www.phoenixcontact.com/us/products/1404235>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1404235>

DNV

Approval ID: TAE000037S



cUL Recognized

Approval ID: E255026



UL Recognized

Approval ID: E255026

HC-ADV-B24-HHWH-1TGM32-PL - Housing



1404235

<https://www.phoenixcontact.com/us/products/1404235>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440202 |
| ECLASS-15.0 | 27440202 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC000437 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

1404235

<https://www.phoenixcontact.com/us/products/1404235>

Environmental product compliance

EU RoHS

| | |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

China RoHS

| | |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 2.593 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com