

HC-B24-BC-HI-PLBK - Protective cover



1407695

<https://www.phoenixcontact.com/us/products/1407695>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Protective cover B24, for single locking latch, protective cover material: PC, height: 19 mm, seal: no



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1407695 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF66 |
| Product key | AF7AZC |
| GTIN | 4046356776806 |
| Weight per piece (including packing) | 50 g |
| Weight per piece (excluding packing) | 44.1 g |
| Customs tariff number | 85389099 |
| Country of origin | PL |

HC-B24-BC-HI-PLBK - Protective cover

1407695

 
<https://www.phoenixcontact.com/us/products/1407695>

Technical data

Product properties

| | |
|------------------------|------------------|
| Product type | Protective cover |
| Housing type | Protective cover |
| Type | B24 |
| Retaining cord present | no |
| Seal present | no |

Dimensions

| | |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width | 47 mm |
| Height | 19 mm |
| Length | 124 mm |

Material specifications

| | |
|----------------------------------------|----|
| Material Protective cover | PC |
| Flammability rating according to UL 94 | V0 |
| Material, protective cover | PC |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP65 |
| | IP66 |
| Ambient temperature (operation) | -20 °C ... 100 °C |

HC-B24-BC-HI-PLBK - Protective cover





1407695

<https://www.phoenixcontact.com/us/products/1407695>

Drawings

Dimensional drawing

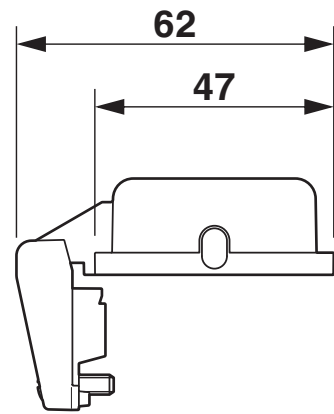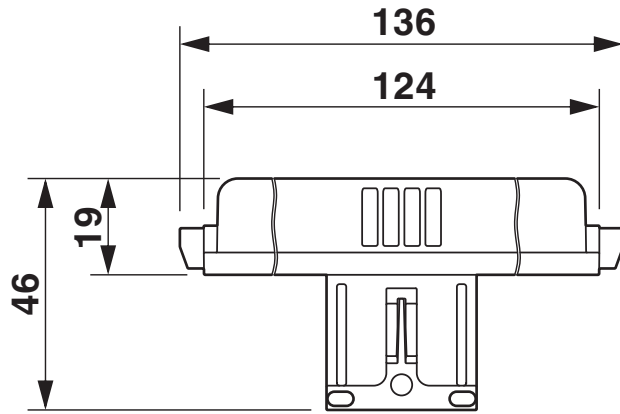

Dimensional drawing

HC-B24-BC-HI-PLBK - Protective cover



1407695

<https://www.phoenixcontact.com/us/products/1407695>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1407695>



EAC

Approval ID: RU C-DE.AI30.B.01102

HC-B24-BC-HI-PLBK - Protective cover



1407695

<https://www.phoenixcontact.com/us/products/1407695>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440208 |
| ECLASS-15.0 | 27440208 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002314 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

HC-B24-BC-HI-PLBK - Protective cover



1407695

<https://www.phoenixcontact.com/us/products/1407695>

Environmental product compliance

EU RoHS

| | |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

China RoHS

| | |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|---------------|
| CO2e kg | 0.681 kg CO2e |
|---------|---------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com