

# HC-COM-K-KML-O1PG16 - Housing



1408384

<https://www.phoenixcontact.com/us/products/1408384>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Coupling housings COM, with single locking latch, material: PC, cable outlets: 1, straight, 1x Pg16, height: 50.5 mm, cable gland: none, Standard

## Commercial data

Item number	1408384
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF59
Product key	AF7AAH
GTIN	4046356618120
Weight per piece (including packing)	43.15 g
Weight per piece (excluding packing)	42 g
Customs tariff number	85389099
Country of origin	CN

# HC-COM-K-KML-O1PG16 - Housing

1408384


<https://www.phoenixcontact.com/us/products/1408384>

## Technical data

### Product properties

Product type	Housing with locking latch
Housing type	Coupling housings
Product family	HC-COM
Application	Standard
Type	COM
No. of cable outlets	1
Type of the screw connection	1x Pg16
Cable outlet	straight
Pg screw connection	none

### Dimensions

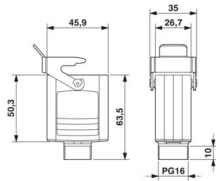Dimensional drawing	
Width	46 mm
Height	50.5 mm
Length	26.5 mm

### Material specifications

Flammability rating according to UL 94	V0
Seal material	NBR
Housing material	PC
Locking latch material	Stainless steel

### Mechanical properties

#### Mechanical data

Type of the screw connection	1x Pg16
Locking type	Latch

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP65
	IP66
Ambient temperature (operation)	-40 °C ... 125 °C

# HC-COM-K-KML-O1PG16 - Housing




1408384

<https://www.phoenixcontact.com/us/products/1408384>

## Drawings

Dimensional drawing

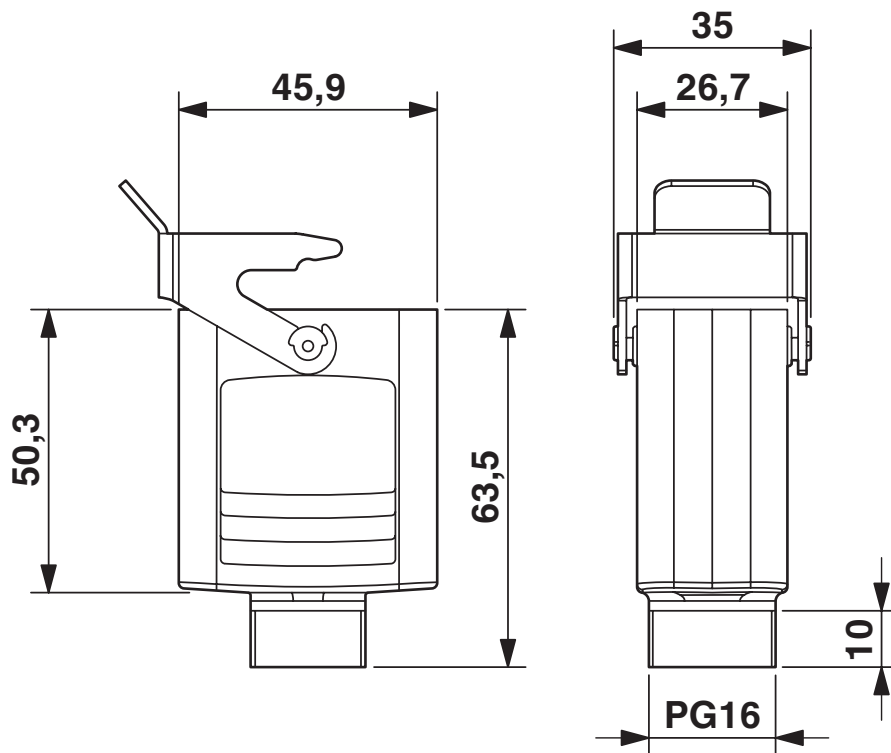

Dimensional drawing

# HC-COM-K-KML-O1PG16 - Housing



1408384

<https://www.phoenixcontact.com/us/products/1408384>

## Classifications

### ECLASS

ECLASS-13.0	27440202
ECLASS-15.0	27440202

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

1408384

<https://www.phoenixcontact.com/us/products/1408384>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)