

HC-KIT-B16-R01 - Connector set

1409710

<https://www.phoenixcontact.com/us/products/1409710>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Connector set, consisting of: B16 sleeve housing and panel mounting base, 16-pos. plug and socket insert, M25 cable gland



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1409710 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF63 |
| Product key | AF7AFX |
| GTIN | 4046356752466 |
| Weight per piece (including packing) | 630.8 g |
| Weight per piece (excluding packing) | 606.8 g |
| Customs tariff number | 85366990 |
| Country of origin | CN |

HC-KIT-B16-R01 - Connector set

1409710

<https://www.phoenixcontact.com/us/products/1409710>

Set consists of

G-INS-M25-M68N-NNES-S - Cable gland

1411165

<https://www.phoenixcontact.com/us/products/1411165>




Cable gland, material for screw connection: Brass, nickel-plated, application: Standard, external cable diameter 11 mm ... 17 mm, shielding: no, connecting thread: M25 x 1.5, color: silver-colored, with O-ring

HC-B 16-I-UT-M - Contact insert

1648238

<https://www.phoenixcontact.com/us/products/1648238>

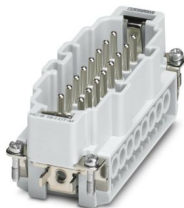

Contact insert, number of positions: 16+PE, size: B16, number of connections per position: 1, Pin, Screw connection, 500 V, 16 A, 0.5 mm² ... 2.5 mm², application: Power

HC-KIT-B16-R01 - Connector set

1409710

<https://www.phoenixcontact.com/us/products/1409710>



HC-STA-B16-HLFS-1TTM25-EL-AL - Housing

1412729

<https://www.phoenixcontact.com/us/products/1412729>



Sleeve housing B16, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, straight, 1x M25, height: 60 mm, cable gland: none, Standard

HC-STA-B16-BWSC-ELC-AL - Housing

1411325

<https://www.phoenixcontact.com/us/products/1411325>



Panel mounting base B16, with single locking latch, material: Die-cast aluminum, salt water resistant, protective cover material: PC, height: 30.5 mm, cable gland: none, protective cover: yes, Standard, with flat gasket

HC-KIT-B16-R01 - Connector set

1409710


<https://www.phoenixcontact.com/us/products/1409710>



HC-B 16-I-UT-F - Contact insert

1648241

<https://www.phoenixcontact.com/us/products/1648241>

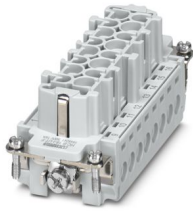

Contact insert, number of positions: 16+PE, size: B16, number of connections per position: 1, Socket, Screw connection, 500 V, 16 A, 0.5 mm² ... 2.5 mm², application: Power

HC-KIT-B16-R01 - Connector set

1409710

<https://www.phoenixcontact.com/us/products/1409710>

Technical data

Product properties

| | |
|-----------------------|------------------|
| Product type | Connector set |
| Housing type | Complete housing |
| Application | Power |
| Type | B16 |
| Number of positions | 16 |
| Connection profile | 16+PE |
| No. of cable outlets | 1 |
| Seal present | yes |
| Protective cover | yes |
| Contact material type | turned |
| Cable outlet | straight |

Insulation characteristics

| | |
|----------------------|-----|
| Overvoltage category | III |
| Degree of pollution | 3 |


Electrical properties

| | |
|-----------------------|-------|
| Rated voltage (III/3) | 500 V |
| Rated surge voltage | 6 kV |
| Rated current | 20 A |
| Nominal voltage U_N | 500 V |
| Nominal current I_N | 16 A |

Connection data

| | |
|------------------------------|--|
| Connection method | Screw connection |
| Connection technology | Screw connection |
| Conductor cross-section | 0.5 mm ² ... 2.5 mm ² (applies to stranded conductors with ferrules) 0.5 mm ² ... 2.5 mm ² (applies to stranded conductors with ferrules) |
| Connection cross section AWG | 20 ... 14 |
| Tightening torque | 0.5 Nm ... 0.8 Nm |

Dimensions
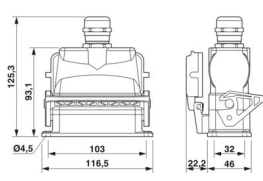
| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 43 mm |
| Height | 132 mm |
| Length | 114 mm |

HC-KIT-B16-R01 - Connector set



1409710

<https://www.phoenixcontact.com/us/products/1409710>

Installation dimensions

| | |
|-------------------------------|-------|
| Width of the assembly cutout | 35 mm |
| Length of the assembly cutout | 86 mm |

Material specifications

| | |
|--|-------------------|
| Material Housing | Die-cast aluminum |
| Flammability rating according to UL 94 | V0 |
| Seal material | NBR, conductive |
| Contact material | Copper alloy |
| Contact surface material | Ag |
| Contact carrier material | PC |
| Locking latch material | PA |

Cable/line

| | |
|-------------------------|--------------------------------|
| External cable diameter | 11 mm ... 17 mm |
| | 14 mm ... 17 mm (for UL 514 B) |
| External cable diameter | 11 mm ... 16 mm |

Mechanical properties

Mechanical data

| | |
|--------------|-------|
| Locking type | Latch |
|--------------|-------|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP65 |
| Impact strength | IK09 |
| Ambient temperature (operation) | -40 °C ... 100 °C |

Mounting

| | |
|---------------|----------------|
| Mounting type | Screw mounting |
|---------------|----------------|

HC-KIT-B16-R01 - Connector set




1409710

<https://www.phoenixcontact.com/us/products/1409710>

Drawings

Dimensional drawing

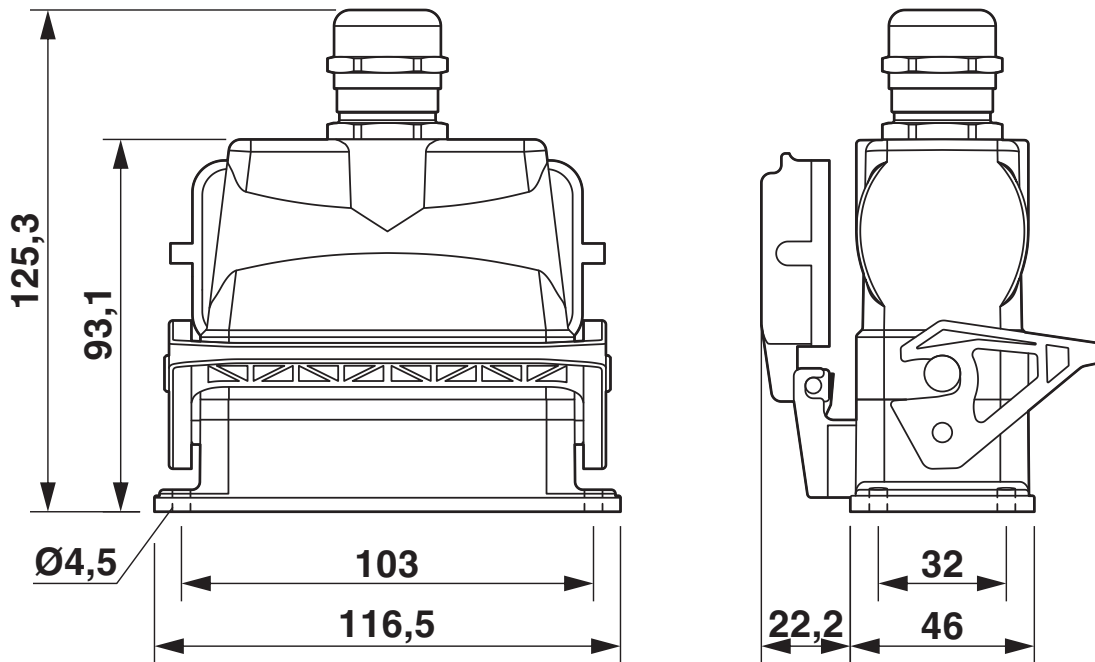

Dimensional drawing

HC-KIT-B16-R01 - Connector set



1409710

<https://www.phoenixcontact.com/us/products/1409710>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440113 |
| ECLASS-15.0 | 27440113 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002636 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

HC-KIT-B16-R01 - Connector set



1409710

<https://www.phoenixcontact.com/us/products/1409710>

Environmental product compliance

EU RoHS

| | |
|---|------|
| Fulfills EU RoHS substance requirements | Yes |
| Exemption | 6(c) |

China RoHS

| | |
|--|---|
| Environment friendly use period (EFUP) | EFUP-50 |
| | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

EU REACH SVHC

| | |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1) |
| SCIP | a827dfc3-a7b0-4d6a-a0b7-d8f72973b847 |

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com