

# HC-B-TA-M25-ER-AL - Adapter

1414257

<https://www.phoenixcontact.com/us/products/1414257>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Adapter, aluminum, for EVO housing, M25 thread



## Commercial data

Item number	1414257
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF57
Product key	AF7APM
GTIN	4055626022192
Weight per piece (including packing)	105.3 g
Weight per piece (excluding packing)	105.1 g
Customs tariff number	85389099
Country of origin	DE

# HC-B-TA-M25-ER-AL - Adapter

1414257

<https://www.phoenixcontact.com/us/products/1414257>

## Technical data


### Product properties

Product type	Thread adapter
Application	Bayonet B - metric
Type of the screw connection	M25

### Connection data

Tightening torque	... 12 Nm
-------------------	-----------

### Dimensions

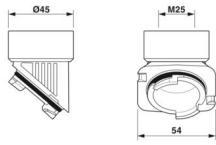Dimensional drawing	
Thread type on seal side	M25

### Internal dimensions

Length of internal thread	13 mm
---------------------------	-------

### Material specifications

Color	aluminum color
Material	Die-cast aluminum, corrosion-resistant
Seal material O-ring	NBR
Housing material	Die-cast aluminum, corrosion resistant

### Cable/line

External cable diameter	depending on the cable gland
-------------------------	------------------------------

### Mechanical properties

#### Mechanical data

Type of the screw connection	M25
------------------------------	-----

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP66
	IP67
Enclosure rating (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

# HC-B-TA-M25-ER-AL - Adapter


1414257

<https://www.phoenixcontact.com/us/products/1414257>



## Drawings

Dimensional drawing

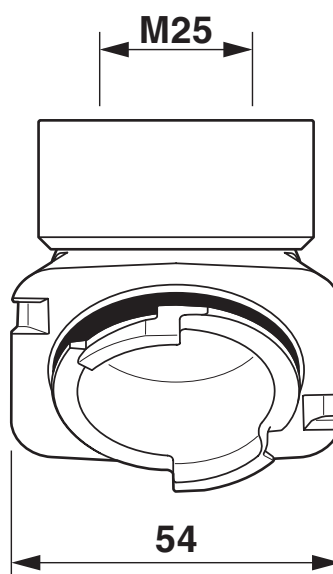

Dimensional drawing

# HC-B-TA-M25-ER-AL - Adapter



1414257

<https://www.phoenixcontact.com/us/products/1414257>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1414257>

**DNV**

Approval ID: TAE000037S



**cUL Recognized**

Approval ID: E255026



**UL Recognized**

Approval ID: E255026



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-B-TA-M25-ER-AL - Adapter



1414257

<https://www.phoenixcontact.com/us/products/1414257>

## Classifications

### ECLASS

ECLASS-13.0	27140801
ECLASS-15.0	27140801

### ETIM

ETIM 10.0	EC000441
-----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# HC-B-TA-M25-ER-AL - Adapter



1414257

<https://www.phoenixcontact.com/us/products/1414257>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)