

# HC-B-GTRS-M32-ER-AL - Cable gland



1414658

<https://www.phoenixcontact.com/us/products/1414658>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Set consisting of: EVO metal adapter 1414258 and screw connection with terminal block 1415194, M32



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1414658       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BF57          |
| Product key                          | AF7APM        |
| GTIN                                 | 4055626031095 |
| Weight per piece (including packing) | 297.7 g       |
| Weight per piece (excluding packing) | 297.7 g       |
| Customs tariff number                | 85389099      |
| Country of origin                    | DE            |

# HC-B-GTRS-M32-ER-AL - Cable gland

1414658


<https://www.phoenixcontact.com/us/products/1414658>

## Technical data

### Product properties

|                              |                   |
|------------------------------|-------------------|
| Product type                 | Cable screw gland |
| No. of conductors            | 1                 |
| Type of the screw connection | M32               |
| Shielded                     | no                |

### Dimensions
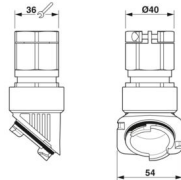
|                        |  |
|------------------------|--|
| Dimensional drawing    |  |
| Wrench size, union nut | 36 mm  |
| Wrench size, support   | 36 mm  |

### Material specifications

|                               |                      |
|-------------------------------|----------------------|
| Color                         | brass color          |
| Material Pressure screw       | Brass, nickel-plated |
| Seal material                 | EPDM                 |
| Seal material O-ring          | NBR                  |
| Material for screw connection | Brass, nickel-plated |

### Cable/line

|                                 |                 |
|---------------------------------|-----------------|
| External cable diameter Cable 1 | 13 mm ... 21 mm |
|---------------------------------|-----------------|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Degree of protection            | IP66              |
|                                 | IP67              |
| Ambient temperature (operation) | -40 °C ... 100 °C |

# HC-B-GTRS-M32-ER-AL - Cable gland


1414658

<https://www.phoenixcontact.com/us/products/1414658>



## Drawings

Dimensional drawing

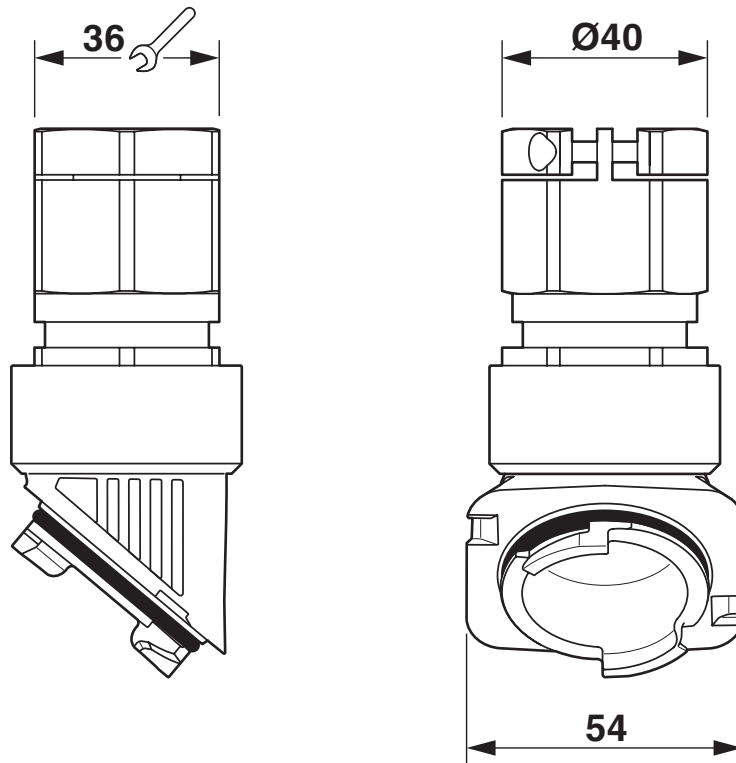

Dimensional drawing

# HC-B-GTRS-M32-ER-AL - Cable gland



1414658

<https://www.phoenixcontact.com/us/products/1414658>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1414658>



**EAC**

Approval ID: RU C-DE.AI30.B.01102



**EAC-RoHS**

Approval ID: RU D-DE.HB35.B.00387

# HC-B-GTRS-M32-ER-AL - Cable gland



1414658

<https://www.phoenixcontact.com/us/products/1414658>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27140801 |
| ECLASS-15.0 | 27140801 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC000441 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121300 |
|-------------|----------|

1414658

<https://www.phoenixcontact.com/us/products/1414658>

## Environmental product compliance

### EU RoHS

|   |      |
|---|------|
| Fulfills EU RoHS substance requirements | Yes  |
| Exemption                               | 6(c) |

### China RoHS

|  |   |
|--|---|
| Environment friendly use period (EFUP) | EFUP-50   |
|  | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

### EU REACH SVHC

|                                     |                                     |
|-------------------------------------|-------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: 7439-92-1)                |
| SCIP                                | 993dd7ec-1c25-432d-a62f-ae55f7fdb21 |

### EF3.1 Climate Change

|         |                |
|---------|----------------|
| CO2e kg | 11.325 kg CO2e |
|---------|----------------|

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)