

# HC-D25-SP-RBK - Profile gasket



1414672

<https://www.phoenixcontact.com/us/products/1414672>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Replacement profile gasket, for HC-EVO-D25.....BK housing



## Commercial data

Item number	1414672
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF66
Product key	AF7APZ
GTIN	4055626031231
Weight per piece (including packing)	3.03 g
Weight per piece (excluding packing)	3.03 g
Customs tariff number	40169300
Country of origin	IT

# HC-D25-SP-RBK - Profile gasket



1414672


<https://www.phoenixcontact.com/us/products/1414672>

## Technical data

### Product properties

Product type	Seal
Type	D25

### Dimensions

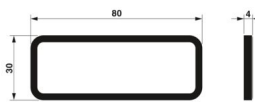Dimensional drawing	
Width	30 mm
Height	4 mm
Length	80 mm

### Material specifications

Seal material Profile gasket	NBR
------------------------------	-----

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

### Mounting

Assembly note	The replacement seal should be bonded with Loctite 454 adhesive. For HC-EVO-D25...BK housing
---------------	---

# HC-D25-SP-RBK - Profile gasket


1414672

<https://www.phoenixcontact.com/us/products/1414672>



## Drawings

Dimensional drawing

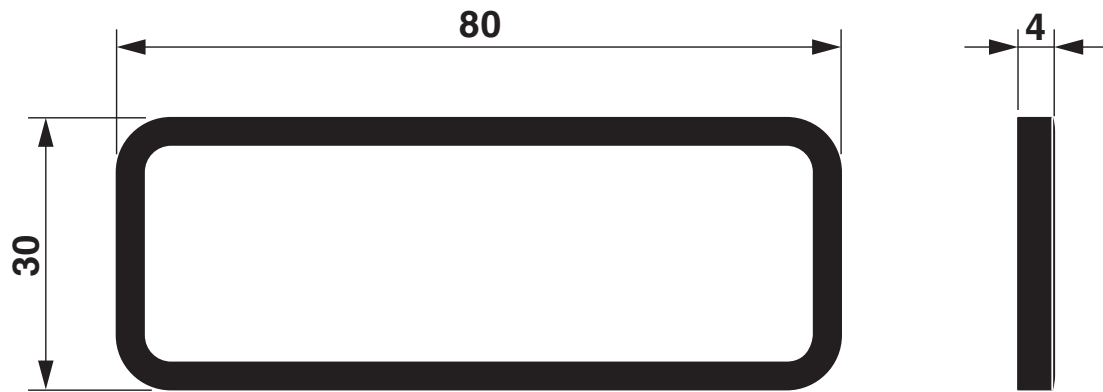

Dimensional drawing

# HC-D25-SP-RBK - Profile gasket



1414672

<https://www.phoenixcontact.com/us/products/1414672>

## Classifications

### ECLASS

ECLASS-13.0

23071590

### ETIM

ETIM 9.0

EC002498

### UNSPSC

UNSPSC 21.0

31401600

# HC-D25-SP-RBK - Profile gasket



1414672

<https://www.phoenixcontact.com/us/products/1414672>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)