

MD-INB24-4-SZP-S - Module plate



1415243

<https://www.phoenixcontact.com/us/products/1415243>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Module plate, with seal, for CES B24 sealing frames, with 4 openings, including mounting screws



Product description

Module plate
8 mounting screws (M5x12) /
and
Washers are supplied as standard

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1415243 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF67 |
| Product key | AF7CZX |
| GTIN | 4055626039480 |
| Weight per piece (including packing) | 718.5 g |
| Weight per piece (excluding packing) | 22.22 g |
| Customs tariff number | 73089059 |
| Country of origin | DE |

MD-INB24-4-SZP-S - Module plate



1415243

<https://www.phoenixcontact.com/us/products/1415243>

Technical data

Notes

| | |
|---------|-----------------------|
| General | incl. mounting screws |
|---------|-----------------------|

Product properties

| | |
|--------------|---------------|
| Product type | Adapter plate |
| Seal present | yes |

Connection data

| | |
|-------------------|--------------|
| Tightening torque | 1 ... 1.2 Nm |
|-------------------|--------------|

Dimensions

| | |
|---------------------|--------|
| Dimensional drawing | |
| Width | 168 mm |
| Height | 2 mm |
| Length | 338 mm |

Material specifications

| | |
|---------------|---------------------------------|
| Material | Stainless steel 1.4301/AISI 304 |
| Seal material | NBR |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | IP54 |
| Ambient temperature (operation) | -40 °C ... 100 °C |

Mounting

| | |
|---------------|--|
| Assembly note | Diameter of fixing hole for self-tapping screw: 4.5 mm ... 4.7 mm, mounting screws (M5x12): 1.0 Nm ... 1.2 Nm tightening torque, SW4 Allen key |
| | Make sure the seal is fitted correctly (must not be squeezed out at the sides) |

MD-INB24-4-SZP-S - Module plate




1415243

<https://www.phoenixcontact.com/us/products/1415243>

Drawings

Dimensional drawing

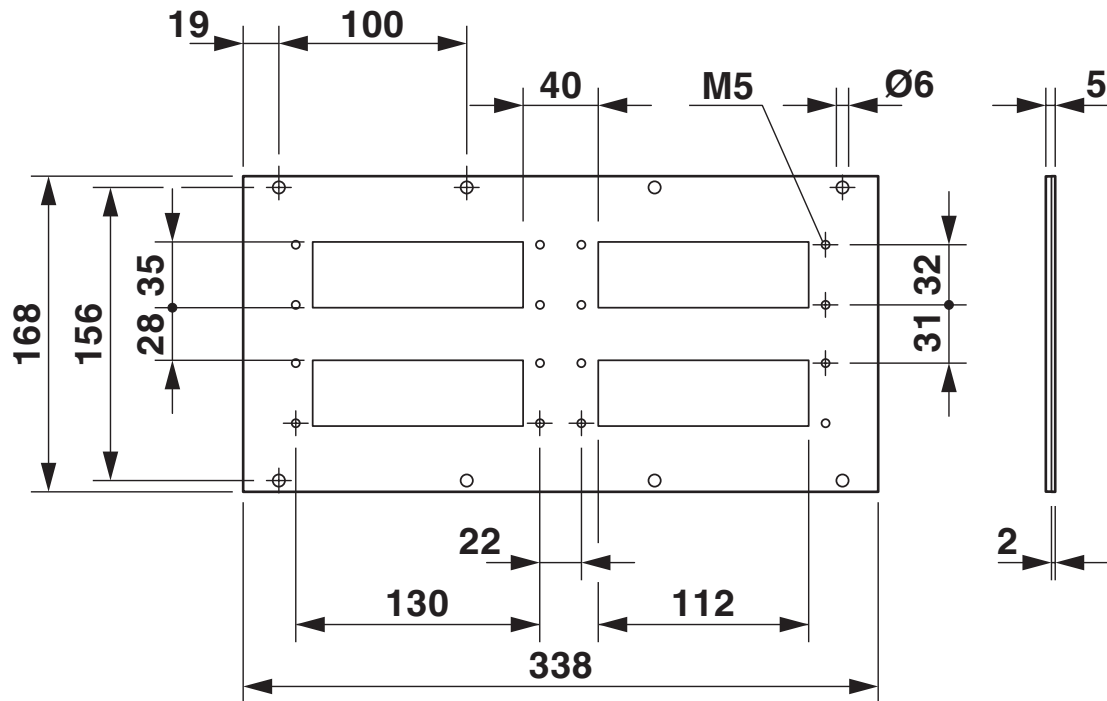


MD-INB24-4-SZP-S - Module plate



1415243

<https://www.phoenixcontact.com/us/products/1415243>

Dimensional drawing

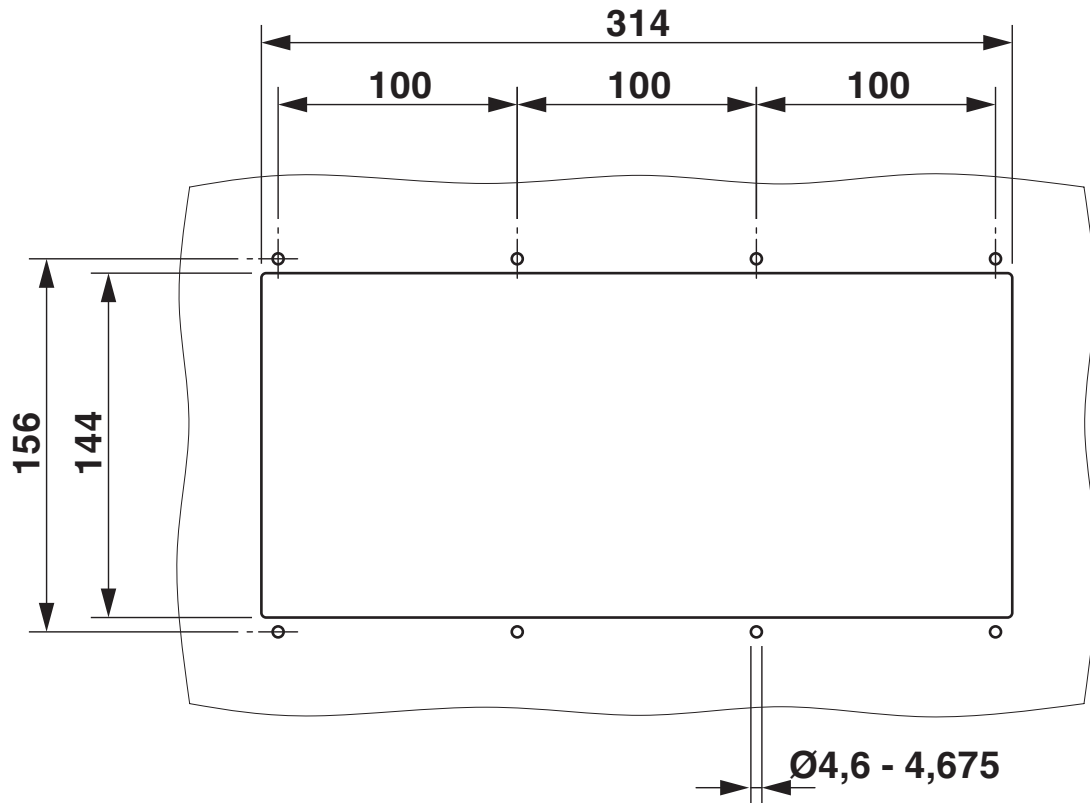

Wall cutout drawing

MD-INB24-4-SZP-S - Module plate



1415243

<https://www.phoenixcontact.com/us/products/1415243>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002309 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

MD-INB24-4-SZP-S - Module plate



1415243

<https://www.phoenixcontact.com/us/products/1415243>

Environmental product compliance

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com