

# SACC-SQ-M12FS-12P-25F/0,07-0,08 - Device connector front mounting

1417037

<https://www.phoenixcontact.com/us/products/1417037>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Device connector front mounting, 12-position, Socket, straight, M12-SPEEDCON, A-coding, on free cable end, Individual wires, cable length: 0.07 m, 0.08 mm<sup>2</sup>, potted, this item is expected to be lead-free from Q2 2026 in accordance with RoHS II without exception 6c (Pb < 0.1%), a lead-free alternative is possible on request in advance

## Commercial data

Item number	1417037
Packing unit	1 pc
Minimum order quantity	50 pc
Product key	ABQCFD
GTIN	4055626077307
Weight per piece (including packing)	19.2 g
Weight per piece (excluding packing)	17.088 g
Country of origin	DE

# SACC-SQ-M12FS-12P-25F/0,07-0,08 - Device connector front mounting



1417037

<https://www.phoenixcontact.com/us/products/1417037>

## Technical data

### Mounting

Mounting type	Front mounting/square flange (25 mm side length)
---------------	--------------------------------------------------

### Product properties

Product type	Circular connectors (device side)
Application	Signal
Number of positions	12
No. of cable outlets	1
Coding	A
Thread type	M12

### Material specifications

Material Molding compound	PUR (potted)
---------------------------	--------------

### Connection data

#### Conductor connection

Connection method	Individual wires
Contact connection type	Socket
Conductor cross-section	0.08 mm <sup>2</sup>

### Connector

#### Connection 1

Head design	Socket
Head cable outlet	straight
Head thread type	M12
Head locking type	SPEEDCON
Coding	A

#### Connection 2

Head design	free cable end
-------------	----------------

### Cable/line

Cable length	0.07 m
Cable cross section	0.08 mm <sup>2</sup>
AWG signal line	28

### Environmental and real-life conditions

#### Ambient conditions

UL Type Rating	Type 4 (indoor use only)
----------------	--------------------------


# SACC-SQ-M12FS-12P-25F/0,07-0,08 - Device connector front mounting

1417037

<https://www.phoenixcontact.com/us/products/1417037>

## Drawings

Schematic diagram

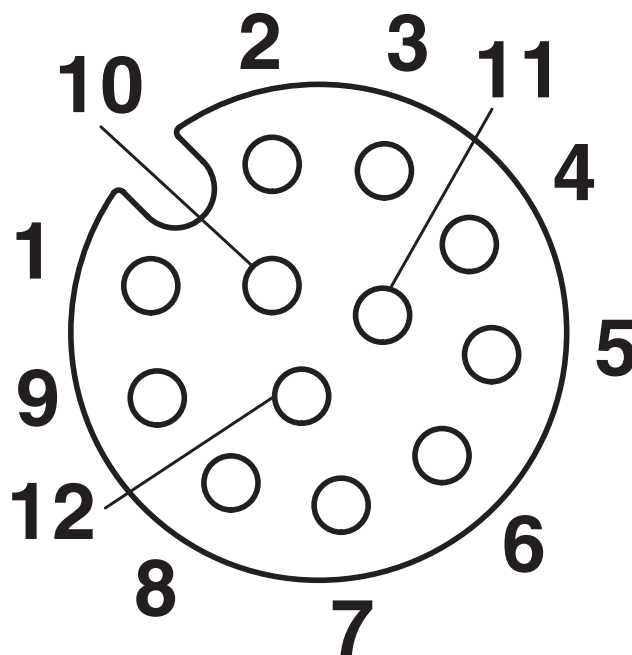

Pin assignment M12 socket, 12-pos., A-coded, view female side

# SACC-SQ-M12FS-12P-25F/0,07-0,08 - Device connector front mounting



1417037

<https://www.phoenixcontact.com/us/products/1417037>

## Classifications

### ECLASS

ECLASS-13.0	27440103
ECLASS-15.0	27440103

### ETIM

ETIM 10.0	EC003570
-----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# SACC-SQ-M12FS-12P-25F/0,07-0,08 - Device connector front mounting



1417037

<https://www.phoenixcontact.com/us/products/1417037>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
-----------------------------------------	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)