

# CES-B24-SFC-M-15,6 - Locking element



1423745

<https://www.phoenixcontact.com/us/products/1423745>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Locking element, design: B24, material: Steel, galvanized, length: 146 mm, width: 57 mm, height: 15.6 mm



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1423745       |
| Packing unit                         | 10 pc         |
| Minimum order quantity               | 10 pc         |
| Sales key                            | BF67          |
| Product key                          | AF7CZX        |
| GTIN                                 | 4055626353432 |
| Weight per piece (including packing) | 107.33 g      |
| Weight per piece (excluding packing) | 100 g         |
| Customs tariff number                | 73269098      |
| Country of origin                    | DE            |

# CES-B24-SFC-M-15,6 - Locking element



1423745


<https://www.phoenixcontact.com/us/products/1423745>

## Technical data

### Product properties

|              |             |
|--------------|-------------|
| Product type | Cover plate |
| Type         | B24         |

### Dimensions
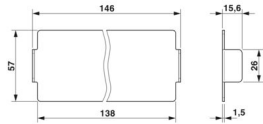
|                     |  |
|---------------------|--|
| Dimensional drawing |  |
| Width               | 57 mm  |
| Height              | 15.6 mm  |
| Length              | 146 mm   |

### Material specifications

|          |                   |
|----------|-------------------|
| Material | Steel, galvanized |
|----------|-------------------|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 120 °C |
|---------------------------------|-------------------|

### Mounting

|               |  |
|---------------|--|
| Assembly note | suitable for article 0801647, V/C: 01 (version batch), see printing of the packaging label |
|---------------|--|

# CES-B24-SFC-M-15,6 - Locking element




1423745

<https://www.phoenixcontact.com/us/products/1423745>

## Drawings

Dimensional drawing

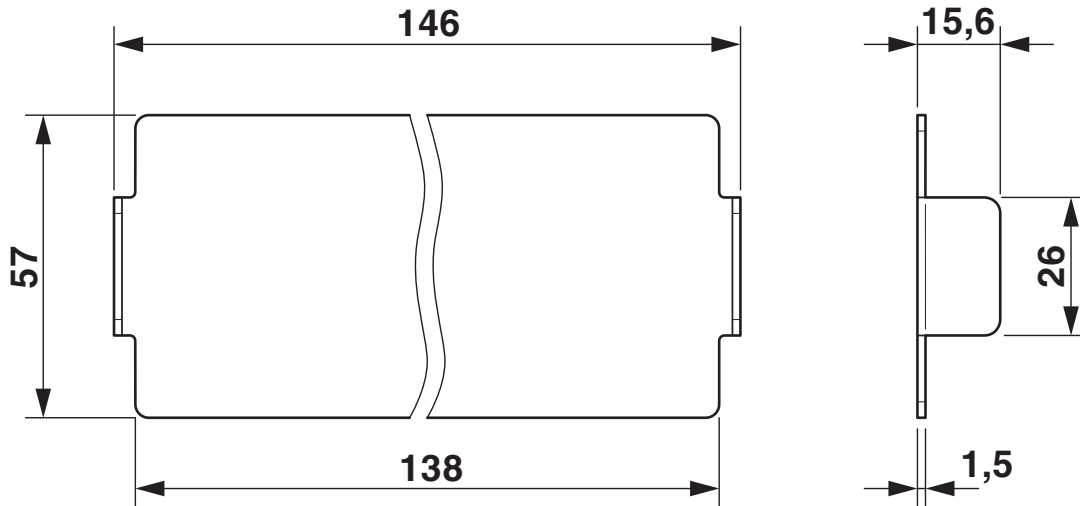

Dimensional drawing

# CES-B24-SFC-M-15,6 - Locking element



1423745

<https://www.phoenixcontact.com/us/products/1423745>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1423745>

**DNV**

Approval ID: TAE00003VJ

# CES-B24-SFC-M-15,6 - Locking element



1423745

<https://www.phoenixcontact.com/us/products/1423745>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440192 |
| ECLASS-15.0 | 27440192 |

### ETIM

|           |          |
|-----------|----------|
| ETIM 10.0 | EC002943 |
|-----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

# CES-B24-SFC-M-15,6 - Locking element



1423745

<https://www.phoenixcontact.com/us/products/1423745>

## Environmental product compliance

### EU RoHS

|   |                    |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

### China RoHS

|  |  |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|  | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)