

HC-D64-PTT-FWM - Retaining bracket




1424167

<https://www.phoenixcontact.com/us/products/1424167>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Retaining bracket for supporting cables

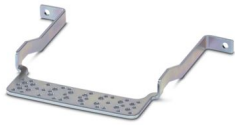

Commercial data

Item number	1424167
Packing unit	1 pc
Minimum order quantity	1 pc
Product key	AF7ABZ
GTIN	4055626405919
Weight per piece (including packing)	56.7 g
Weight per piece (excluding packing)	54 g
Country of origin	CN

HC-D64-PTT-FWM - Retaining bracket



1424167

<https://www.phoenixcontact.com/us/products/1424167>

Technical data

Product properties

Product type	Contact insert with a fixed no. of positions
Series	HC-D
Connection profile	64+PE

Dimensions

Width	93 mm
Length	105 mm
Drill hole distance, horizontal	129 mm

Connection data

Connection technology

Connection technology	Push-in connection
-----------------------	--------------------

Conductor connection

Conductor cross-section	0.5 mm ² ... 2.5 mm ²
Connection cross section AWG	20 ... 14
Stripping length of the individual wire	10 mm

Electrical properties

Rated voltage (III/3)	250 V
Rated surge voltage	6 kV
Rated current	10 A

Material specifications

Material Housing	Steel, galvanized
Contact material	Copper alloy
Contact surface material	Ag
Contact carrier material	PC
Standards/regulations	PC

HC-D64-PTT-FWM - Retaining bracket



1424167

<https://www.phoenixcontact.com/us/products/1424167>

Classifications

ECLASS

ECLASS-15.0	27440192
ECLASS-13.0	27440192

ETIM

ETIM 10.0	EC002943
-----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

HC-D64-PTT-FWM - Retaining bracket



1424167

<https://www.phoenixcontact.com/us/products/1424167>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com