

HC-STA-D25-BWSC-EL-AL - Housing



1424390

<https://www.phoenixcontact.com/us/products/1424390>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Panel mounting base D25, with single locking latch, material: Die-cast aluminum, salt water resistant, protective cover material: PC, height: 26 mm, cable gland: none, protective cover: yes, Standard

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1424390 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF56 |
| Product key | AF7APE |
| GTIN | 4055626371306 |
| Weight per piece (including packing) | 102.1 g |
| Weight per piece (excluding packing) | 70 g |
| Customs tariff number | 85389099 |
| Country of origin | CN |

HC-STA-D25-BWSC-EL-AL - Housing

1424390

<https://www.phoenixcontact.com/us/products/1424390>

Technical data

 
Notes

| | |
|---------|---------------------------------|
| General | For contact inserts HC-D25, A16 |
|---------|---------------------------------|

Product properties

| | |
|---------------------|----------------------------|
| Product type | Housing with locking latch |
| Housing type | Panel mounting base |
| Product family | HC-STA-D |
| Application | Standard |
| Type | D25 |
| Protective cover | yes |
| Pg screw connection | none |

Dimensions

| | |
|---------------------|--|
| Dimensional drawing |  |
| Width | 39 mm |
| Height | 26 mm |
| Length | 97 mm |
| Hole diameter | 3.3 mm |

Installation dimensions

| | |
|-------------------------------|-------|
| Width of the assembly cutout | 24 mm |
| Length of the assembly cutout | 74 mm |

Material specifications

| | |
|--|---|
| Flammability rating according to UL 94 | V0 (Interlock) V0 (Protective cover) |
| Seal material Flat gasket | NBR, conductive |
| Housing material | Die-cast aluminum, salt water resistant |
| Housing surface material | uncoated |
| Material, protective cover | PC |
| Locking latch material | PA |

Mechanical properties

Mechanical data

| | |
|--------------|-------|
| Locking type | Latch |
|--------------|-------|

Connection data

| | |
|-------------------|---|
| Tightening torque | 0.5 Nm ... 0.8 Nm (For M3 mounting screws on the panel-mount) |
|-------------------|---|

HC-STA-D25-BWSC-EL-AL - Housing



1424390

<https://www.phoenixcontact.com/us/products/1424390>

base)

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------------------------|
| Degree of protection | IP66 (with locked protective cover) |
| | IP67 (when plugged in) |
| Impact strength | IK08 |
| Ambient temperature (operation) | -40 °C ... 125 °C |

HC-STA-D25-BWSC-EL-AL - Housing




1424390

<https://www.phoenixcontact.com/us/products/1424390>


Drawings

Dimensional drawing

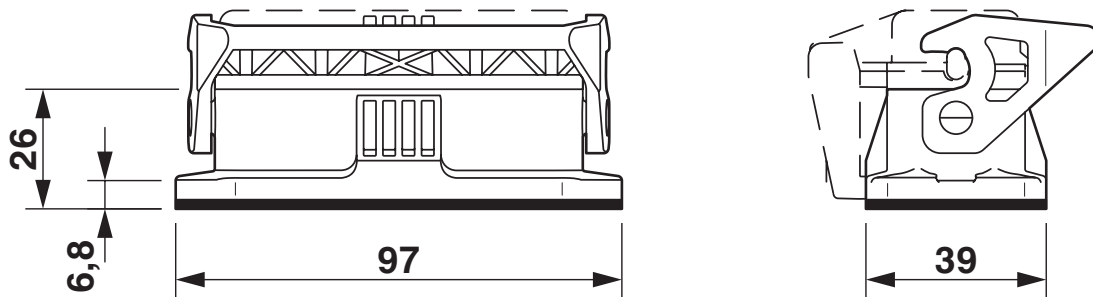

Dimensional drawing

Dimensional drawing

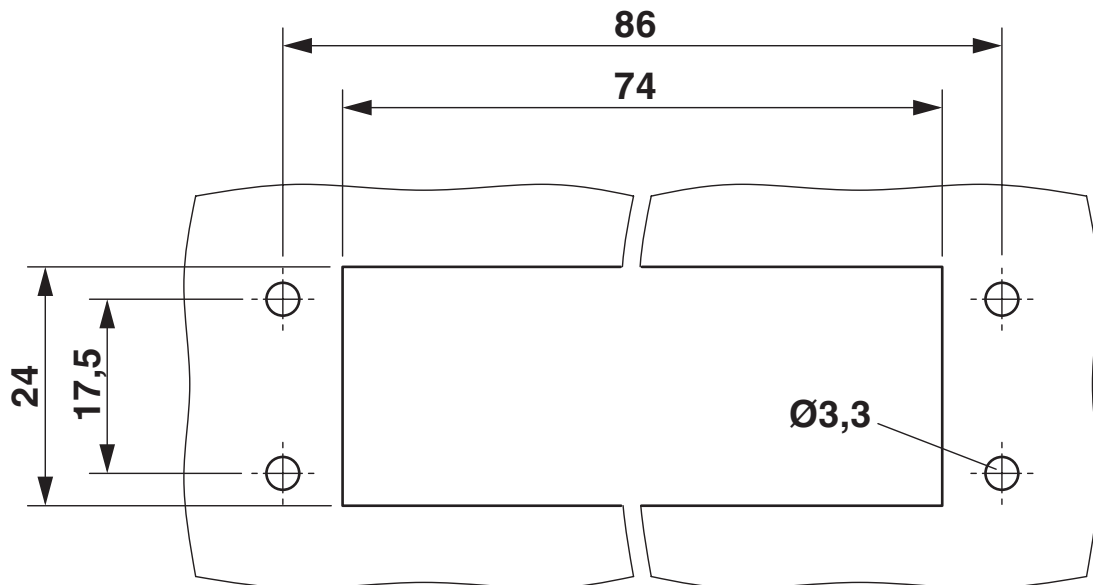

Mounting cutout

HC-STA-D25-BWSC-EL-AL - Housing



1424390

<https://www.phoenixcontact.com/us/products/1424390>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1424390>

DNV

Approval ID: TAE000037S

HC-STA-D25-BWSC-EL-AL - Housing



1424390

<https://www.phoenixcontact.com/us/products/1424390>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 27440202 |
| ECLASS-15.0 | 27440202 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC000437 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

HC-STA-D25-BWSC-EL-AL - Housing



1424390

<https://www.phoenixcontact.com/us/products/1424390>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com