

HC-D07-SG-RBK - Seal

1424441

<https://www.phoenixcontact.com/us/products/1424441>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Replacement seal for HC-D7 housing



Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1424441 |
| Packing unit | 10 pc |
| Minimum order quantity | 1 pc |
| Sales key | BF66 |
| Product key | AF7APZ |
| GTIN | 4055626372709 |
| Weight per piece (including packing) | 1.071 g |
| Weight per piece (excluding packing) | 1.071 g |
| Customs tariff number | 85366990 |
| Country of origin | CN |

HC-D07-SG-RBK - Seal

1424441


<https://www.phoenixcontact.com/us/products/1424441>

Technical data

Product properties

| | |
|--------------|-----------------------|
| Product type | Seal |
| Application | for D7 series housing |

Dimensions
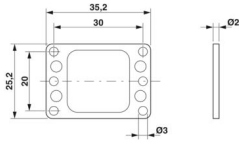
| | |
|---------------------------------|--|
| Dimensional drawing |  |
| Width | 23.7 mm |
| Height | 2.45 mm |
| Depth | 2.45 mm |
| Length | 23.7 mm |
| Drill hole distance, horizontal | 30 mm |
| Drill hole distance, vertical | 20 mm |
| Hole diameter | 3 mm |

Material specifications

| | |
|---------------|-----|
| Seal material | NBR |
|---------------|-----|

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 125 °C |
|---------------------------------|-------------------|


HC-D07-SG-RBK - Seal

1424441

<https://www.phoenixcontact.com/us/products/1424441>



Drawings

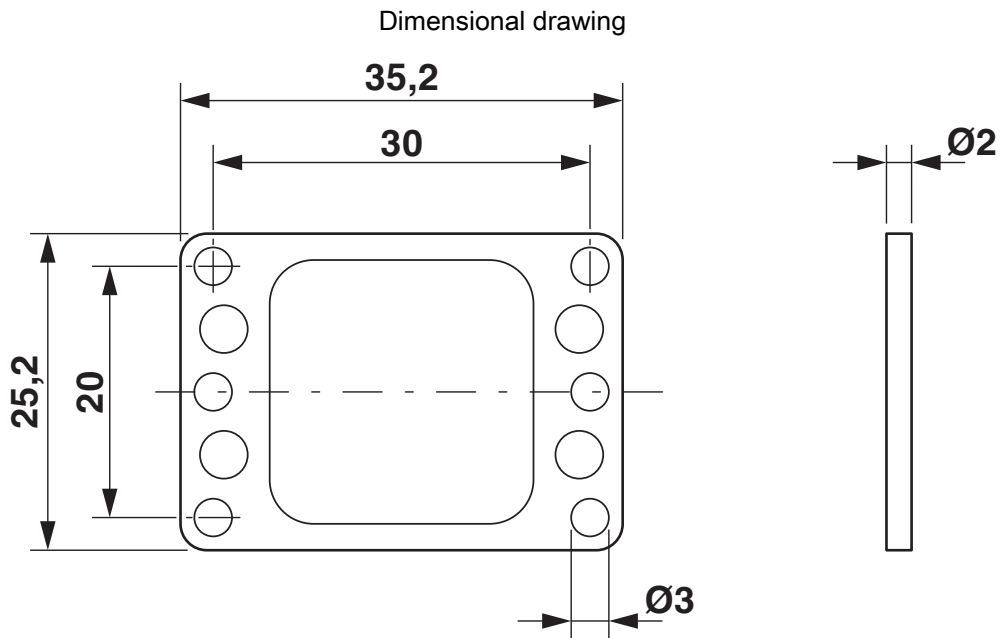

Dimensional drawing

HC-D07-SG-RBK - Seal



1424441

<https://www.phoenixcontact.com/us/products/1424441>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 23071590 |
| ECLASS-15.0 | 27440292 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC002943 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 31401600 |
|-------------|----------|

HC-D07-SG-RBK - Seal



1424441

<https://www.phoenixcontact.com/us/products/1424441>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com