


# SACC-SQ-FS-12P-25F/0,5-0,08PVC - Device connector front mounting



1425614

<https://www.phoenixcontact.com/us/products/1425614>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

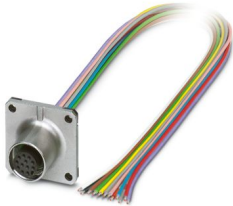

Device connector front mounting, 12-position, Socket, straight, M12, A-coding, on free cable end, Individual wires, cable length: 0.5 m, 0.08 mm<sup>2</sup>, potted, this item is expected to be lead-free from Q2 2026 in accordance with RoHS II without exception 6c (Pb < 0.1%), a lead-free alternative is possible on request in advance

## Commercial data

Item number	1425614
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	AB24
Product key	ABQCFD
GTIN	4055626430591
Weight per piece (including packing)	24.22 g
Weight per piece (excluding packing)	22.396 g
Customs tariff number	85444290
Country of origin	DE

# SACC-SQ-FS-12P-25F/0,5-0,08PVC - Device connector front mounting



1425614

<https://www.phoenixcontact.com/us/products/1425614>

## Technical data

### Notes

General	Contact connection method: Crimp connection
---------	---

### Mounting

Mounting type	Front mounting/square flange (25 mm side length)
---------------	--

### Product properties

Product type	Circular connectors (device side)
Application	Signal
Number of positions	12
Coding	A
Thread type	M12

### Material specifications

Material Molding compound	PUR (potted)
---------------------------	--------------

### Connection data

#### Conductor connection

Connection method	Individual wires
Contact connection type	Socket
Conductor cross-section	0.08 mm <sup>2</sup>

### Connector

#### Connection 1

Head design	Socket
Head cable outlet	straight
Head thread type	M12
Coding	A

#### Connection 2

Head design	free cable end
-------------	----------------

### Cable/line

Cable length	0.5 m
Cable cross section	0.08 mm <sup>2</sup>
AWG signal line	28

### Environmental and real-life conditions

#### Ambient conditions

UL Type Rating	Type 4 (indoor use only)
----------------	--------------------------


# SACC-SQ-FS-12P-25F/0,5-0,08PVC - Device connector front mounting

1425614

<https://www.phoenixcontact.com/us/products/1425614>

## Drawings

Schematic diagram

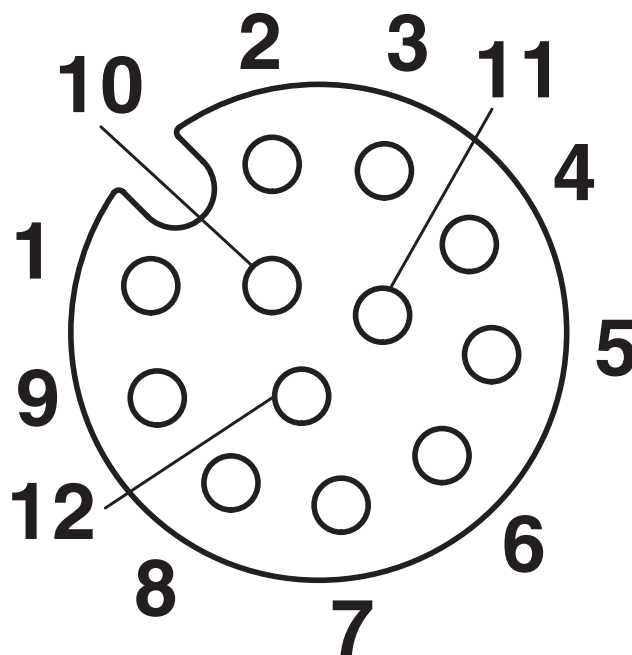

Pin assignment M12 socket, 12-pos., A-coded, view female side

# SACC-SQ-FS-12P-25F/0,5-0,08PVC - Device connector front mounting



1425614

<https://www.phoenixcontact.com/us/products/1425614>

## Classifications

### ECLASS

ECLASS-13.0	27440103
ECLASS-15.0	27440103

### ETIM

ETIM 10.0	EC003570
-----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# SACC-SQ-FS-12P-25F/0,5-0,08PVC - Device connector front mounting



1425614

<https://www.phoenixcontact.com/us/products/1425614>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

### China RoHS

Environment friendly use period (EFUP)	EFUP-50 An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
--	--

### EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	a69ef9cf-96ba-408b-be31-ce86f9e5c429

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)