

EO-AB/PT/LED/15-USB-A/C - Socket



1484524

<https://www.phoenixcontact.com/us/products/1484524>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Socket, LED display and integrated USB, 1x type A and 1x type C, 5 V/3 A (total), Pin connector pattern type AB 15A, connection method: Push-in spring connection, color: gray, nom. voltage: 125 V AC (60 Hz), nominal current: 15 A, DIN rail or direct mounting, standards/specifications: UL 508, CSA C22.2 No. 14, Country marking: Canada, USA

Your advantages

- No additional need for USB chargers or external power supply units
- Reliable USB power supply directly in the control cabinet
- More operational safety and less cable chaos
- Faster installation thanks to integrated solution
- Future-proof equipment for modern applications

Commercial data

Item number	1484524
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BE76
Product key	BE7623
GTIN	4063151924201
Weight per piece (including packing)	158.8 g
Weight per piece (excluding packing)	158.8 g
Customs tariff number	85366990
Country of origin	PL

Technical data

Product properties

Product type	Socket
Country ID	Canada
	USA

Connection data

Connection method	Push-in spring connection
Note	The electrical outlets with Push-in connection are not designed for through-wiring. Connect a maximum of one conductor to each terminal point. Multiple assignment of one terminal point is not permitted.
Stripping length	8 mm
Conductor cross-section rigid	0.2 mm ² ... 4 mm ²
Cross section AWG	24 ... 12 (converted acc. to IEC)
Conductor cross-section flexible	0.25 mm ² ... 2.5 mm ²
Conductor cross-section, flexible [AWG]	24 ... 14 (converted acc. to IEC)
Conductor cross-section flexible (ferrule without plastic sleeve)	0.25 mm ² ... 2.5 mm ²
Flexible conductor cross-section (ferrule with plastic sleeve)	0.25 mm ² ... 2.5 mm ²
Conductor cross-section flexible (2 conductors with the same cross-section, with TWIN ferrule and plastic sleeve)	0.2 mm ² ... 4 mm ²
Nominal current	15 A
Nominal voltage	125 V AC (60 Hz)

Dimensions

Depth on NS 35/7,5	60 mm
Depth on NS 35/15	67.5 mm

Material specifications

Color	gray (RAL 7042)
Insulating material	PA

Connector

Type of plug	Pin connector pattern type AB 15A
--------------	-----------------------------------

Standards and regulations

Standards


Standards/regulations	UL 508
	CSA C22.2 No. 14

Mounting

Mounting type	DIN rail or direct mounting
---------------	-----------------------------

Drawings

Circuit diagram

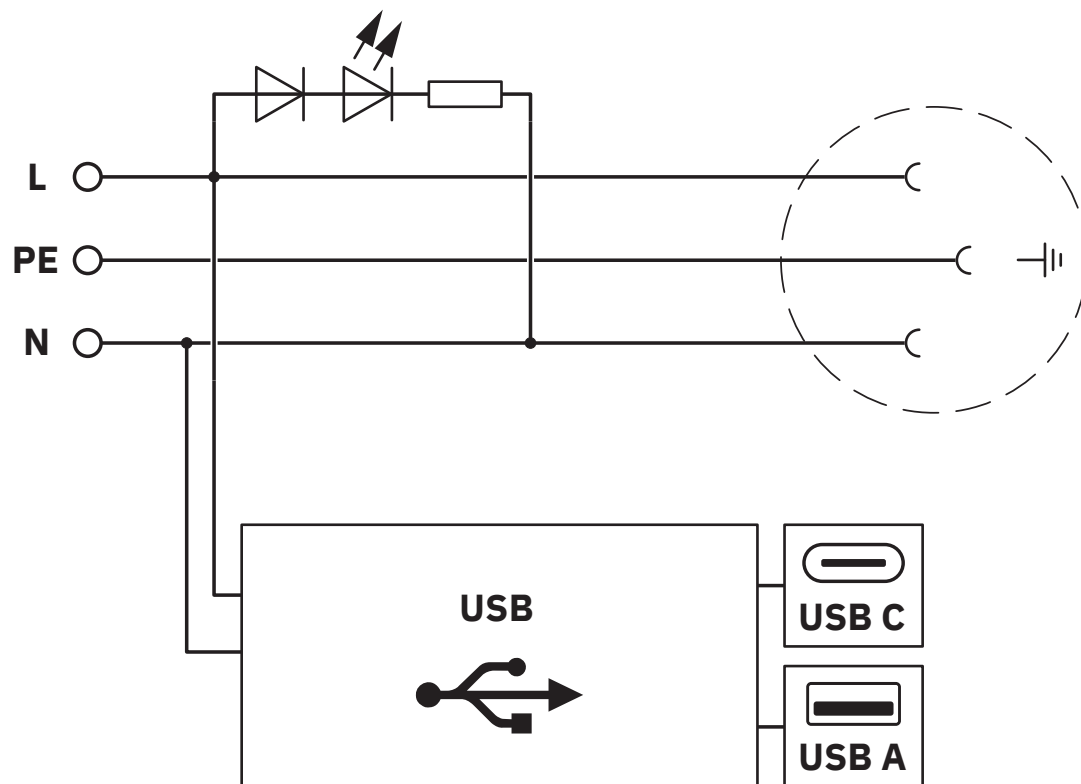

EO-AB/PT/LED/15-USB-A/C - Socket



1484524

<https://www.phoenixcontact.com/us/products/1484524>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1484524>



cULus Listed

Approval ID: 2567394-2549820

EO-AB/PT/LED/15-USB-A/C - Socket



1484524

<https://www.phoenixcontact.com/us/products/1484524>

Classifications

ECLASS

ECLASS-13.0	27142305
ECLASS-15.0	27142305

ETIM

ETIM 10.0	EC001663
-----------	----------

1484524

<https://www.phoenixcontact.com/us/products/1484524>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c), 7(a), 7(c)-I

China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
-------------------------------------	----------------------

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com