

# SAC-3P- 5,0-PUR/M12FS GY - Sensor/actuator cable



1565528

<https://www.phoenixcontact.com/us/products/1565528>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, 3-position, PUR/PVC, black-gray RAL 7021, free cable end, on Socket straight M12, coding: A, cable length: 5 m

as illustration, however with gray handle

## Commercial data

Item number	1565528
Packing unit	50 pc
Minimum order quantity	50 pc
Product key	AF1CBA
GTIN	4046356313209
Weight per piece (including packing)	181.9 g
Weight per piece (excluding packing)	161.9 g
Country of origin	DE

# SAC-3P- 5,0-PUR/M12FS GY - Sensor/actuator cable



1565528

<https://www.phoenixcontact.com/us/products/1565528>

## Technical data

### Product properties

Product type	Sensor/actuator cable
Number of positions	3
No. of cable outlets	1
Shielded	no
Coding	A

### Insulation characteristics

Overvoltage category	II
Degree of pollution	3

### Material specifications

Flammability rating according to UL 94	HB
Seal material	NBR
Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material for screw connection	Zinc die-cast, nickel-plated

### Electrical properties

Insulation resistance	$\geq 100 \text{ M}\Omega$
Nominal voltage $U_N$	250 V
Nominal current $I_N$	4 A

### Mechanical properties

#### Mechanical data

Insertion/withdrawal cycles	$\geq 100$
-----------------------------	------------

### Signaling

Status display	no
Status display present	no

### Connector

#### Connection 1

Type	free cable end
------	----------------

#### Connection 2

Type	Socket straight M12
Number of positions	3
Coding type	A

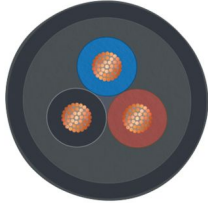
# SAC-3P- 5,0-PUR/M12FS GY - Sensor/actuator cable



1565528

<https://www.phoenixcontact.com/us/products/1565528>

## Cable/line

Cable length	5 m
PUR/PVC black [350]	
Dimensional drawing	
Cable weight	37 kg/km
UL AWM Style	20549 / 1729
Number of positions	3
Shielded	no
Cable type	PUR/PVC black [350]
Conductor structure signal line	42x 0.10 mm
Conductor cross-section	0.34 mm <sup>2</sup>
Wire diameter incl. insulation	1.5 mm ±0.05 mm
External cable diameter	5.20 mm ±0.2 mm
Outer sheath, material	PUR
External sheath, color	black-gray RAL 7021
Conductor material	Bare Cu litz wires
Material wire insulation	PVC
Single wire, color	brown, blue, black
Thickness, insulation	≥ 0.23 mm (Core insulation)
Inner sheath thickness	approx. 0.50 mm
Thickness, outer sheath	≥ 0.38 mm (Outer cable sheath)
Overall twist	3 wires, twisted
Length of twist, overall twist	55 mm
Max. conductor resistance	max. 58 Ω/km (at 20 °C)
Insulation resistance	≥ 100 MΩ*km (at 20 °C)
Nominal voltage, cable	300 V
Test voltage	3000 V
Smallest bending radius, fixed installation	26 mm
Smallest bending radius, movable installation	52 mm
Flame resistance	according to UL 758/1581 (horizontal) in accordance with UL 758/1581 FT2 According to DIN EN 60332-2-2 (20 s)
Other resistance	hydrolysis and microbe resistant Low adhesion abrasion-resistant

# SAC-3P- 5,0-PUR/M12FS GY - Sensor/actuator cable



1565528

<https://www.phoenixcontact.com/us/products/1565528>

Special properties	Flexible use, however not recommended for use in drag chains
Ambient temperature (operation)	-40 °C ... 80 °C (cable, fixed installation)
	-20 °C ... 80 °C (Cable, flexible installation)

## Environmental and real-life conditions

### Ambient conditions

Degree of protection	IP65
	IP67
	IP68
Ambient temperature (operation)	-25 °C ... 90 °C (Plug / socket)
	-25 °C ... 80 °C (cable, fixed installation)
	-5 °C ... 80 °C (Cable, flexible installation)

1565528

<https://www.phoenixcontact.com/us/products/1565528>

## Drawings

Dimensional drawing



M12 x 1 socket, straight

Schematic diagram



Pin assignment M12 socket, 3-pos., A-coded, view female side

# SAC-3P- 5,0-PUR/M12FS GY - Sensor/actuator cable



1565528

<https://www.phoenixcontact.com/us/products/1565528>

Circuit diagram



Contact assignment of the M12 socket

# SAC-3P- 5,0-PUR/M12FS GY - Sensor/actuator cable



1565528

<https://www.phoenixcontact.com/us/products/1565528>

## Classifications

### ECLASS

ECLASS-13.0	27060311
ECLASS-15.0	27060311

# SAC-3P- 5,0-PUR/M12FS GY - Sensor/actuator cable



1565528

<https://www.phoenixcontact.com/us/products/1565528>

## Environmental product compliance

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)