

# HC-K 6 PE 16 QMM F - Terminal block



1583869

<https://www.phoenixcontact.com/us/products/1583869>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HC-K6 PE clamp 6 - 16 with threaded pin M6 x 12 DIN 913 for socket

## Commercial data

Item number	1583869
Packing unit	25 pc
Minimum order quantity	25 pc
Product key	AF7ABZ
GTIN	4046356495387
Weight per piece (including packing)	222.22 g
Weight per piece (excluding packing)	222.22 g
Country of origin	DE

# HC-K 6 PE 16 QMM F - Terminal block



1583869

<https://www.phoenixcontact.com/us/products/1583869>

## Technical data

### Product properties

Product type	Ground contact
--------------	----------------

### Material specifications

Material	Brass
----------	-------

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------


# HC-K 6 PE 16 QMM F - Terminal block

1583869

<https://www.phoenixcontact.com/us/products/1583869>

## Drawings

Dimensional drawing

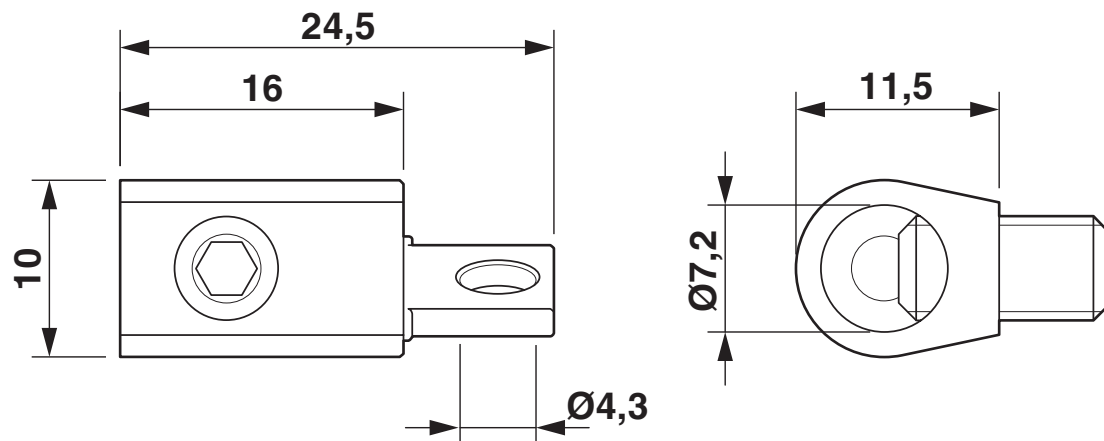

Dimensional drawing

# HC-K 6 PE 16 QMM F - Terminal block



1583869

<https://www.phoenixcontact.com/us/products/1583869>

## Environmental product compliance

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)