

HC-M-08-GBIT-LK7 - Strain relief clamp

1587742

<https://www.phoenixcontact.com/us/products/1587742>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Cable clamp for cable diameter of 5 - 7 mm



Commercial data

Item number	1587742
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF62
Product key	AF7ACZ
GTIN	4046356527958
Weight per piece (including packing)	14.8 g
Weight per piece (excluding packing)	14.25 g
Customs tariff number	85389099
Country of origin	DE

HC-M-08-GBIT-LK7 - Strain relief clamp



1587742

<https://www.phoenixcontact.com/us/products/1587742>

Technical data

Product properties

Product type	Mounting material
--------------	-------------------

Material specifications

Material	Zinc alloy
----------	------------

Cable/line

External cable diameter	5 mm ... 7 mm
-------------------------	---------------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------


HC-M-08-GBIT-LK7 - Strain relief clamp

1587742

<https://www.phoenixcontact.com/us/products/1587742>

Drawings

Dimensional drawing

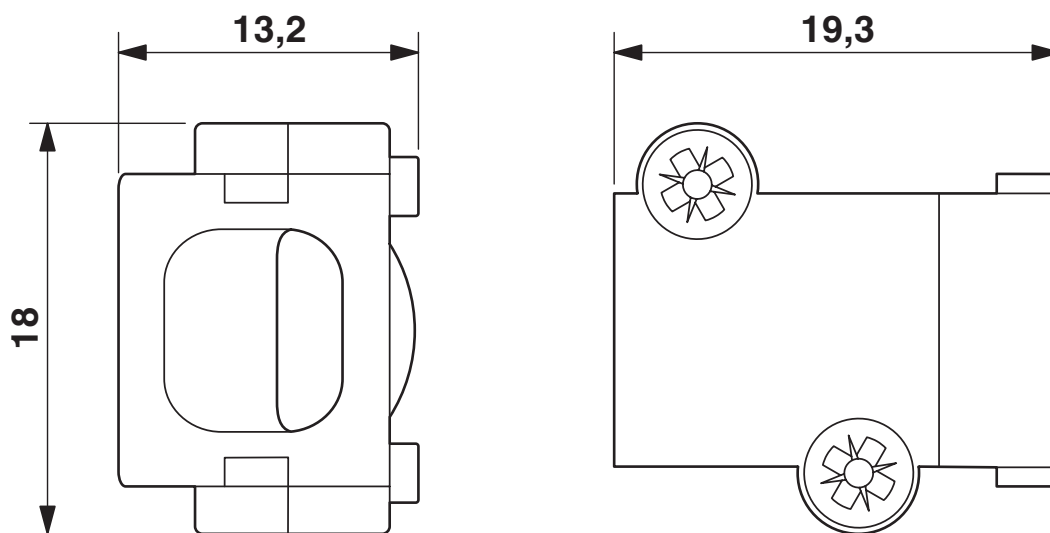

HC-M-08-GBIT-LK7 - Strain relief clamp



1587742

<https://www.phoenixcontact.com/us/products/1587742>

Environmental product compliance

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com