

# HC-26S1N1280D2 - Cable connector



1590353

<https://www.phoenixcontact.com/us/products/1590353>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable connector, application: Signal, M27, contact connection type: Socket, cable diameter range: 2 mm ... 14.5 mm, number of positions: 26, connection method: Solder connection

## Commercial data

Item number	1590353
Packing unit	10 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Product key	ABRAJA
GTIN	4055626118727
Weight per piece (including packing)	79 g
Weight per piece (excluding packing)	79 g
Country of origin	DE

# HC-26S1N1280D2 - Cable connector



1590353

<https://www.phoenixcontact.com/us/products/1590353>

## Technical data

### Product properties

Product type	Circular connector (cable-side)
Application	Signal
Number of positions	26
Thread type	M27

### Connection data

#### Conductor connection

Connection method	Solder connection
-------------------	-------------------

### Cable/line

External cable diameter	2 mm ... 14.5 mm
-------------------------	------------------

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP67
----------------------	------

# HC-26S1N1280D2 - Cable connector




1590353

<https://www.phoenixcontact.com/us/products/1590353>

## Drawings

Schematic diagram

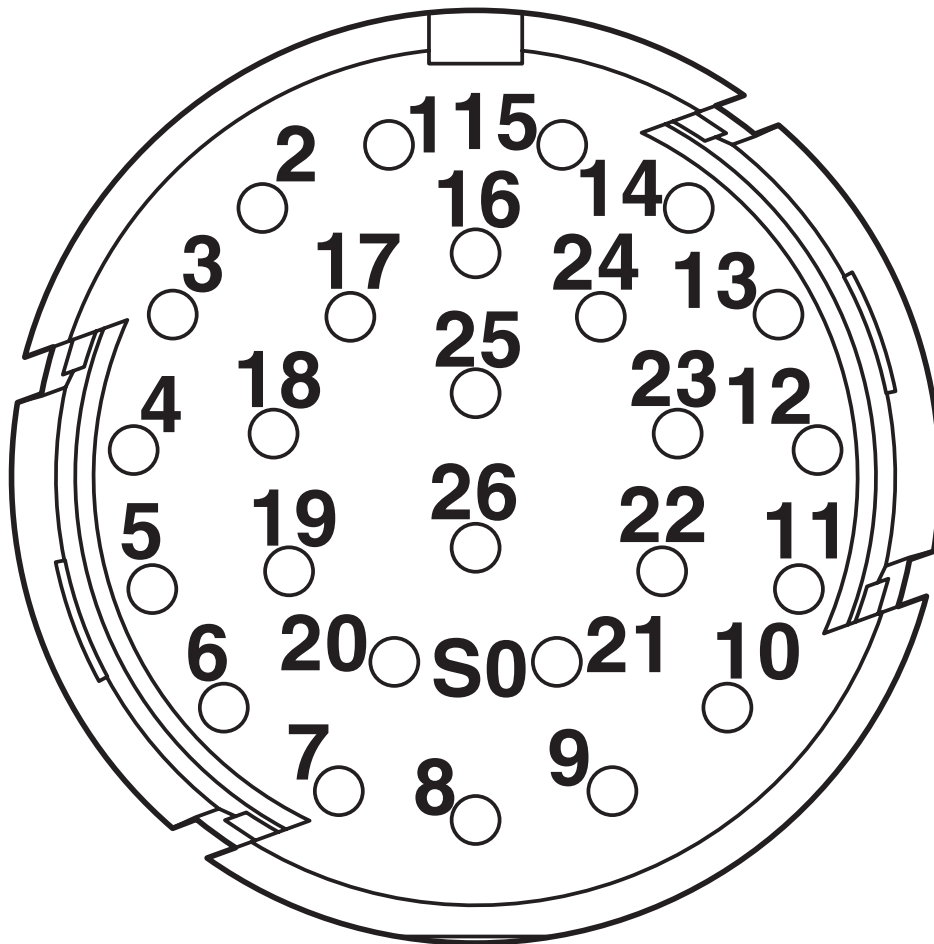

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)