

HC-26S1N324300 - Device connector rear mounting



1590379

<https://www.phoenixcontact.com/us/products/1590379>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Device connector rear mounting, application: Signal, straight, M27, contact connection type: Socket, Radial O-ring, 4xM3, number of positions: 26, connection method: Solder-in connection

The figure shows the 28-pos. product version

Commercial data

Item number	1590379
Packing unit	24 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Product key	ABRAJR
GTIN	4046356187152
Weight per piece (including packing)	52.59 g
Weight per piece (excluding packing)	52.59 g
Country of origin	DE

HC-26S1N324300 - Device connector rear mounting



1590379

<https://www.phoenixcontact.com/us/products/1590379>

Technical data

Product properties

Product type	Circular connectors (device side)
Application	Signal
Number of positions	26
Thread type	M27

Electrical properties

Contact

Contact diameter	1 mm
Nominal current I_N	8 A
Nominal voltage U_N	150 V
Overvoltage category	II
Degree of pollution	3
Rated surge voltage	1.5 kV

Connection data

Conductor connection

Connection method	Solder-in connection
Contact connection type	Socket

Connector

Type	straight
Direction of rotation	Standard


Environmental and real-life conditions

Ambient conditions

Degree of protection	IP67, when plugged in
----------------------	-----------------------

Drawings


Dimensional drawing

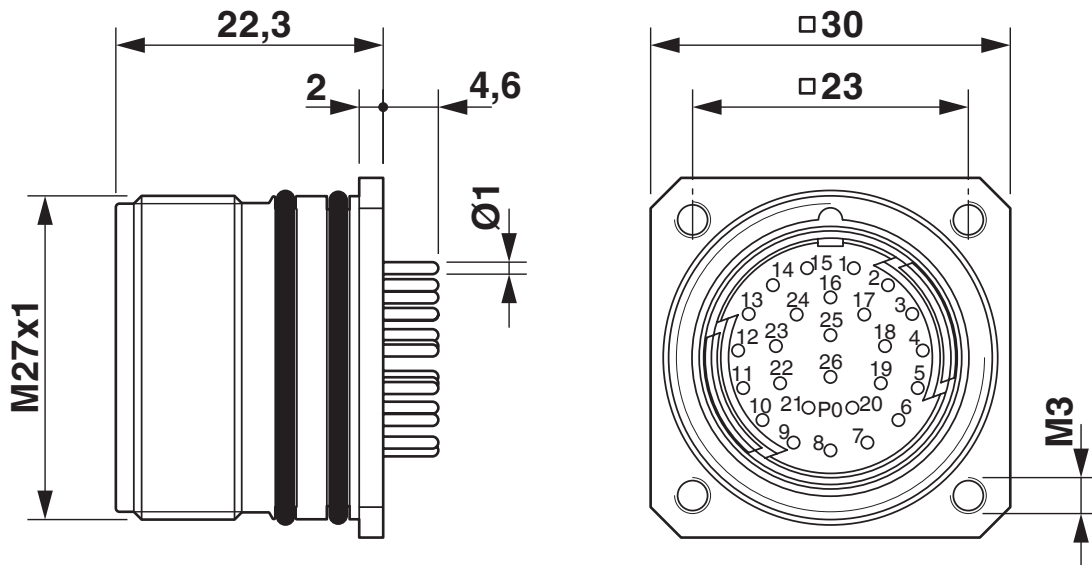

1590379

<https://www.phoenixcontact.com/us/products/1590379>

Schematic diagram

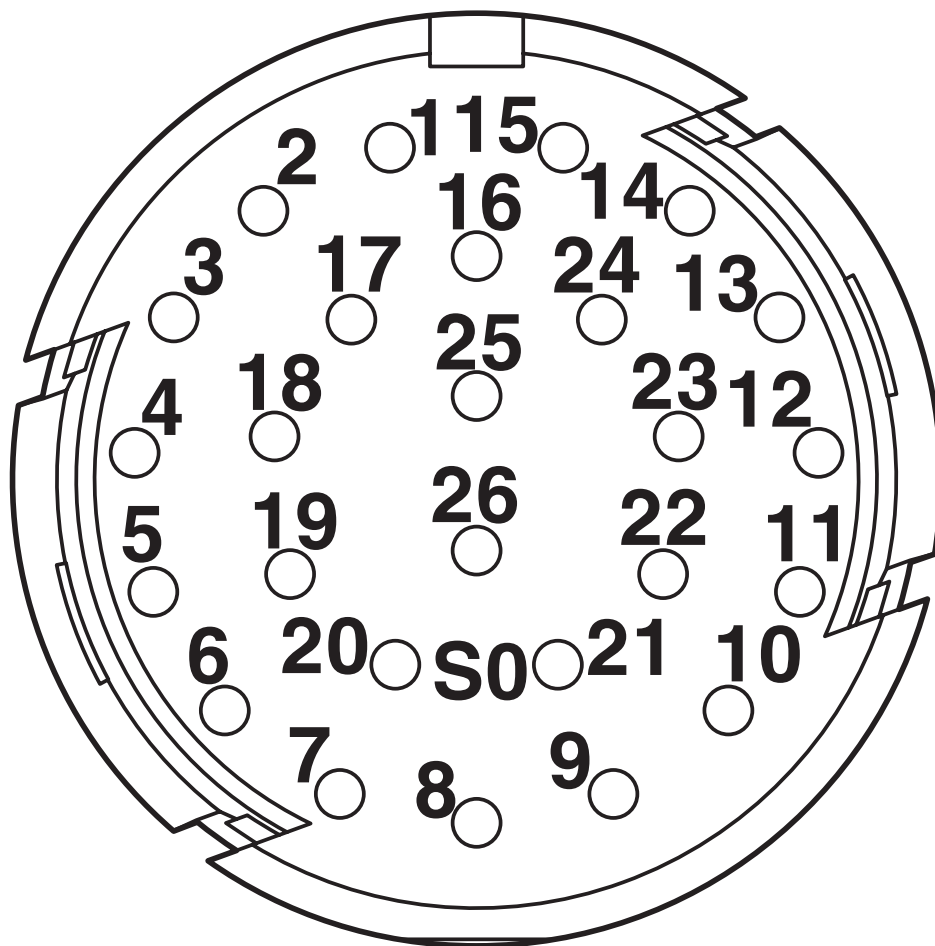

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com