

HC-B 16-TMQ-65/O1M25G - Housing



1604815

<https://www.phoenixcontact.com/us/products/1604815>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HEAVYCON sleeve housing B16, with double locking latch, height 65 mm, with support 1x M25, straight conductor exit

Commercial data

Item number	1604815
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	NULL
Product key	AF7AAC
GTIN	4017918881580
Weight per piece (including packing)	262.88 g
Weight per piece (excluding packing)	253.3 g
Customs tariff number	85389099
Country of origin	DE

HC-B 16-TMQ-65/O1M25G - Housing

1604815

<https://www.phoenixcontact.com/us/products/1604815>

Technical data


Notes

General	For contact inserts HC-B16, BB32, BBB40, D40, DD72, HS6, M, K
---------	---

Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Application	Standard
Type	B16
No. of cable outlets	1
Type of the screw connection	1x M25
Shielded	no
Cable outlet	straight
Pg screw connection	none

Dimensions

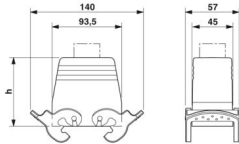Dimensional drawing	
Width	43 mm
Height	65 mm
Length	94 mm

Material specifications

Housing material	Die-cast aluminum
Housing surface material	Powder-coated, gray
Locking latch material	High-grade steel, handle: PA-GF

Mechanical properties

Mechanical data

Type of the screw connection	1x M25
Locking type	Latch

Mounting

Assembly note	For half and full screw connections
---------------	-------------------------------------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP65
----------------------	------

HC-B 16-TMQ-65/O1M25G - Housing

1604815

<https://www.phoenixcontact.com/us/products/1604815>



Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

HC-B 16-TMQ-65/O1M25G - Housing


1604815

<https://www.phoenixcontact.com/us/products/1604815>



Drawings

Dimensional drawing

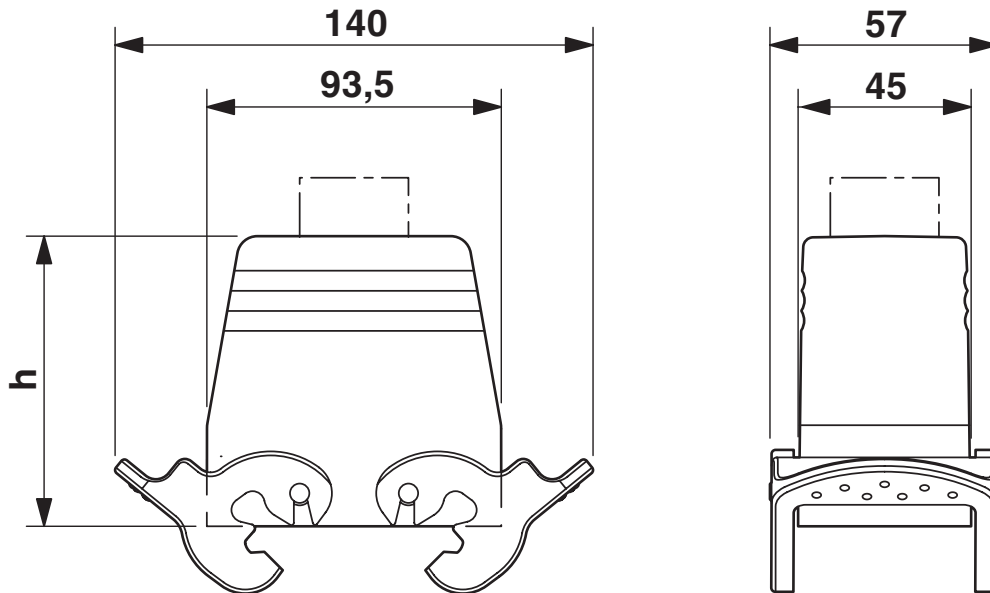

HC-B 16-TMQ-65/O1M25G - Housing



1604815

<https://www.phoenixcontact.com/us/products/1604815>

Classifications

ECLASS

ECLASS-13.0	27440202
ECLASS-15.0	27440202

HC-B 16-TMQ-65/O1M25G - Housing



1604815

<https://www.phoenixcontact.com/us/products/1604815>

Environmental product compliance

China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com