

# TU-0000000WB00 - Housing for circular connector



1605893

<https://www.phoenixcontact.com/us/products/1605893>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Housing for circular connector, series: TU, straight, Bayonet locking, M23, number of positions: 12, contact connection type: Socket, Crimp connection, Axial O-ring, shielded: yes, panel thickness min.: 1.5 mm. This product is in the process of being discontinued. This product must no longer be considered for new projects. Please contact your sales representative for alternatives.

## Commercial data

Item number	1605893
Packing unit	40 pc
Minimum order quantity	1 pc
Sales key	AB31
Product key	ABRAHP
GTIN	4046356255516
Weight per piece (including packing)	37.74 g
Weight per piece (excluding packing)	35.97 g
Customs tariff number	85366990
Country of origin	DE

# TU-0000000WB00 - Housing for circular connector



1605893

<https://www.phoenixcontact.com/us/products/1605893>

## Technical data

### Notes

Order information:	Order contact inserts separately
--------------------	----------------------------------

 
### Product properties

Product type	Circular connector housing
Series	TU
Application	Signal
Connection profile	12
Shielded	yes
Thread type	M23

### Connection data

Connection method	Crimp connection
-------------------	------------------

### Dimensions

Dimensional drawing	
Length of the solder pin	16.5 mm
	9 mm
	16.5 mm
	9 mm
Panel thickness	> 1.5 mm

### Material specifications

Material Housing	GD-Zn
Material Rotating parts	CuZn
Material Housing surface	Ni
Material Seal	FPM (O-ring)
Seal material	FPM or NBR or EPDM

### Connector

Type	straight
------	----------

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP67
Ambient temperature (operation)	-20 °C ... 125 °C
Altitude	2000 m

### Mounting

# TU-0000000WB00 - Housing for circular connector



1605893

<https://www.phoenixcontact.com/us/products/1605893>

Mounting type	Front mounting/square flange (4x Ø 3.2 mm)
---------------	--

# TU-0000000WB00 - Housing for circular connector

1605893


<https://www.phoenixcontact.com/us/products/1605893>



## Drawings

Dimensional drawing

**4xØ3,2/M3/□19,8±0,1**

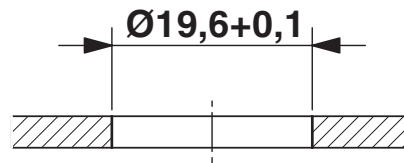

Installation dimensions

# TU-0000000WB00 - Housing for circular connector



1605893

<https://www.phoenixcontact.com/us/products/1605893>

## Classifications

### ECLASS

ECLASS-13.0	27440224
ECLASS-15.0	27440224

### ETIM

ETIM 10.0	EC003556
-----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

1605893

<https://www.phoenixcontact.com/us/products/1605893>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	75313cb1-ef58-4b27-9b69-c53d63a00cc1

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)