

UC-09P1N12F3DU - Coupler connector



1606222

<https://www.phoenixcontact.com/us/products/1606222>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Coupler connector, application: Signal, series: UC, straight, shielded: yes, Screw locking mechanism, No. of pos.: 8+1, Direction of rotation: Standard, contact connection type: Pin, Solder cup, cable diameter range: 2 mm ... 14.5 mm, coding: N

The figure shows the 12-pos.
product version

Commercial data

Item number	1606222
Packing unit	20 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Product key	ABRAIG
GTIN	4046356258142
Weight per piece (including packing)	115.7 g
Weight per piece (excluding packing)	115.7 g
Country of origin	DE

UC-09P1N12F3DU - Coupler connector



1606222

<https://www.phoenixcontact.com/us/products/1606222>

Technical data

Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

Connector

Insulating body

Coding	N
Material (Insulating body)	PBT
Material (Contact)	CuZn
Material (Contact surface)	Ni/Au
Insertion/withdrawal cycles	50
Connection method	Solder cup
Contact switching type	Pin
Application	Signal
Number of positions	9
Direction of rotation	Standard
Connection profile	8+1
Number (Contact group 1)	1
Contact diameter (Contact group 1)	2 mm
Litz wires Min. cross section (Contact group 1)	0.08 mm ²
Litz wires Max. cross section (Contact group 1)	2.5 mm ²
Rated current Contact (Contact group 1)	20 A (for max. connection cross section)
Rated voltage Contact (Contact group 1)	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3
Number (Contact group 2)	8
Contact diameter (Contact group 2)	1 mm
Litz wires Max. cross section (Contact group 2)	1 mm ²
Rated current Contact (Contact group 2)	8 A
Rated voltage Contact (Contact group 2)	48 V AC 48 V AC

Housing

Order information:	Order contact inserts separately
Type	Coupling housing
Thread type	M23
Design	straight
Type of locking	Screw locking mechanism
Pg screw connection	Pg13,5
Material (Housing)	GD-Zn

UC-09P1N12F3DU - Coupler connector



1606222

<https://www.phoenixcontact.com/us/products/1606222>

Material (Housing surface)	Ni
Material (Rotating parts)	CuZn
Degree of protection (plugged in)	IP67

Seal

External cable diameter	2 mm ... 14.5 mm
Seal material	NBR

UC-09P1N12F3DU - Coupler connector



1606222

<https://www.phoenixcontact.com/us/products/1606222>

Drawings

Schematic diagram




Connector pin assignment

UC-09P1N12F3DU - Coupler connector

1606222

<https://www.phoenixcontact.com/us/products/1606222>

Schematic diagram

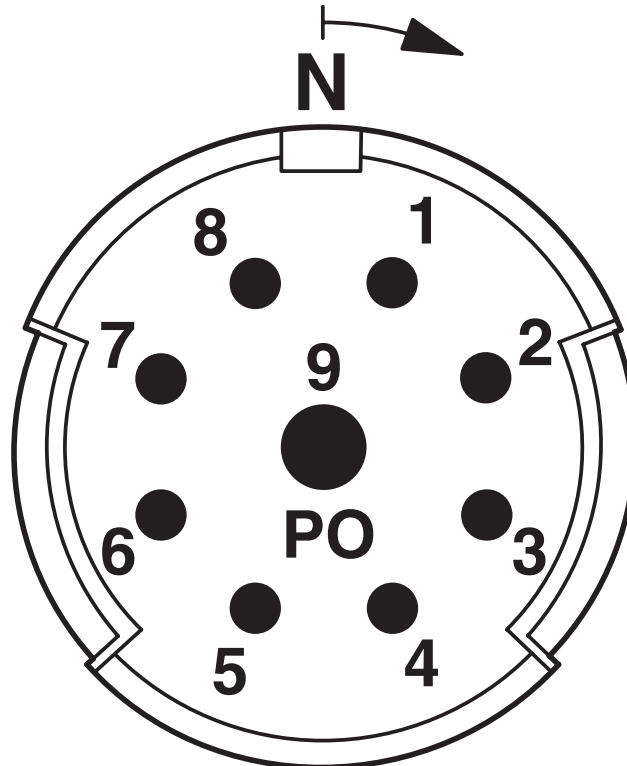

Connector pin assignment

UC-09P1N12F3DU - Coupler connector



1606222

<https://www.phoenixcontact.com/us/products/1606222>

Schematic diagram




Dimensional drawing

UC-09P1N12F3DU - Coupler connector



1606222

<https://www.phoenixcontact.com/us/products/1606222>

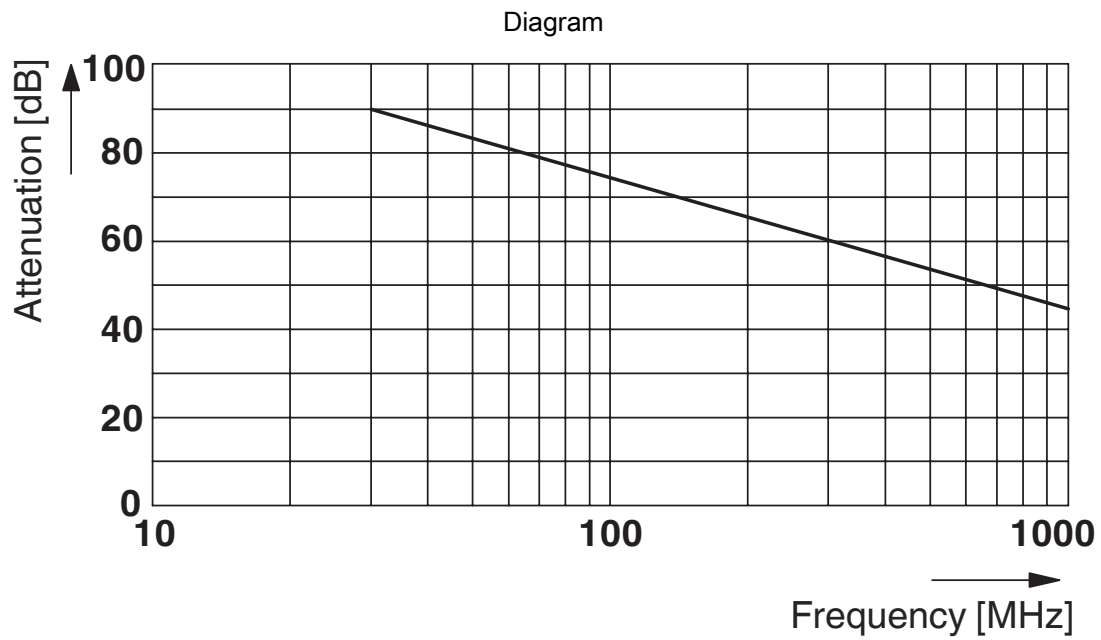

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com