

# TC-06P1N8A80EQ - Cable connector



1622622

<https://www.phoenixcontact.com/us/products/1622622>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable connector, application: Signal, No. of pos.: 6, Direction of rotation: Standard, contact connection type: Pin, Crimp connection, cable diameter range: 3 mm ... 10.5 mm, coding: N

## Commercial data

Item number	1622622
Packing unit	20 pc
Minimum order quantity	20 pc
Note	Made to order (non-returnable)
Product key	ABRIDA
GTIN	4055626052861
Weight per piece (including packing)	74.71 g
Weight per piece (excluding packing)	70.023 g
Country of origin	DE

# TC-06P1N8A80EQ - Cable connector



1622622

<https://www.phoenixcontact.com/us/products/1622622>

## Technical data

### Notes

Order information:	Order crimp contacts Ø 2 mm separately
--------------------	--

### Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

### Material specifications

Flammability rating according to UL 94	V0
--	----

### Connector

#### Insulating body

Note	Order information: Order crimp contacts Ø 2 mm separately
Coding	N
Material (Insulating body)	PA 6.6
Flammability rating according to UL 94	V0
Connection method	Crimp connection
Contact switching type	Pin
Application	Signal
Number of positions	6
Direction of rotation	Standard
Connection profile	6
Number (Contact group 1)	6
Contact diameter (Contact group 1)	2 mm
Rated current Contact (Contact group 1)	20 A (for max. connection cross section)
Rated voltage Contact (Contact group 1)	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

#### Seal

External cable diameter	3 mm ... 10.5 mm
Seal material	NBR

### Environmental and real-life conditions

#### Ambient conditions

Permissible humidity (storage/transport)	50 % ... 65 %
--	---------------

# TC-06P1N8A80EQ - Cable connector


1622622

<https://www.phoenixcontact.com/us/products/1622622>



## Drawings

Schematic diagram

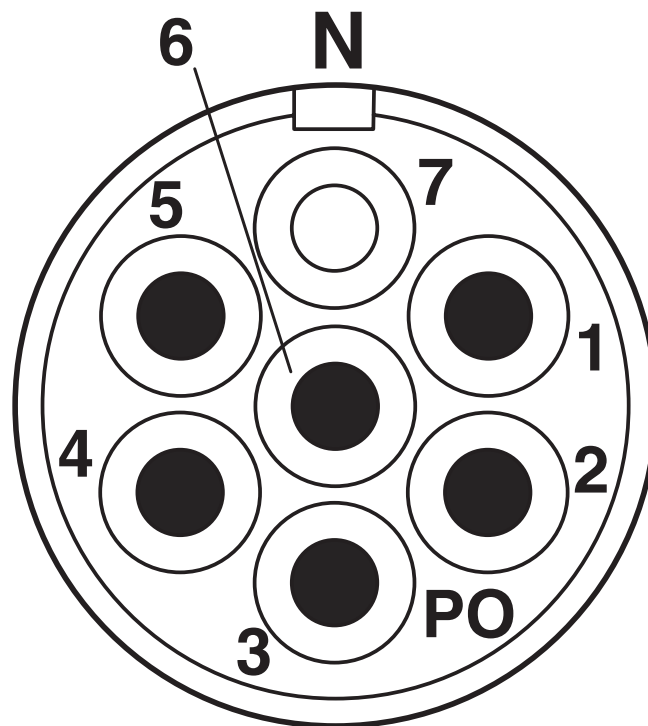

Connector pin assignment

# TC-06P1N8A80EQ - Cable connector



1622622

<https://www.phoenixcontact.com/us/products/1622622>

## Classifications

### ECLASS

ECLASS-13.0	27440312
ECLASS-15.0	27440312

### ETIM

ETIM 9.0	EC002641
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# TC-06P1N8A80EQ - Cable connector



1622622

<https://www.phoenixcontact.com/us/products/1622622>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	76039651-5400-485e-a847-afbc56980e38

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)