

# CA-12P2N8A8006 - Cable connector



1623446

<https://www.phoenixcontact.com/us/products/1623446>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Cable connector, application: Signal, series: CA, straight, shielded: yes, Screw locking mechanism, No. of pos.: 12, Direction of rotation: Counter direction, contact connection type: Pin, Crimp connection, cable diameter range: 4 mm ... 6 mm, coding: N

The figure shows the 12-pos. product version with standard contact chamber numbering and solder contacts

## Commercial data

Item number	1623446
Packing unit	1 pc
Minimum order quantity	1 pc
Product key	ABRAEA
GTIN	4055626149530
Weight per piece (including packing)	82.7 g
Weight per piece (excluding packing)	82.7 g
Country of origin	DE

# CA-12P2N8A8006 - Cable connector



1623446

<https://www.phoenixcontact.com/us/products/1623446>

## Technical data

### Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

### Connector

#### Insulating body

Note	Order information: Order crimp contacts Ø 1 mm separately
Coding	N
Material (Insulating body)	PA 6.6
Connection method	Crimp connection
Contact switching type	Pin
Application	Signal
Number of positions	12
Direction of rotation	Counter direction
Connection profile	12
Number (Contact group 1)	12
Contact diameter (Contact group 1)	1 mm
Rated current Contact (Contact group 1)	8 A (for max. connection cross section)
Rated voltage Contact (Contact group 1)	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

#### Housing

Type	Cable connector housing
Thread type	M23
Design	straight
Type of locking	Screw locking mechanism
Pg screw connection	none
Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Material for screw connection	CuZn
Degree of protection (plugged in)	IP67

#### Seal

External cable diameter	4 mm ... 6 mm
Seal material	NBR

## Environmental and real-life conditions

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------


# CA-12P2N8A8006 - Cable connector

1623446

<https://www.phoenixcontact.com/us/products/1623446>

## Drawings

Schematic diagram

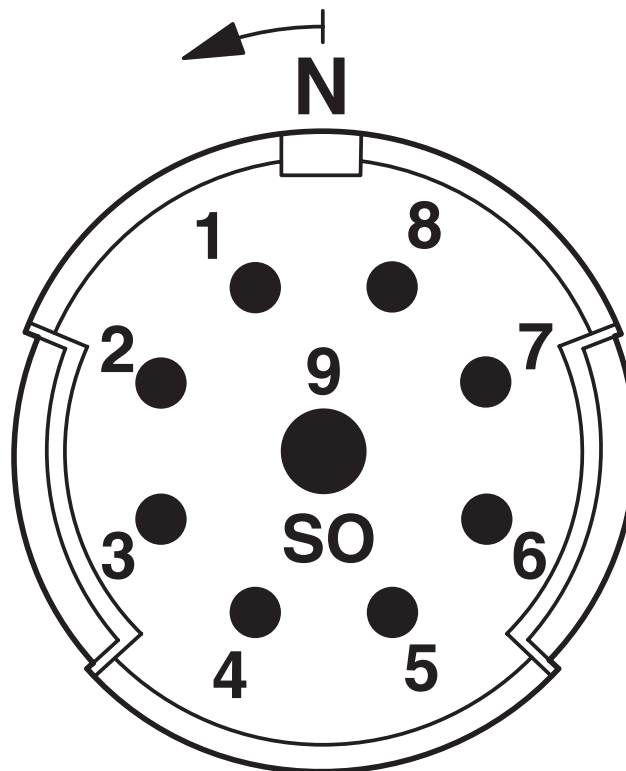

Contact chamber numbering (view of plug-in side), pin counter direction

Phoenix Contact 2026 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)