


# SHK-0478/05,00 - Assembled cable connectors



1627074

<https://www.phoenixcontact.com/us/products/1627074>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

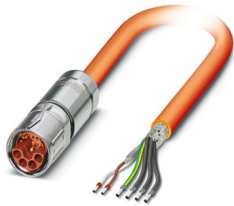

Assembled cable connectors, series: SHK, M23-Pin, gerade, konfektioniert, number of positions: 4+4+PE, cable length: 5 m, shielded: yes, color of outer sheath: orange RAL 2003, this item is expected to be lead-free from Q2 2026 in accordance with RoHS II without exception 6c (Pb < 0.1%), a lead-free alternative is possible on request in advance

## Commercial data

Item number	1627074
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	AB39
Product key	ABRSBL
GTIN	4055626310664
Weight per piece (including packing)	2,029.7 g
Weight per piece (excluding packing)	1,882.229 g
Customs tariff number	85444290
Country of origin	DE

1627074

<https://www.phoenixcontact.com/us/products/1627074>

## Technical data

### Product properties

Product type	Signal and power cable
--------------	------------------------

### Connector

#### Connector specifications

Type	gerade, konfektioniert
Thread type	M23
No. of pos.	4+4+PE
Direction of rotation	Standard
Contact switching type	Pin

### Cable/line


Cable length	5 m
--------------	-----

#### Cable specifications

Shielded	yes
Cable structure	(4 x 4 + (2 x 1.0))
External cable diameter	± 14.60 mm 0.6 mm
Outer sheath, material	PUR
Material wire insulation	PP (halogen-free)
External sheath, color	orange RAL 2003
Single wire, color	black 1, black 2, black 3, green/yellow Power wires + PE white, brown Signal wires
Nominal voltage, cable	1000 V
Test voltage	4 kV
Smallest bending radius, fixed installation	58 mm
Smallest bending radius, movable installation	109 mm
Acceleration	10 m/s <sup>2</sup>
Ambient temperature (operation) for fixed installation	-40 °C ... 80 °C
Ambient temperature (operation) for flexible installation	-30 °C ... 60 °C
Special properties	Flexible cable conduit capable
Flame resistance	IEC 60332-1-2
Halogen-free	yes, PUR sheath
Resistance to oil	yes, PUR sheath

Drawings

Circuit diagram

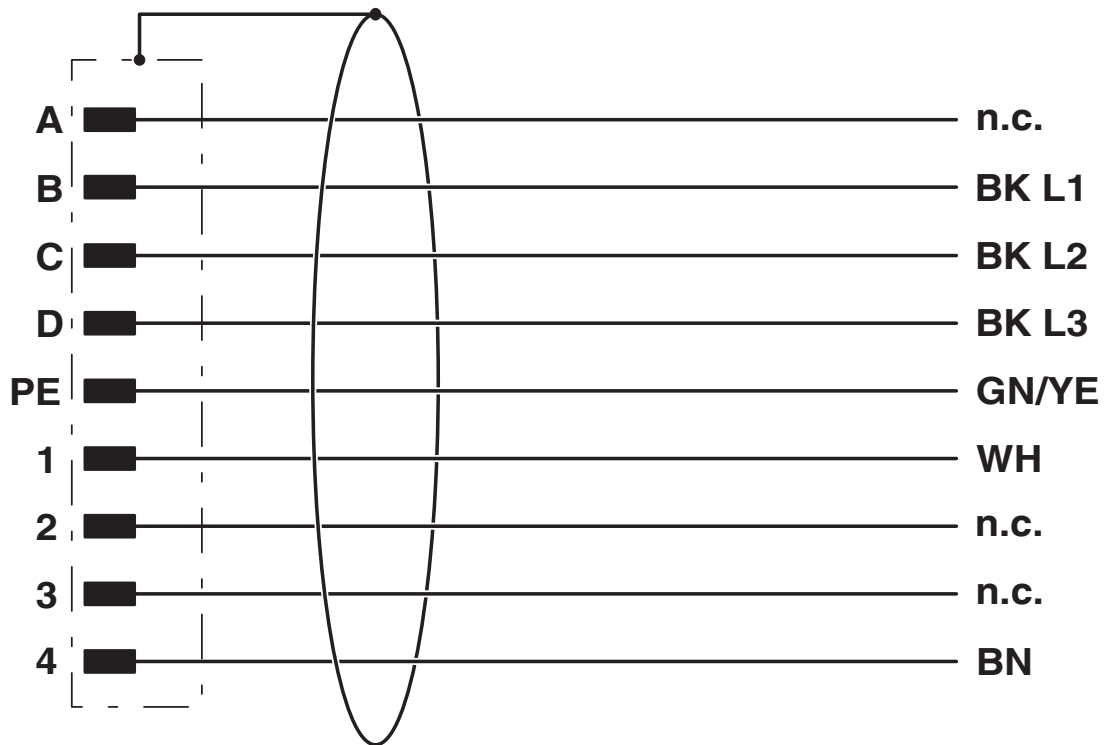

Contact assignment

# SHK-0478/05,00 - Assembled cable connectors



1627074

<https://www.phoenixcontact.com/us/products/1627074>

## Classifications

### ECLASS

ECLASS-15.0

27440108

### ETIM

ETIM 10.0

EC003569

### UNSPSC

UNSPSC 21.0

39121400

1627074

<https://www.phoenixcontact.com/us/products/1627074>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

### China RoHS

Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

### EU REACH SVHC

REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	c83b9070-737f-46f8-ad56-0a671f145af7

Phoenix Contact 2026 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)