


HC-B 16-EBUZZ - Contact insert



1647404

<https://www.phoenixcontact.com/us/products/1647404>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

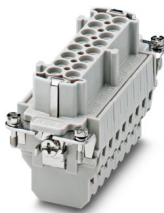

HEAVYCON female insert, B16 series, 16-pos., 2 spring-cage connections per contact

Commercial data

Item number	1647404
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF61
Product key	AF7ABC
GTIN	4017918948917
Weight per piece (including packing)	124.5 g
Weight per piece (excluding packing)	124.5 g
Customs tariff number	85369010
Country of origin	RO

HC-B 16-EBUZZ - Contact insert



1647404

<https://www.phoenixcontact.com/us/products/1647404>

Technical data

Notes

General	For housing HC-B16
---------	--------------------

Mounting

Assembly note	For housing $h \geq 72$ mm. Connectors may be operated only when there is no load/voltage.
	For housings of type B16/B32. Connectors may only be actuated when there is no load/voltage.


Product properties

Product type	Contact insert with a fixed no. of positions
Series	HC-B
Type	B16 B32
Number of positions	16
Connection profile	16+PE
Contact numbering	1 - 16

Insulation characteristics

Overvoltage category	III
Degree of pollution	3

Dimensions

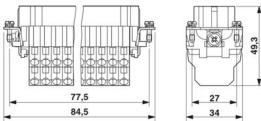Dimensional drawing	
Width	34 mm
Height	37.5 mm
Length	84.5 mm

Mechanical characteristics

Minimum housing height	72 mm
------------------------	-------

Connection data

Connection technology

Connection technology	Spring-cage connection
-----------------------	------------------------

Conductor connection

Conductor cross-section	0.14 mm ² ... 2.5 mm ²
Connection cross section AWG	26 ... 14
Tightening torque	0.5 Nm

HC-B 16-EBUZZ - Contact insert



1647404

<https://www.phoenixcontact.com/us/products/1647404>

Stripping length of the individual wire	10 mm ±1 mm
---	-------------

Electrical properties

Rated voltage (III/3)	500 V
Rated surge voltage	6 kV
Rated current	16 A

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 500
-----------------------------	-------

Material specifications

Flammability rating according to UL 94	V0
Contact material	Copper alloy
Contact surface material	Ag
Contact carrier material	PC

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C (including heating up of contacts)
---------------------------------	--

HC-B 16-EBUZZ - Contact insert




1647404

<https://www.phoenixcontact.com/us/products/1647404>


Drawings

Dimensional drawing

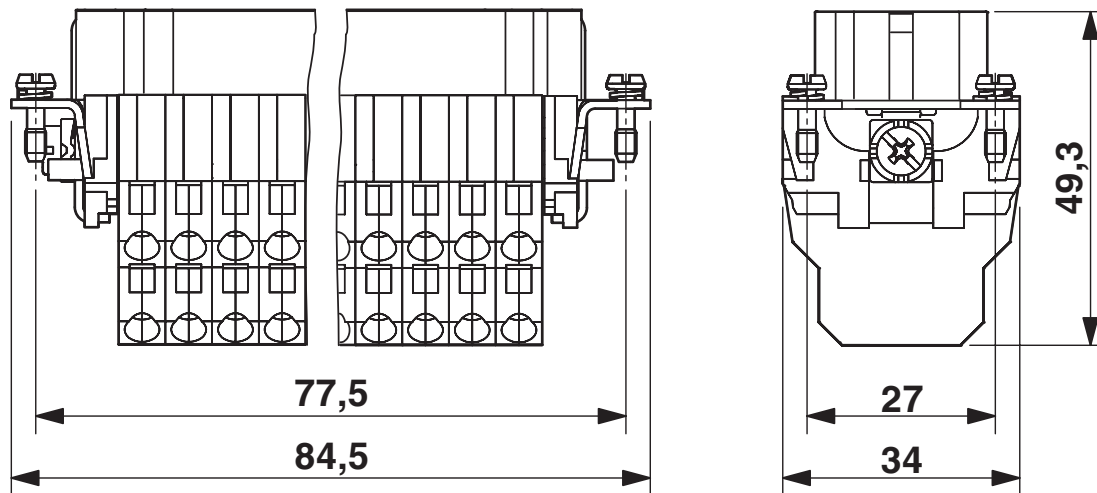

Dimensional drawing

Dimensional drawing

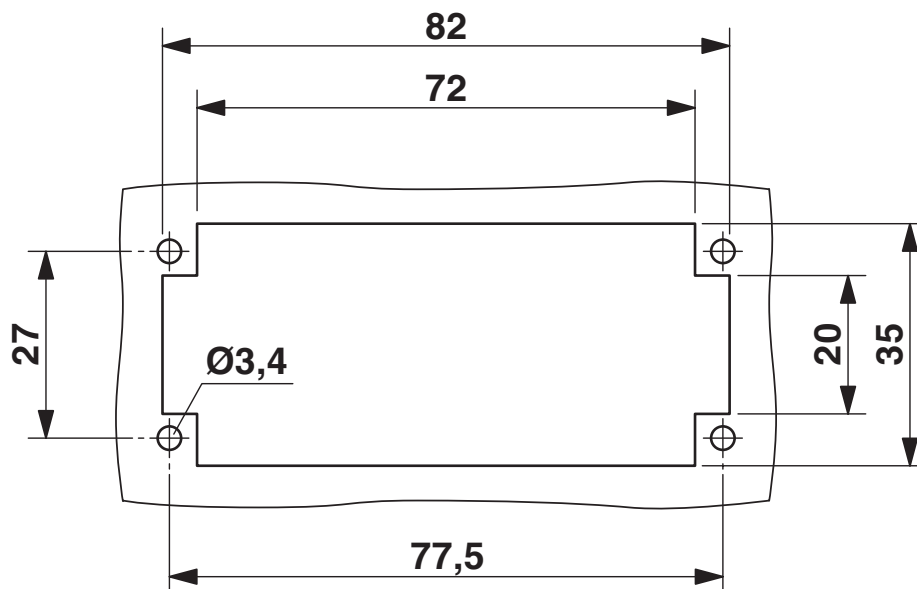

Mounting cutout


HC-B 16-EBUZZ - Contact insert

1647404


<https://www.phoenixcontact.com/us/products/1647404>




Schematic diagram

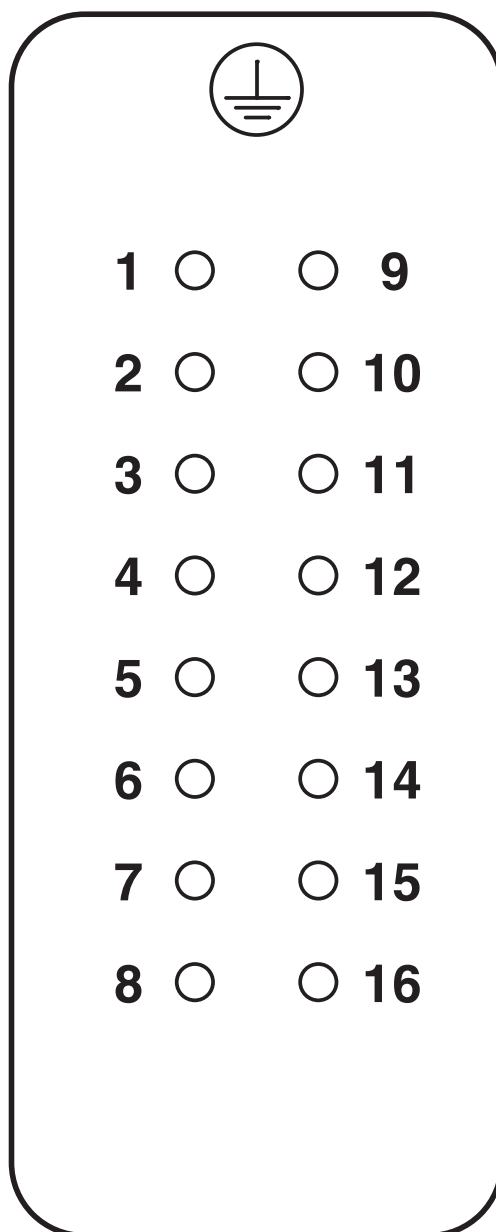

Connector pin assignment, connection side

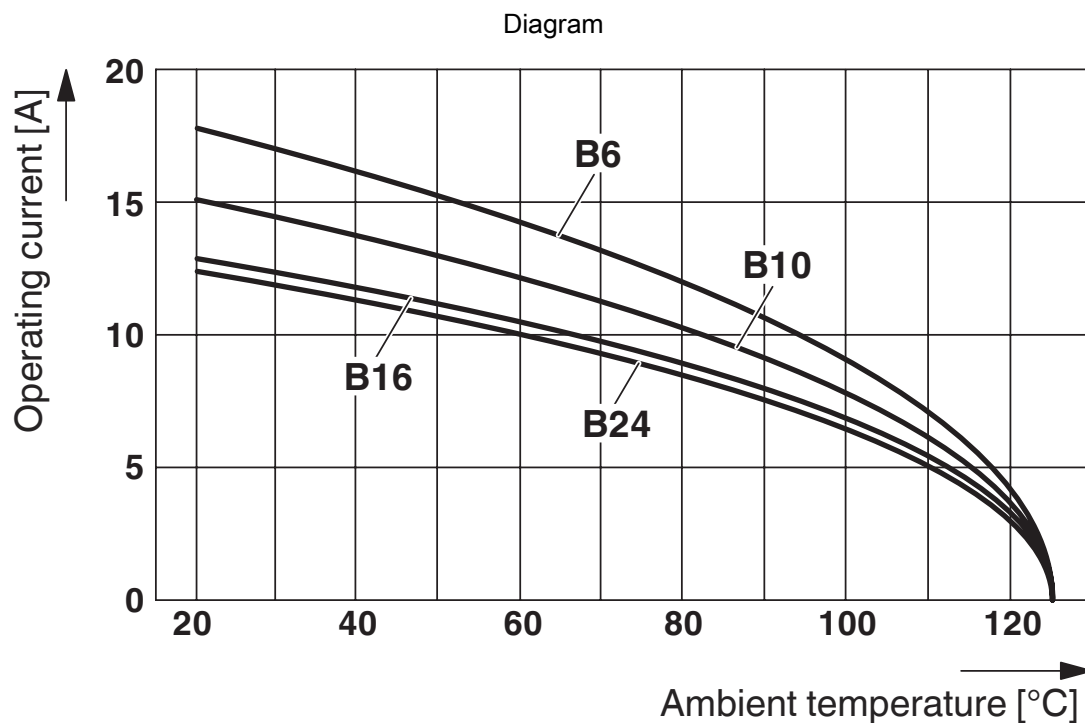

The figure shows the derating diagram of various series B contact inserts (B6 to B24), conductor cross-section 1.5 mm²

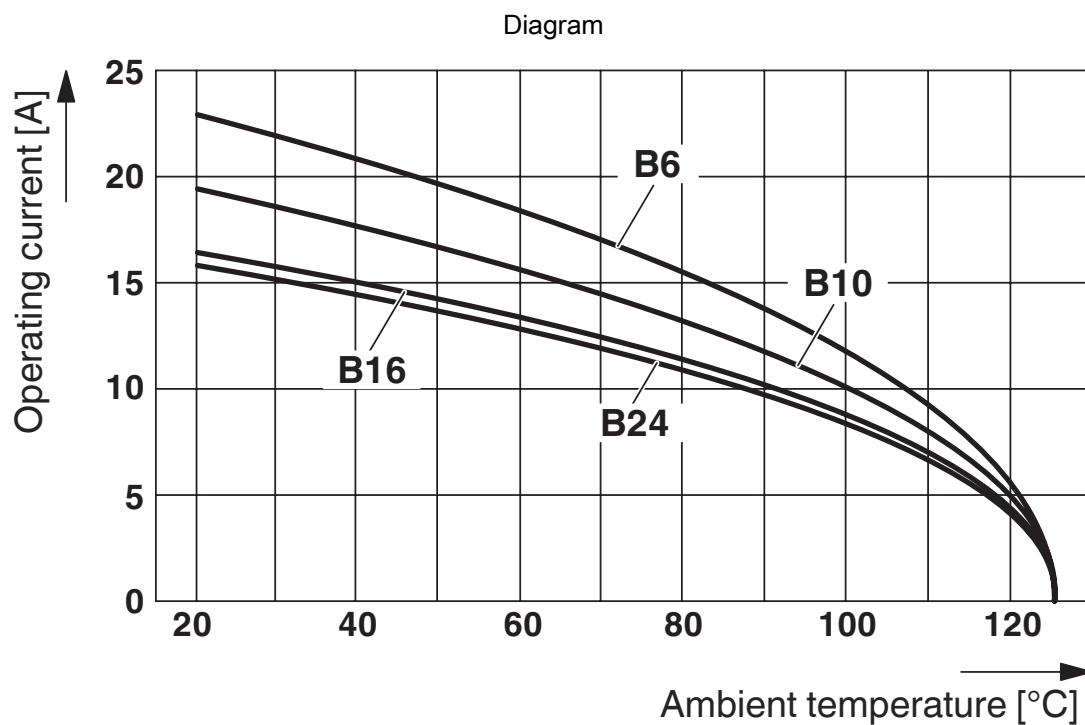

The figure shows the derating diagram of various series B contact inserts (B6 to B24), conductor cross-section 2.5 mm²

HC-B 16-EBUZZ - Contact insert



1647404

<https://www.phoenixcontact.com/us/products/1647404>

Classifications

ECLASS

ECLASS-13.0	27440205
ECLASS-15.0	27440205

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com