

VS-PP-19-1HE-16-F - Marshalling panel



1652994

<https://www.phoenixcontact.com/us/products/1652994>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Patch panel, 19" assembly, IP20, with 16 slots for contact inserts with the Freenet system



19" patch bay, for 16 Freenet inserts

Your advantages

- 16 installation slots per rack unit (RU)
- Grounding concept prepared
- Can be optionally equipped with copper and FO inserts
- For easy cable management

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 1652994 |
| Packing unit | 1 pc |
| Minimum order quantity | 1 pc |
| Sales key | AB18 |
| Product key | ABNLBA |
| GTIN | 4017918969967 |
| Weight per piece (including packing) | 618 g |
| Weight per piece (excluding packing) | 582.7 g |
| Customs tariff number | 85366990 |
| Country of origin | PL |

VS-PP-19-1HE-16-F - Marshalling panel

1652994

<https://www.phoenixcontact.com/us/products/1652994>

Technical data

Product properties

| | |
|------------------------|---|
| Product type | Patch panel |
| Application | Einbauplätze für Kontakteinsätze mit Freenet-System |
| No. of cable outlets | 16 |
| Number of module slots | 16 |
| Number of slots | 16 |


Electrical properties

| | |
|---------------------|----|
| Transmission medium | FO |
|---------------------|----|

Connection data

| | |
|-------------------|------------------|
| Connection method | Screw connection |
|-------------------|------------------|

Dimensions
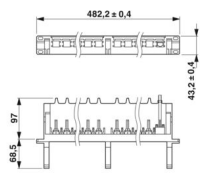
| | |
|---------------------------------|--|
| Dimensional drawing |  |
| Width | 482.2 mm |
| Height | 43.2 mm |
| Drill hole distance, horizontal | 31.6 mm |

Material specifications

| | |
|--|---------------------|
| Color | light gray RAL 7035 |
| Material | Plastic |
| Flammability rating according to UL 94 | V0 |
| Housing material | PC-GF |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|----------------|
| Degree of protection | IP20 |
| | IP20 |
| Ambient temperature (operation) | 5 °C ... 55 °C |

Mounting

| | |
|---------------|----------|
| Mounting type | 19" rack |
|---------------|----------|


VS-PP-19-1HE-16-F - Marshalling panel



1652994

<https://www.phoenixcontact.com/us/products/1652994>

Drawings

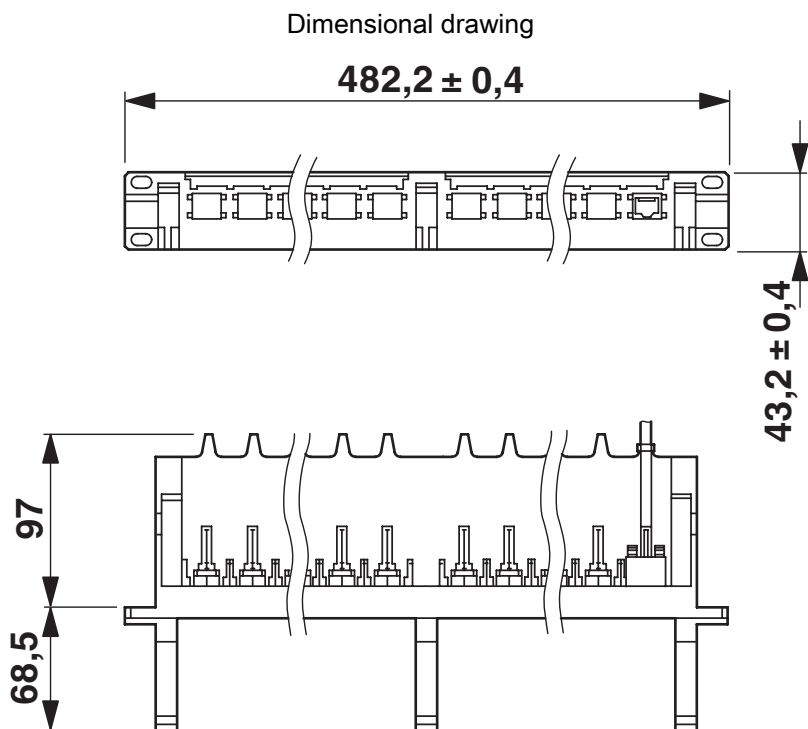

RJ45 patch panel

VS-PP-19-1HE-16-F - Marshalling panel



1652994

<https://www.phoenixcontact.com/us/products/1652994>

Classifications

ECLASS

| | |
|-------------|----------|
| ECLASS-13.0 | 19170192 |
| ECLASS-15.0 | 19170192 |

ETIM

| | |
|-----------|----------|
| ETIM 10.0 | EC003626 |
|-----------|----------|

UNSPSC

| | |
|-------------|----------|
| UNSPSC 21.0 | 43223300 |
|-------------|----------|

VS-PP-19-1HE-16-F - Marshalling panel



1652994

<https://www.phoenixcontact.com/us/products/1652994>

Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

EF3.1 Climate Change

| | |
|---------|----------------|
| CO2e kg | 12.238 kg CO2e |
|---------|----------------|

Phoenix Contact 2026 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com